


ROHM SEMICONDUCTOR Transistors

RoHS Compliant This product is RoHS compliant.

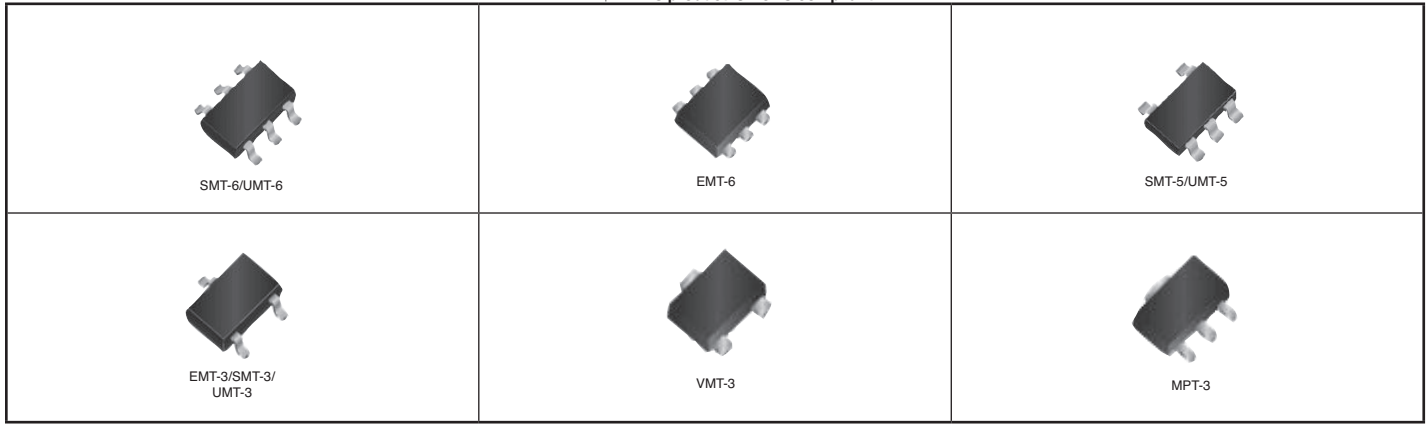

TRANSISTORS (CONT.)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Rohm Semi. Part No.	Package	Polarity	V _{CEO} (V)	I _C (A)	Price Each		
						1	25	100
Bipolar Transistors (Cont.)								
755-IMX17T110	IMX17T110	SMT-6	NPNx2	50	0.5	.46	.33	.237
755-IMX8T108	IMX8T108	SMT-6	NPNx2	120	0.05	.43	.31	.22
755-IMZ4T108	IMZ4T108	SMT-6	NPN	40	0.5	.46	.33	.237
			PNP	-40	-0.5			
755-EMZ1T2R	EMZ1T2R	EMT-6	NPN	50	0.15	.46	.33	.237
			PNP	-50	-0.15			
755-FMY1AT148	FMY1AT148	SMT-5	NPN	50	0.15	.44	.34	.244
			PNP	-50	-0.15			
755-IMZ1AT108	IMZ1AT108	SMT-6	NPN	50	0.15	.43	.31	.22
			PNP	-50	-0.15			
755-IMZ2AT108	IMZ2AT108	SMT-6	NPN	50	0.15	.46	.33	.237
			PNP	-50	-0.15			
755-UMY1NTR	UMY1NTR	UMT-5	NPN	50	0.15	.37	.25	.172
			PNP	-50	-0.15			
755-UMZ2NTR	UMZ2NTR	UMT-6	NPN	50	0.15	.43	.29	.198
			PNP	-50	-0.15			
755-EMT1T2R	EMT1T2R	EMT-6	PNP	-50	-0.15	.46	.33	.237
755-IMT1AT110	IMT1AT110	SMT-6	PNP	-50	-0.15	.48	.32	.223
755-UMT1NTN	UMT1NTN	UMT-6	PNP	-50	-0.15	.42	.28	.193
755-UMT2NTR	UMT2NTR	UMT-6	PNP	-50	-0.15	.42	.28	.193
755-IMT17T110	IMT17T110	SMT-6	PNP	-50	-0.5	.46	.33	.232
755-IMT4T108	IMT4T108	SMT-6	PNP	-120	-0.05	.43	.31	.22
Digital Transistors								
755-DTC113ZKAT146	DTC113ZKAT146	SMT-3	NPN	50	0.1	.36	.20	.133
755-DTC113ZUAT106	DTC113ZUAT106	UMT-3	NPN	50	0.1	.49	.28	.184
755-DTC114EETL	DTC114EETL	EMT-3	NPN	50	0.1	.36	.20	.133
755-DTC114EKAT146	DTC114EKAT146	SMT-3	NPN	50	0.1	.34	.20	.127
755-DTC114EUAT106	DTC114EUAT106	UMT-3	NPN	50	0.1	.43	.24	.158
755-DTC114TKAT146	DTC114TKAT146	SMT-3	NPN	50	0.1	.31	.18	.114
755-DTC114TUAT106	DTC114TUAT106	UMT-3	NPN	50	0.1	.36	.20	.133
755-DTC114WKAT146	DTC114WKAT146	SMT-3	NPN	50	0.1	.39	.26	.177
755-DTC114YETL	DTC114YETL	EMT-3	NPN	50	0.1	.43	.24	.158
755-DTC114YKAT146	DTC114YKAT146	SMT-3	NPN	50	0.1	.36	.20	.133
755-DTC114YMT2L	DTC114YMT2L	VMT-3	NPN	50	0.1	.43	.29	.202
755-DTC114YUAT106	DTC114YUAT106	UMT-3	NPN	50	0.1	.43	.24	.158
755-DTC115EKAT146	DTC115EKAT146	SMT-3	NPN	50	0.1	.36	.20	.133
755-DTC115EUAT106	DTC115EUAT106	UMT-3	NPN	50	0.1	.43	.24	.158
755-DTC123EETL	DTC123EETL	EMT-3	NPN	50	0.1	.43	.24	.158
755-DTC123EKAT146	DTC123EKAT146	SMT-3	NPN	50	0.1	.36	.20	.133
755-DTC123JETL	DTC123JETL	EMT-3	NPN	50	0.1	.43	.24	.158
755-DTC123JKAT146	DTC123JKAT146	SMT-3	NPN	50	0.1	.34	.20	.127
755-DTC123JUAT106	DTC123JUAT106	UMT-3	NPN	50	0.1	.43	.24	.158
755-DTC123YKAT146	DTC123YKAT146	SMT-3	NPN	50	0.1	.36	.20	.133
755-DTC123YUAT106	DTC123YUAT106	UMT-3	NPN	50	0.1	.43	.29	.198
755-DTC124EETL	DTC124EETL	EMT-3	NPN	50	0.1	.43	.24	.158
755-DTC124EKAT146	DTC124EKAT146	SMT-3	NPN	50	0.1	.36	.20	.133
755-DTC124EUAT106	DTC124EUAT106	UMT-3	NPN	50	0.1	.43	.24	.158
755-DTC124XETL	DTC124XETL	EMT-3	NPN	50	0.1	.43	.24	.158
755-DTC124XKAT146	DTC124XKAT146	SMT-3	NPN	50	0.1	.36	.20	.133
755-DTC143EETL	DTC143EETL	EMT-3	NPN	50	0.1	.43	.24	.158
755-DTC143EKAT146	DTC143EKAT146	SMT-3	NPN	50	0.1	.34	.20	.127
755-DTC143TKAT146	DTC143TKAT146	SMT-3	NPN	50	0.1	.34	.20	.127
755-DTC143TUAT106	DTC143TUAT106	UMT-3	NPN	50	0.1	.43	.24	.158
755-DTC143XKAT146	DTC143XKAT146	SMT-3	NPN	50	0.1	.36	.20	.133
755-DTC143ZETL	DTC143ZETL	EMT-3	NPN	50	0.1	.43	.24	.158
755-DTC143ZKAT146	DTC143ZKAT146	SMT-3	NPN	50	0.1	.36	.20	.133
755-DTC143ZUAT106	DTC143ZUAT106	UMT-3	NPN	50	0.1	.43	.24	.158
755-DTC144EETL	DTC144EETL	EMT-3	NPN	50	0.1	.43	.24	.158
755-DTC144EKAT146	DTC144EKAT146	SMT-3	NPN	50	0.1	.36	.20	.133
755-DTC144EMT2L	DTC144EMT2L	VMT-3	NPN	50	0.1	.37	.25	.176
755-DTC144EUAT106	DTC144EUAT106	UMT-3	NPN	50	0.1	.43	.24	.158
755-DTD113EKT146	DTD113EKT146	SMT-3	NPN	50	0.5	.42	.30	.215
755-DTD113ZKT146	DTD113ZKT146	SMT-3	NPN	50	0.5	.58	.39	.278
755-DTD114EKT146	DTD114EKT146	SMT-3	NPN	50	0.5	.40	.30	.219

TRANSISTORS (CONT.)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Rohm Semi. Part No.	Package	Polarity	V _{CEO} (V)	I _C (A)	Price Each		
						1	25	100
Digital Transistors (Cont.)								
755-DTD123EKT146	DTD123EKT146	SMT-3	NPN	50	0.5	.40	.30	.219
755-DTD123YKT146	DTD123YKT146	SMT-3	NPN	50	0.5	.40	.30	.214
755-DTD143EKT146	DTD143EKT146	SMT-3	NPN	50	0.5	.50	.38	.277
755-DTDG23YPT100	DTDG23YPT100	MPT-3	NPN	60	1.0	.68	.51	.39
755-DTA114EETL	DTA114EETL	EMT-3	PNP	-50	-0.1	.36	.20	.133
755-DTA114EKAT146	DTA114EKAT146	SMT-3	PNP	-50	-0.1	.29	.17	.11
755-DTA114EMT2L	DTA114EMT2L	VMT-3	PNP	-50	-0.1	.43	.24	.158
755-DTA114EUAT106	DTA114EUAT106	UMT-3	PNP	-50	-0.1	.36	.20	.133
755-DTA114TKAT146	DTA114TKAT146	SMT-3	PNP	-50	-0.1	.36	.20	.133
755-DTA114YKAT146	DTA114YKAT146	SMT-3	PNP	-50	-0.1	.36	.20	.133
755-DTA114YUAT106	DTA114YUAT106	UMT-3	PNP	-50	-0.1	.37	.22	.143
755-DTA115EKAT146	DTA115EKAT146	SMT-3	PNP	-50	-0.1	.39	.26	.177
755-DTA115EUAT106	DTA115EUAT106	UMT-3	PNP	-50	-0.1	.43	.29	.198
755-DTA123JETL	DTA123JETL	EMT-3	PNP	-50	-0.1	.43	.24	.158
755-DTA123JKAT146	DTA123JKAT146	SMT-3	PNP	-50	-0.1	.36	.20	.133
755-DTA124EKAT146	DTA124EKAT146	SMT-3	PNP	-50	-0.1	.36	.20	.133
755-DTA124EUAT106	DTA124EUAT106	UMT-3	PNP	-50	-0.1	.43	.25	.162
755-DTA143EETL	DTA143EETL	EMT-3	PNP	-50	-0.1	.43	.24	.158
755-DTA143EKAT146	DTA143EKAT146	SMT-3	PNP	-50	-0.1	.34	.20	.13
755-DTA143EUAT106	DTA143EUAT106	UMT-3	PNP	-50	-0.1	.43	.24	.158
755-DTA143ZKAT146	DTA143ZKAT146	SMT-3	PNP	-50	-0.1	.31	.18	.114
755-DTA144EKAT146	DTA144EKAT146	SMT-3	PNP	-50	-0.1	.36	.20	.133
755-DTA144EUAT106	DTA144EUAT106	UMT-3	PNP	-50	-0.1	.43	.24	.158
755-DTB113ZKT146	DTB113ZKT146	SMT-3	PNP	-50	-0.5	.44	.31	.229
755-DTB114EKT146	DTB114EKT146	SMT-3	PNP	-50	-0.5	.40	.30	.219
755-DTB123EKT146	DTB123EKT146	SMT-3	PNP	-50	-0.5	.40	.30	.219
755-DTB123YKT146	DTB123YKT146	SMT-3	PNP	-50	-0.5	.40	.30	.219
755-DTB143EKT146	DTB143EKT146	SMT-3	PNP	-50	-0.5	.44	.32	.228
755-FMG1AT148	FMG1AT148	SMT-5	NPNx2	50	0.1	.46	.35	.255
755-FMG2AT148	FMG2AT148	SMT-5	NPNx2	50	0.1	.42	.32	.234
755-IMH10AT110	IMH10AT110	SMT-6	NPNx2	50	0.1	.40	.26	.183
755-IMH11AT110	IMH11AT110	SMT-6	NPNx2	50	0.1	.64	.37	.243
755-IMH4AT110	IMH4AT110	SMT-6	NPNx2	50	0.1	.46	.33	.232
755-UMG2NTR	UMG2NTR	UMT-5	NPNx2	50	0.1	.38	.28	.198
755-UMG3NTR	UMG3NTR	UMT-5	NPNx2	50	0.1	.38	.27	.193
755-UMH9NTN	UMH9NTN	UMT-6	NPNx2	50	0.1	.38	.28	.198
755-EMD3T2R	EMD3T2R	EMT-6	NPN	50	0.05	.46	.33	.237
			PNP	-50	-0.05			
755-EMD6T2R	EMD6T2R	EMT-6	NPN	50	0.1	.46	.33	.237
			PNP	-50	-0.1			
755-EMD9T2R	EMD9T2R	EMT-6	NPN	50	0.1	.46	.33	.237
			PNP	-50	-0.1			
755-IMD2AT108	IMD2AT108	SMT-6	NPN	50	0.1	.44	.32	.228
			PNP	-50	-0.1			
755-IMD3AT108	IMD3AT108	SMT-6	NPN	50	0.1	.44	.32	.228
			PNP	-50	-0.1			
755-IMD9AT108	IMD9AT108	SMT-6	NPN	50	0.1	.44	.32	.228
			PNP	-50	-0.1			
755-UMD12NTR	UMD12NTR	UMT-6	NPN	50	0.1	.38	.28	.198
			PNP	-50	-0.1			
755-UMD22NTR	UMD22NTR	UMT-6	NPN	50	0.1	.37	.18	.132
			PNP	-50	-0.1			
755-UMD2NTR	UMD2NTR	UMT-6	NPN	50	0.1	.38	.28	.198
			PNP	-50	-0.1			
755-UMD3NTR	UMD3NTR	UMT-6	NPN	50	0.1	.43	.29	.202
			PNP	-50	-0.1			
755-UMD5NTR	UMD5NTR	UMT-6	NPN	50	0.1	.38	.27	.193
			PNP	-50	-0.1			
755-IMD10AT108	IMD10AT108	SMT-6	NPN	50	0.1	.55	.40	.285
			PNP					