

3M TOUCH SYSTEMS Multitouch Capacitive Displays *MicroTouch*

RoHS Compliant This product is RoHS compliant.

15" MICROTOUCH DISPLAY AND BASE

- Features:**
- Capacitive touch screen
 - All glass surface with 3M ClearTek hard coat
 - 91.5% light transmission
 - 225-nit brightness with touchscreen
 - Bolt down bottom mount
 - Peripheral attachment system
 - VESA mounting compatible, 75mm
 - Video Cable Connector: 15-pin D-Sub
 - Power Supply: 12VDC
 - Display Area WxH (mm): 304.1 x 228.1
 - Dimensions WxHxD (mm): 408 x 398 x 258.7
 - Frame Color: Black
- For quantities greater than listed, call for quote.**

| MOUSER STOCK NO. | 3M Touch Systems Part No. | Fig. | LCD Technology | Display Colors | Pixel Pitch (mm) | Contrast Ratio | Touch Response Time Typ. (ms) | Max Resolution | Controller | Price Each |
|------------------|---------------------------|------|--------------------|----------------|------------------|----------------|-------------------------------|----------------|------------|------------|
| 517-11-81375-225 | 11-81375-225 | A | TFT, Active Matrix | 16.2 Million | 0.297 x 0.297 | 500:1 | 5.4 | 1024x768 | USB | 543.99 |
| 517-11-81375-227 | 11-81375-227 | A | TFT, Active Matrix | 16.2 Million | 0.297 x 0.297 | 500:1 | 5.4 | 1024x768 | Serial | 543.99 |

17" MICROTOUCH DISPLAY AND BASE

- Features:**
- Capacitive touch screen
 - All glass surface with 3M ClearTek hard coat
 - 91.5% light transmission
 - 270-nit brightness with touchscreen
 - Peripheral attachment system
 - VESA mounting compatible, 100mm
 - Power Supply: 12VDC
 - Display Area WxH (mm): 337.9 x 270.3
 - Dimensions WxHxD (mm): 405 x 413.3 x 247
 - Frame Color: Black
- For quantities greater than listed, call for quote.**

| MOUSER STOCK NO. | 3M Touch Systems Part No. | Fig. | LCD Technology | Display Colors | Pixel Pitch (mm) | Contrast Ratio | Touch Response Time Typ. (ms) | Max Resolution | Controller | Price Each |
|------------------|---------------------------|------|--------------------|----------------|------------------|----------------|-------------------------------|----------------|------------|------------|
| 517-11-91378-225 | 11-91378-225 | B | TFT, Active Matrix | 16.2 Million | 0.264x0.264 | 800:1 | 5.4 | 1280x1024 | USB | 643.99 |
| 517-11-91378-227 | 11-91378-227 | B | TFT, Active Matrix | 16.2 Million | 0.264x0.264 | 800:1 | 5.4 | 1280x1024 | Serial | 643.99 |

15" MICROTOUCH DISPLAY

- Features:**
- Capacitive touch screen
 - All glass surface with 3M ClearTek hard coat
 - 91.5% light transmission
 - 225-nit brightness with touchscreen
 - VESA mounting compatible, 75mm
 - Set of 2 side or top/bottom mounting brackets
 - Slimline Bezel
 - Video Cable Connector: 15-pin D-Sub
 - Power Supply: 12VDC, 110/220VAC
 - Display Area WxH (mm): 304.1 x 228.1
 - Dimensions WxHxD (mm): 350.4 x 277.3 x 50
- For quantities greater than listed, call for quote.**

| MOUSER STOCK NO. | 3M Touch Systems Part No. | Fig. | LCD Technology | Display Colors | Pixel Pitch (mm) | Contrast Ratio | Touch Response Time Typ. (ms) | Max Resolution | Controller | Price Each |
|---------------------|---------------------------|------|--------------------|----------------|------------------|----------------|-------------------------------|----------------|------------|------------|
| 517-11-71315-225-01 | 11-71315-225-01 | C | TFT, Active Matrix | 16.2 Million | 0.297x0.297 | 500:1 | 5.4 | 1024x768 | USB | 510.99 |
| 517-11-71315-227-01 | 11-71315-227-01 | C | TFT, Active Matrix | 16.2 Million | 0.297x0.297 | 500:1 | 5.4 | 1024x768 | Serial | 510.99 |

17" MICROTOUCH DISPLAY

- Features:**
- Capacitive touch screen
 - All glass surface with 3M ClearTek hard coat
 - 91.5% light transmission
 - 225-nit brightness with touchscreen
 - VESA mounting compatible, 75mm
 - Set of 2 side or top/bottom mounting brackets
 - Video Cable Connector: 15-pin D-Sub
 - Power Supply: 12VDC
 - Display Area WxH (mm): 337.9 x 270.3
 - Dimensions WxHxD (mm): 405.7 x 335.1 x 49
- For quantities greater than listed, call for quote.**

| MOUSER STOCK NO. | 3M Touch Systems Part No. | Fig. | LCD Technology | Display Colors | Pixel Pitch (mm) | Contrast Ratio | Touch Response Time Typ. (ms) | Max Resolution | Controller | Price Each |
|--------------------|---------------------------|------|--------------------|----------------|------------------|----------------|-------------------------------|----------------|------------|------------|
| 517-11-4945-225-00 | 11-4945-225-00 | D | TFT, Active Matrix | 16.2 Million | 0.264x0.264 | 1000:1 | 5.4 | 1280x1024 | USB | 610.99 |
| 517-11-4945-227-00 | 11-4945-227-00 | D | TFT, Active Matrix | 16.2 Million | 0.264x0.264 | 1000:1 | 5.4 | 1280x1024 | Serial | 610.99 |

22" MULTITOUCH DISPLAY

- Features:**
- Capacitive touch screen
 - All glass surface with 3M ClearTek hard coat
 - 91.5% light transmission
 - 225-nit brightness with touchscreen
 - VESA Pattern: 100mm x 100mm
 - Video Input: DVI and VGA
 - Power Supply: 12VDC
 - Display Area WxH (mm): 473.8 x 296.1
 - Dimensions WxHxD (mm): 500 x 328.4 x 51.87
- For quantities greater than listed, call for quote.**

| MOUSER STOCK NO. | 3M Touch Systems Part No. | Fig. | LCD Technology | Display Colors | Pixel Pitch (mm) | Contrast Ratio | Touch Response Time Typ. (ms) | Max Resolution | Controller | Price Each |
|------------------|---------------------------|------|--------------------|----------------|------------------|----------------|-------------------------------|----------------|-------------|------------|
| 517-C2234SW | C2234SW | E | TFT, Active Matrix | 16.7 Million | 0.282 x 0.282 | 1000:1 | 5.4 | 1680x1050 | USB, Serial | 799.00 |

22" MULTITOUCH DISPLAY

- Features:**
- Projected capacitive matrix Touch Screen
 - 10 finger touch response
 - All glass surface with 3M ClearTek hard coat
 - Over 3300 touch sensing points
 - VESA Pattern: 100mm x 100mm
 - Video Input: DVI and VGA
 - Power Supply: 12VDC
 - Display Area WxH (mm): 473.8 x 296.1
 - Dimensions WxHxD (mm): 500 x 328.4 x 51.87
- For quantities greater than listed, call for quote.**

| MOUSER STOCK NO. | 3M Touch Systems Part No. | Fig. | LCD Technology | Display Colors | Pixel Pitch (mm) | Contrast Ratio | Touch Response Time Typ. (ms) | Max Resolution | Controller | Price Each |
|------------------|---------------------------|------|----------------|----------------|------------------|----------------|-------------------------------|----------------|-------------|------------|
| 517-C2254PW | C2254PW | F | P-MVA | 16.7 Million | 0.282 x 0.282 | 1000:1 | 12 | 1680x1050 | USB, Serial | 1499.00 |

22" MULTITOUCH DISPLAY AND BASE


- Features:**
- Projected capacitive matrix Touch Screen
 - 20+ finger touch response
 - All glass surface with 3M ClearTek hard coat
 - Over 3300 touch sensing points
 - Works with nitrile, latex, and vinyl gloves
 - VESA Pattern: 100mm x 100mm
 - Video Input: DVI(HDCP) and VGA
 - Power Supply: Internal 110/220VAC
 - Display Area WxH (mm): 473.8 x 296.1
 - Dimensions WxHxD (mm): 513.2 x 337.8 x 60.2
- For quantities greater than listed, call for quote.**

| MOUSER STOCK NO. | 3M Touch Systems Part No. | Fig. | LCD Technology | Display Colors | Pixel Pitch (mm) | Contrast Ratio | Touch Response Time Typ. (ms) | Max Resolution | Controller | Price Each |
|------------------|---------------------------|------|----------------|----------------|------------------|----------------|-------------------------------|----------------|-------------|------------|
| 517-M2256PW | M2256PW | G | P-MVA | 16.7 Million | 0.282 x 0.282 | 1000:1 | 6 | 1680x1050 | USB, Serial | 1599.00 |

HARDWARE

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | 3M Touch Systems Part No. | Description | Price Each |
|------------------|---------------------------|---|------------|
| 517-29368 | 29368 | Industrial Flange Bezel for CT150 Touch Monitor | 104.00 |
| 517-29369 | 29369 | Contour Flange Bezel for CT150 Touch Monitor | 32.50 |
| 517-5021104 | 5021104 | Industrial Flange Bezel for C1700SS Touch Monitor | 104.00 |

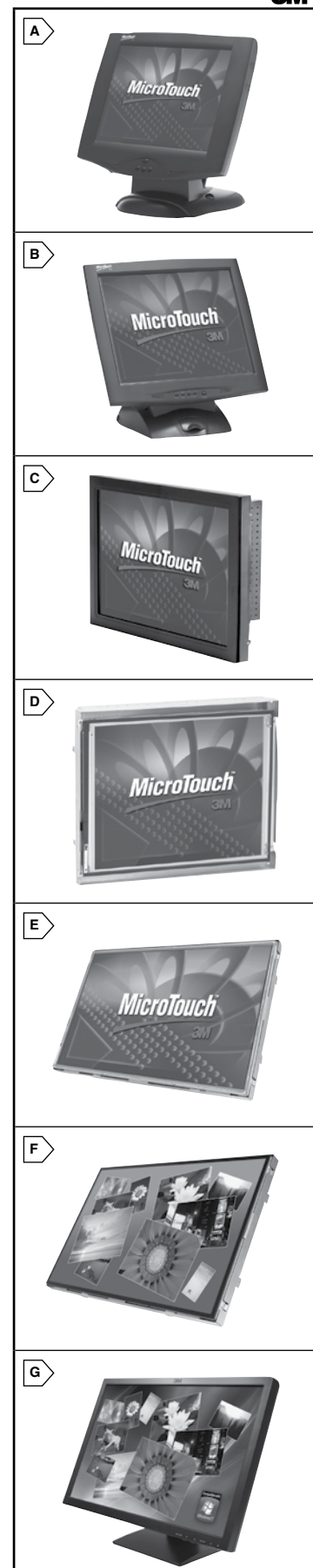

Displays 3M NEW TECHNOLOGY NEW TECHNOLOGY NEW TECHNOLOGY NEW TECHNOLOGY