


COOPER BUSSMANN Fuses

Products may be RoHS compliant. Check mouser.com for RoHS status.

COOPER Bussmann

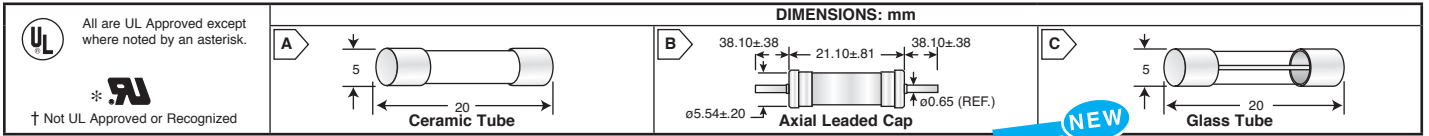

S505H SERIES TIME DELAY FUSES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amp (A)	Volt (V)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
504—BK1-S505H-1-R	A	1	250	1.09	1.05	1.03	
504—BK1-S505H-1-25-R	A	1.25	250	1.09	1.05	1.03	
504—BK1-S505H-1-6-R	A	1.6	250	1.09	1.05	1.03	
504—BK1-S505H-2-R	A	2	250	1.09	1.05	1.03	
504—BK1-S505H-2-5-R	A	2.5	250	1.09	1.05	1.03	
504—BK1-S505H-3-15-R	A	3.15	250	1.09	1.05	1.03	
504—BK1-S505H-4-R	A	4	250	1.09	1.05	1.03	
504—BK1-S505H-5-R	A	5	250	1.09	1.05	1.03	
504—BK1-S505H-6-3-R	A	6.3	250	1.09	1.05	1.03	

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amp (A)	Volt (V)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
504—BK1-S505H-8-R	A	8	250	1.45	1.39	1.36	
504—BK1-S505H-10-R	A	10	250	1.45	1.39	1.36	
504—BK1-S505H-500-R	A	500mA	250	1.09	1.05	1.03	
504—BK1-S505H-800-R	A	800mA	250	1.09	1.05	1.03	
504—BK-S505H-V-1-R	B	1	250	3.00	2.85	2.69	
504—BK-S505H-V-1-25R	B	1.25	250	3.00	2.85	2.69	
504—BK-S505H-V-1-6-R	B	1.6	250	3.00	2.85	2.69	
504—BK-S505H-V-2-R	B	2	250	3.00	2.85	2.69	
504—BK-S505H-V-2-5-R	B	2.5	250	3.00	2.85	2.69	

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amp (A)	Volt (V)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
504—BK-S505H-V-3-15R	B	3.15	250	3.00	2.85	2.69	
504—BK-S505H-V-4-R	B	4	250	3.00	2.85	2.69	
504—BK-S505H-V-5-R	B	5	250	3.00	2.85	2.69	
504—BK-S505H-V-6-3-R	B	6.3	250	3.00	2.85	2.69	
504—BK-S505H-V-8-R	B	8	250	3.98	3.81	3.59	
504—BK-S505H-V-10-R	B	10	250	3.98	3.72	3.53	
504—BK-S505H-V-500-R	B	500mA	250	3.00	2.85	2.69	
504—BK-S505H-V-800-R	B	800mA	250	3.00	2.85	2.69	

5MM X 20MM FUSES

GDA Series Fast-Acting/High Breaking Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amp (A)	Volt (V)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
504—GDA-50MA	A	.05	250	2.09	2.04	1.99	
504—GDA-100MA	A	.1	250	3.68	3.60	3.56	
504—GDA-160MA	A	.16	250	3.60	3.57	3.53	
504—GDA-200MA	A	.2	250	3.60	3.57	3.53	
504—GDA-250MA	A	.25	250	3.60	3.57	3.53	
504—GDA-315MA	A	.315	250	3.65	3.45	3.29	
504—GDA-500MA	A	.5	250	1.48	1.40	1.34	
504—GDA-630MA	A	.63	250	1.48	1.40	1.34	
504—GDA-800MA	A	.8	250	3.56	3.49	3.43	
504—GDA-1A	A	1	250	1.48	1.40	1.34	
504—GDA-1.25A	A	1.25	250	3.56	3.49	3.43	
504—GDA-1.6A	A	1.6	250	3.56	3.49	3.43	
504—GDA-2A	A	2	250	1.48	1.40	1.34	
504—GDA-2.5A	A	2.5	250	1.48	1.40	1.34	
504—GDA-3.15A	A	3.15	250	1.48	1.40	1.34	
504—GDA-4A	A	4	250	1.48	1.40	1.34	
504—GDA-5A	A	5	250	1.48	1.40	1.34	
504—GDA-6.3A	A	6.3	250	1.48	1.40	1.34	

GDB Series Fast-Acting/Low Breaking Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amp (A)	Volt (V)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
504—GDB-80MA	C	.08	250	1.61	1.54	1.44	
504—GDB-100MA	C	.1	250	1.61	1.54	1.44	
504—GDB-125MA	C	.125	250	1.61	1.54	1.44	
504—GDB-160MA	C	.16	250	.91	.876	.82	
504—GDB-315MA	C	.315	250	.91	.876	.82	
504—GDB-400MA	C	.4	250	.91	.876	.82	
504—GDB-500MA	C	.5	250	.21	.201	.188	
504—BK/S500-630-R	C	.63	250	.24	.23	.227	
504—GDB-800MA	C	.8	250	.21	.201	.188	
504—GDB-1A	C	1	250	.21	.201	.188	
504—GDB-1.25A	C	1.25	250	.21	.201	.188	
504—GDB-2A	C	2	250	.21	.201	.188	
504—GDB-2.5A	C	2.5	250	.21	.201	.188	
504—GDB-3.15A	C	3.15	250	.21	.201	.188	
504—GDB-4A	C	4	250	.21	.201	.188	
504—GDB-5A	C	5	250	.21	.201	.188	
504—GDB-6.3A	C	6.3	250	.21	.201	.188	
504—GDB-10	C	10	250	1.04	.996	.933	

GMC Series Medium Time-Delay Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amp (A)	Volt (V)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
504—GMC-125MA	C	1/8	250	2.10	2.00	1.89	
504—GMC-1/4	C	1/4	250	3.73	3.68	3.64	
504—GMC-1/2	C	1/2	250	2.48	2.37	2.34	
504—GMC-3/4	C	3/4	250	2.48	2.37	2.34	
504—GMC-8/10	C	8/10	250	1.41	1.31	1.19	
504—GMC-1	C	1	250	2.48	2.37	2.34	
504—GMC-2	C	2	250	2.48	2.37	2.34	
504—GMC-2-1/2	C	2 1/2	250	2.48	2.37	2.34	
504—GMC-3	C	3	250	2.48	2.37	2.34	
504—GMC-3-15	C	3-15/100	250	2.48	2.37	2.34	
504—GMC-3-1/2	C	3 1/2	125	.92	.87	.83	
504—GMC-4	C	4	125	2.48	2.37	2.34	
504—GMC-5	C	5	125	2.48	2.37	2.34	
504—GMC-6	C	6	125	2.48	2.37	2.34	
504—GMC-7	C	7	125	2.48	2.37	2.34	
* 504—GMC-8	C	8	125	2.48	2.37	2.34	
* 504—GMC-10	C	10	125	2.48	2.37	2.34	

GDC Series Time-Delay/Low Breaking Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amp (A)	Volt (V)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
504—GDC-V-50MA	C	.05	250	9.11	8.85	8.61	
504—GDC-63MA	C	.063	250	7.47	7.25	7.05	
504—GDC-100MA	C	.1	250	4.63	4.55	4.50	
504—GDC-V-100MA	C	0.1	250	6.05	5.88	5.72	
504—GDC-125MA	C	.125	250	4.83	4.77	4.70	
504—GDC-V-160MA	C	0.16	250	6.05	5.88	5.72	
504—GDC-200MA	C	.2	250	4.63	4.55	4.50	
504—GDC-250MA	C	.25	250	4.63	4.55	4.50	
504—GDC-500MA	C	.5	250	.81	.763	.724	
504—GDC-630MA	C	.63	250	.81	.763	.724	
504—GDC-800MA	C	.8	250	.81	.763	.724	
504—GDC-1A	C	1	250	.81	.763	.724	
504—GDC-1.25A	C	1.25	250	.81	.763	.724	
504—GDC-1.6A	C	1.6	250	.81	.763	.724	
504—GDC-2A	C	2	250	.81	.763	.724	
504—GDC-2.5A	C	2.5	250	.81	.763	.724	
504—GDC-3.15A	C	3.15	250	.81	.763	.724	
504—GDC-4A	C	4	250	.81	.763	.724	
504—GDC-5A	C	5	250	.81	.763	.724	
504—GDC-6.3A	C	6.3	250	.81	.763	.724	

GMA Series Fast-Acting Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amp (A)	Volt (V)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
504—BK/GMA-1-R	C	1	250	.35	.29	.26	
504—BK/GMA-1.25-R	C	1.25	250	.32	.301	.274	
504—BK/GMA-1.5-R	C	1.5	250	.32	.301	.274	
504—BK/GMA-1.6-R	C	1.6	250	.32	.301	.274	
504—BK/GMA-2-R	C	2	250	.35	.29	.26	
504—BK/GMA-2.5-R	C	2.5	250	.32	.301	.274	
504—BK/GMA-3-R	C	3	250	.35	.29	.26	
504—BK/GMA-3.15-R	C	3.15	125	.32	.301	.274	
504—BK/GMA-3.5-R	C	3.5	125	.32	.301	.274	
504—BK/GMA-4-R	C	4	125	.32	.301	.274	
504—BK/GMA-5-R	C	5	125	.32	.301	.274	
504—BK/GMA-6-R	C	6	125	.32	.301	.274	
504—BK/GMA-7-R	C	7	125	.32	.301	.274	
504—BK/GMA-8-R	C	8	125	.32	.301	.274	
504—BK/GMA-10-R	C	10	125	.35	.29	.26	
504—BK/GMA-63-R	C	63mA	250	1.58	1.46	1.33	
504—BK/GMA-100-R	C	100mA	250	.73	.668	.607	
504—BK/GMA-125-R	C	125mA	250	.73	.668	.607	
504—BK/GMA-200-R	C	200mA	250	.73	.668	.607	
504—BK/GMA-250-R	C	250mA	250	.73	.668	.607	
504—BK/GMA-300-R	C	300mA	250	.73	.668	.607	
504—BK/GMA-500-R	C	500mA	250	.43	.36	.327	
504—BK/GMA-750-R	C	750mA	250	.43	.37	.33	
504—BK/GMA-800-R	C	800mA	250	.43	.37	.33	

GMD Series Time-Delay/Low Breaking Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amp (A)	Volt (V)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
504—GMD-125MA	C	0.125	250	2.62	2.49	2.36	
504—GMD-150MA	C	0.15	250	2.62	2.49	2.36	
504—GMD-200MA	C	0.2	250	3.36	2.73	2.60	
504—GMD-250MA	C	0.25	250	4.44	4.36	4.29	
504—GMD-300	C	0.3	250	1.25	1.18	1.12	
504—GMD-315MA	C	0.315	250	4.44	4.36	4.29	
504—GMD-400MA	C	0.4	250	1.25	1.18	1.12	
504—GMD-500MA	C	0.5	250	2.61	2.54	2.51	
504—GMD-600MA	C	0.6	250	.96	.91	.86	
504—GMD-630MA	C	0.63	250	2.59	2.53	2.49	
504—GMD-750MA	C	0.75	250	.96	.91	.86	
504—GMD-800MA	C	0.8	250	2.59	2.53	2.49	
504—GMD-1A	C	1	250	2.61	2.54	2.51	
504—GMD-1.2A	C	1.2	250	.96	.91	.86	
504—GMD-1.25A	C	1.25	250	.96	.91	.86	
504—GMD-1.5A	C	1.5	250	2.61	2.54	2.51	
504—GMD-1.6A	C	1.6	250	1.14	.959	.845	
504—GMD-2A	C	2	250	2.61	2.54	2.51	
504—GMD-2.5A	C	2.5	250	1.14	.959	.845	
504—GMD-3A	C	3	250	2.61	2.54	2.51	

S50X SERIES FAST ACTING/TIME DELAY FUSES

MOUSER STOCK NO.		Fig.
------------------	--	------