


LITTELFUSE Fuses



RoHS Compliant This product is RoHS compliant.

DIMENSIONS: mm (in.)

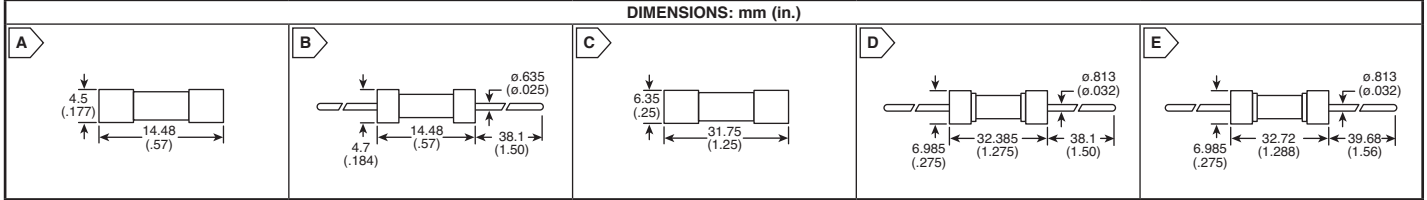

Littelfuse Fuses & Fuse Holders

LITTELFUSE 2AG FUSES (CONT.)

225 Series Fast-Acting Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0225.500HXP	0225.500HXP	A	0.5	250	.49	.45	.38	.34
576-0225.750HXP	0225.750HXP	A	0.75	250	.49	.45	.38	.34
576-0225001.HXP	0225001.HXP	A	1	250	.49	.45	.38	.34
576-022501.5HXP	022501.5HXP	A	1.5	250	.49	.45	.38	.34
576-0225002.HXP	0225002.HXP	A	2	250	.49	.45	.38	.34
576-022502.5HXP	022502.5HXP	A	2.5	250	.49	.45	.38	.34
576-0225003.HXP	0225003.HXP	A	3	250	.49	.45	.38	.34
576-022503.5HXP	022503.5HXP	A	3.5	250	.49	.45	.38	.34
576-0225004.HXUP	0225004.HXUP	A	4	125	.49	.46	.39	.35
576-0225005.HXUP	0225005.HXUP	A	5	125	.49	.46	.39	.35
576-0225006.HXUP	0225006.HXUP	A	6	125	.49	.46	.39	.35
576-0225007.HXUP	0225007.HXUP	A	7	125	.49	.46	.39	.35
576-0225008.HXUP	0225008.HXUP	A	8	125	.49	.46	.39	.35
576-0225010.HXUP	0225010.HXUP	A	10	125	.49	.46	.39	.35

229 Series Slo-Blo® Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0229.250HXP	0229.250HXP	A	0.25	250	.58	.53	.43	.40
576-0229.375HXP	0229.375HXP	A	0.375	250	.58	.53	.43	.40
576-0229.500HXP	0229.500HXP	A	0.5	250	.58	.53	.43	.40
576-0229001.HXP	0229001.HXP	A	1	250	.58	.53	.43	.40
576-02291.25HXP	02291.25HXP	A	1.25	250	.58	.53	.43	.40
576-022901.5HXP	022901.5HXP	A	1.5	250	.58	.53	.43	.40
576-0229002.HXP	0229002.HXP	A	2	250	.58	.53	.43	.40
576-0229003.HXP	0229003.HXP	A	3	250	.58	.53	.43	.40
576-022903.5HXP	022903.5HXP	A	3.5	250	.58	.53	.43	.40
576-0229004.HXP	0229004.HXP	A	4	125	.58	.53	.43	.40
576-0229005.HXP	0229005.HXP	A	5	125	.58	.53	.43	.40
576-0229007.HXP	0229007.HXP	A	7	125	.58	.53	.43	.40

230 Series (Axial Lead) Slo-Blo® Fuses

* Indicating Fuse

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0230.250HXP	0230.250HXP	B	0.25	250	.82	.70	.62	.57
*576-0230.250HXSP	0230.250HXSP	B	0.25	250	1.03	.969	.92	.855
576-0230.375HXP	0230.375HXP	B	0.375	250	.82	.70	.62	.57
576-0230.500HXP	0230.500HXP	B	0.5	250	.82	.70	.62	.57
576-0230.600HXP	0230.600HXP	B	0.6	250	.82	.70	.62	.57
576-0230001.HXP	0230001.HXP	B	1	250	.82	.70	.62	.57
576-02301.25HXP	02301.25HXP	B	1.25	250	.82	.70	.62	.57
576-023001.5HXP	023001.5HXP	B	1.5	250	.82	.70	.62	.57
576-0230002.HXP	0230002.HXP	B	2	250	.82	.70	.62	.57
*576-0230002.HXSP	0230002.HXSP	B	2	250	1.03	.969	.92	.855
576-0230002.5HXP	0230002.5HXP	B	2.5	250	.82	.70	.62	.57
576-0230003.HXP	0230003.HXP	B	3	250	.82	.70	.62	.57
576-023003.5HXP	023003.5HXP	B	3.5	250	.82	.70	.62	.57
576-0230004.HXP	0230004.HXP	B	4	125	.82	.70	.62	.57
576-0230005.HXP	0230005.HXP	B	5	125	.82	.70	.62	.57
*576-0230005.HXSP	0230005.HXSP	B	5	125	1.03	.969	.92	.855
576-0230006.DRT2P	0230006.DRT2P	B	6	125	1.00	.93	.81	.74
576-0230007.HXP	0230007.HXP	B	7	125	.82	.70	.62	.57
*576-0230007.HXSP	0230007.HXSP	B	7	125	1.03	.969	.92	.855

LITTELFUSE 3AG FUSES

312 Series Fast-Acting Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0312.062HXP	0312.062HXP	C	0.062	250	1.74	1.62	1.34	1.23
576-0312.100HXP	0312.100HXP	C	0.1	250	1.74	1.62	1.34	1.23
576-0312.125HXP	0312.125HXP	C	0.125	250	1.00	.84	.77	.71
576-0312.175HXP	0312.175HXP	C	0.175	250	1.00	.84	.77	.71
576-0312.187HXP	0312.187HXP	C	0.187	250	1.00	.84	.77	.71
576-0312.200HXP	0312.200HXP	C	0.2	250	1.00	.84	.77	.71
576-0312.250HXP	0312.250HXP	C	0.25	250	1.00	.84	.77	.71
576-0312.300HXP	0312.300HXP	C	0.3	250	1.00	.84	.77	.71
576-0312.375HXP	0312.375HXP	C	0.375	250	.29	.27	.23	.21
576-0312.500HXP	0312.500HXP	C	0.5	250	.29	.27	.23	.21
576-0312.600HXP	0312.600HXP	C	0.6	250	.29	.27	.23	.21
576-0312.750HXP	0312.750HXP	C	0.75	250	.29	.27	.23	.21
576-0312001.HXP	0312001.HXP	C	1	250	.29	.27	.23	.21
576-03121.25HXP	03121.25HXP	C	1.25	250	.29	.27	.23	.21
576-031201.5HXP	031201.5HXP	C	1.5	250	.29	.27	.23	.21
576-0312002.HXP	0312002.HXP	C	2	250	.29	.27	.23	.21
576-031202.5HXP	031202.5HXP	C	2.5	250	.29	.27	.23	.21
576-0312003.HXP	0312003.HXP	C	3	250	.29	.27	.23	.21
576-0312004.HXP	0312004.HXP	C	4	250	.29	.27	.23	.21
576-0312005.HXP	0312005.HXP	C	5	250	.29	.27	.23	.21
576-0312006.HXP	0312006.HXP	C	6	250	.29	.27	.23	.21
576-0312007.HXP	0312007.HXP	C	7	250	.29	.27	.23	.21
576-0312008.HXP	0312008.HXP	C	8	250	.29	.27	.23	.21
576-0312010.HXP	0312010.HXP	C	10	250	.29	.27	.23	.21

LITTELFUSE 3AG FUSES (CONT.)

313 Series Slo-Blo® Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0313.031HXP	0313.031HXP	C	0.031	250	3.85	3.35	3.00	2.57
576-0313.040HXP	0313.040HXP	C	0.04	250	3.85	3.35	3.00	2.57
576-0313.062HXP	0313.062HXP	C	0.062	250	1.85	1.74	1.41	1.30
576-0313.100HXP	0313.100HXP	C	0.1	250	1.85	1.74	1.41	1.30
576-0313.125HXP	0313.125HXP	C	0.125	250	1.85	1.74	1.41	1.30
576-0313.150HXP	0313.150HXP	C	0.15	250	1.85	1.74	1.41	1.30
576-0313.187HXP	0313.187HXP	C	0.187	250	1.06	1.00	.81	.76
576-0313.200HXP	0313.200HXP	C	0.2	250	1.06	1.00	.81	.76
576-0313.250HXP	0313.250HXP	C	0.25	250	1.06	1.00	.81	.76
576-0313.300HXP	0313.300HXP	C	0.3	250	1.06	1.00	.81	.76
576-0313.375HXP	0313.375HXP	C	0.375	250	1.06	1.00	.81	.76
576-0313.400HXP	0313.400HXP	C	0.4	250	1.06	1.00	.81	.76
576-0313.700HXP	0313.700HXP	C	0.7	250	.82	.70	.62	.57
576-0313.750HXP	0313.750HXP	C	0.75	250	.82	.70	.62	.57
576-0313.800HXP	0313.800HXP	C	0.8	250	.82	.70	.62	.57
576-0313001.HXP	0313001.HXP	C	1	250	.82	.70	.62	.57
576-031301.2HXP	031301.2HXP	C	1.2	250	.82	.70	.62	.57
576-03131.25HXP	03131.25HXP	C	1.25	250	.82	.70	.62	.57
576-031301.5HXP	031301.5HXP	C	1.5	250	.82	.70	.62	.57
576-031301.6HXP	031301.6HXP	C	1.6	250	.82	.70	.62	.57
576-0313002.HXP	0313002.HXP	C	2	250	.82	.70	.62	.57
576-031302.5HXP	031302.5HXP	C	2.5	250	.82	.70	.62	.57
576-0313003.HXP	0313003.HXP	C	3	250	.82	.70	.62	.57
576-031303.2HXP	031303.2HXP	C	3.2	250	.82	.70	.62	.57
576-0313004.HXP	0313004.HXP	C	4	250	.93	.87	.75	.68
576-0313005.HXP	0313005.HXP	C	5	250	.93	.87	.75	.68
576-03136.25HXP	03136.25HXP	C	6.25	250	.93	.87	.75	.68
576-031306.3HXP	031306.3HXP	C	6.3	250	.93	.87	.75	.68
576-0313007.HXP	0313007.HXP	C	7	250	.93	.87	.75	.68
576-0313008.HXP	0313008.HXP	C	8	250	.93	.87	.75	.68
576-0313010.HXP	0313010.HXP	C	10	32	.93	.87	.75	.68
576-0313012.HXP	0313012.HXP	C	12	32	.93	.87	.75	.68
576-0313015.HXP	0313015.HXP	C	15	32	.93	.87	.75	.68
576-0313020.HXP	0313020.HXP	C	20	32	1.18	1.10	.90	.83
576-0313025.HXP	0313025.HXP	C	25	32	1.18	1.10	.90	.83
576-0313030.HXP	0313030.HXP	C	30	32	1.18	1.10	.90	.83

315 Series Slo-Blo® Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0315.500HXP	0315.500HXP	D	0.5	250	1.28	1.21	.94	.89
576-0315001.HXP	0315001.HXP	D	1	250	1.28	1.21	.94	.89
576-031501.5HXP	031501.5HXP	D	1.5	250	1.28	1.21	.94	.89
576-0315002.HXP	0315002.HXP	D	2	250	1.28	1.21	.94	.89
576-0315003.HXP	0315003.HXP	D	3	250	1.28	1.21	.94	.89
576-0315005.HXP	0315005.HXP	D	5	250	1.28	1.21	.94	.89
576-0315008.HXP	0315008.HXP	D	8	250	1.28	1.21	.94	.89
576-0315010.HXP	0315010.HXP	D	10	32	1.28	1.21	.94	.89
576-0315015.HXP	0315015.HXP	D	15	32	1.28	1.21	.94	.89