

LITTELFUSE Fuses



RoHS Compliant This product is RoHS compliant.

251L SERIES PICO® II FAST-ACTING SUBMINIATURE FUSES, AXIAL LEAD



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0251.062MXL	0251.062MXL	A	0.062	125	1.08	.90	.75	.67
576-0251.125MXL	0251.125MXL	A	0.125	125	.60	.55	.46	.42
576-0251.250MXL	0251.250MXL	A	0.25	125	.60	.55	.46	.42
576-0251.375MXL	0251.375MXL	A	0.375	125	.60	.55	.46	.42
576-0251.500MAT1L	0251.500MAT1L	A	0.5	125	.57	.54	.46	.41
576-0251.750MAT1L	0251.750MAT1L	A	0.75	125	.57	.54	.46	.41
576-0251001.MXL	0251001.MXL	A	1	125	.50	.47	.40	.355
576-02511.25MXL	02511.25MXL	A	1.25	125	.50	.47	.40	.355
576-025101.5MXL	025101.5MXL	A	1.5	125	.50	.47	.40	.355
576-0251002.MXL	0251002.MXL	A	2	125	.50	.47	.40	.355
576-025102.5MXL	025102.5MXL	A	2.5	125	.50	.47	.40	.355
576-0251003.MXL	0251003.MXL	A	3	125	.50	.47	.40	.355
576-025103.5MXL	025103.5MXL	A	3.5	125	.50	.47	.40	.355
* 576-0251004.MRT1L	0251004.MRT1L	A	4	125	.57	.54	.46	.41
* 576-0251005.MXL	0251005.MXL	A	5	125	.50	.47	.40	.355
* 576-0251007.MXL	0251007.MXL	A	7	125	.50	.47	.40	.355
* 576-0251010.MXL	0251010.MXL	A	10	125	.50	.47	.40	.355
* 576-0251012.MRT1L	0251012.MRT1L	A	12	32	.60	.575	.545	.515
* 576-0251015.MRT1L	0251015.MRT1L	A	15	32	.60	.575	.545	.515

* Tape and Reel

263 SERIES PICO® II VERY FAST-ACTING SUBMINIATURE FUSES



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0263.062MXL	0263.062MXL	B	0.062	250	2.09	1.94	1.63	1.57
576-0263.125MXL	0263.125MXL	B	0.125	250	1.72	1.56	1.28	1.17
576-0263.250MXL	0263.250MXL	B	0.25	250	1.72	1.56	1.28	1.17
576-0263.375MXL	0263.375MXL	B	0.375	250	1.72	1.56	1.28	1.17
576-0263.500MXL	0263.500MXL	B	0.5	250	1.72	1.56	1.28	1.17
576-0263.750MXL	0263.750MXL	B	0.75	250	1.41	1.32	1.08	.99
576-0263001.MXL	0263001.MXL	B	1	250	1.41	1.32	1.08	.99
576-026301.5MXL	026301.5MXL	B	1.5	250	1.41	1.32	1.08	.99
576-0263002.MXL	0263002.MXL	B	2	250	1.41	1.32	1.08	.99
576-026302.5MXL	026302.5MXL	B	2.5	250	1.41	1.32	1.08	.99
576-0263003.MXL	0263003.MXL	B	3	250	1.41	1.32	1.08	.99
576-026303.5MXL	026303.5MXL	B	3.5	250	1.41	1.32	1.08	.99
576-0263004.MXL	0263004.MXL	B	4	250	1.41	1.32	1.08	.99
576-0263005.MXL	0263005.MXL	B	5	250	1.41	1.32	1.08	.99

473 SERIES PICO® II SLO-BLO SUBMINIATURE FUSES



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
* 576-0473.375MRT1L	0473.375MRT1L	A	0.375	125	1.26	1.20	1.14	1.08
* 576-0473.500MRT1L	0473.500MRT1L	A	0.5	125	1.26	1.20	1.14	1.08
* 576-0473.750MRT1L	0473.750MRT1L	A	0.75	125	1.26	1.20	1.14	1.08
* 576-0473001.MRT1L	0473001.MRT1L	A	1	125	1.26	1.20	1.14	1.08
* 576-047301.5MRT1L	047301.5MRT1L	A	1.5	125	1.26	1.20	1.14	1.08
* 576-0473002.MRT1L	0473002.MRT1L	A	2	125	1.26	1.20	1.14	1.08
* 576-04732.25MRT1L	04732.25MRT1L	A	2.25	125	1.26	1.20	1.14	1.08
* 576-047302.5MRT1L	047302.5MRT1L	A	2.5	125	1.26	1.20	1.14	1.08
* 576-0473003.MRT1L	0473003.MRT1L	A	3	125	1.26	1.20	1.14	1.08
* 576-047303.5MRT1L	047303.5MRT1L	A	3.5	125	1.26	1.20	1.14	1.08
* 576-0473004.MRT1L	0473004.MRT1L	A	4	125	1.26	1.20	1.14	1.08
* 576-0473005.MRT1L	0473005.MRT1L	A	5	125	1.26	1.20	1.14	1.08
* 576-0473007.MRT1L	0473007.MRT1L	A	7	125	1.26	1.20	1.14	1.08

* Tape and Reel

273 SERIES MICRO™ FUSE VERY FAST-ACTING SUBMINIATURE FUSES



Developed originally for the U.S. Space Program, MICRO fuse provides reliability in a compact design.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0273.031V	0273.031V	C	0.031	125	25.65	24.39	23.14	21.88
576-0273.050H	0273.050H	C	0.05	125	4.97	4.62	3.97	3.67
576-0273.062V	0273.062V	C	0.062	125	6.83	6.49	6.16	5.82
576-0273.125H	0273.125H	C	0.125	125	4.90	4.50	3.90	3.34
576-0273.250H	0273.250H	C	0.25	125	4.90	4.50	3.90	3.34
576-0273.500H	0273.500H	C	0.5	125	4.90	4.50	3.90	3.34
576-0273001.H	0273001.H	C	1	125	4.90	4.50	3.90	3.34
576-027301.5H	027301.5H	C	1.5	125	4.90	4.50	3.90	3.34
576-0273002.H	0273002.H	C	2	125	4.90	4.50	3.90	3.34
576-0273003.H	0273003.H	C	3	125	4.90	4.50	3.90	3.34
576-0273004.H	0273004.H	C	4	125	4.90	4.50	3.90	3.34
576-0273005.H	0273005.H	C	5	125	4.90	4.50	3.90	3.34

257 SERIES AUTOFUSE ATO® FAST-ACTING BLADE FUSES


Designed and originated by Littelfuse for the automotive industry, the ATO® fuse has become the original equipment circuit protection standard for foreign and domestic automobiles and trucks. Readily identifiable and easily replaced, this fuse can be specified for a variety of low voltage electronic applications. The ATO® series is rated to 85°C ambient.



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0287020.PXCN	0287020.PXCN	D	20	32	.66	.628	.594	.56
576-0287030.PXCN	0287030.PXCN	D	30	32	.92	.84	.67	.61

© Copyright 2012 Mouser Electronics

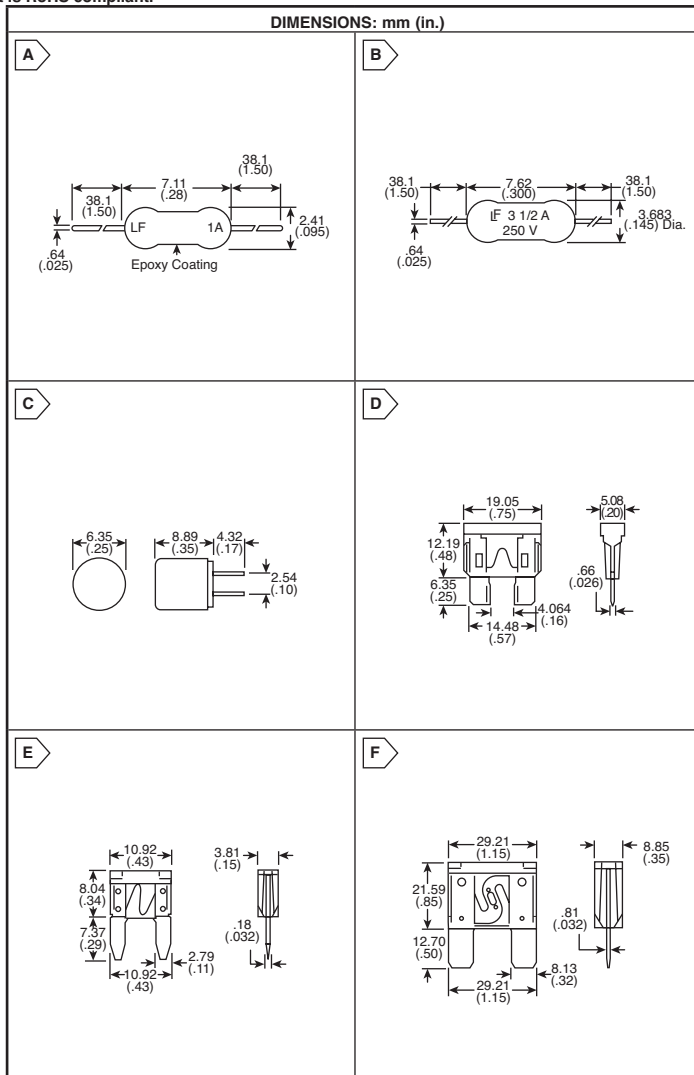

297 SERIES AUTOFUSE MINI® FAST-ACTING

The MINI® fuse has become the industry standard blade fuse for engine compartment locations requiring a 125°C temperature rating.



- Materials: plastic body, silver plated terminals
- Voltage rating: 32V

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0297002.WXNV	0297002.WXNV	E	2	32	.66	.60	.496	.472
576-0297003.WXNV	0297003.WXNV	E	3	32	.66	.60	.496	.472
576-0297004.WXNV	0297004.WXNV	E	4	32	.66	.60	.496	.472
576-0297005.WXNV	0297005.WXNV	E	5	32	.66	.60	.496	.472
576-029707.5WXNV	029707.5WXNV	E	7.5	32	.66	.60	.496	.472
576-0297010.WXNV	0297010.WXNV	E	10	32	.66	.60	.496	.472
576-0297015.WXNV	0297015.WXNV	E	15	32	.66	.60	.496	.472
576-0297020.WXNV	0297020.WXNV	E	20	32	.66	.60	.496	.472
576-0297025.WXNV	0297025.WXNV	E	25	32	.66	.60	.496	.472
576-0297030.WXNV	0297030.WXNV	E	30	32	.66	.60	.496	.472

299 SERIES MAXI® SLO-BLO® AUTOMOTIVE BLADE FUSES

Designed and originated by Littelfuse for the automotive industry, the MAXI® fuse has become the original equipment circuit protection standard for foreign and domestic automobiles and trucks. The MAXI® series is rated to 125°C ambient.



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0299020.ZXNV	0299020.ZXNV	F	20	32	1.62	1.53	1.26	1.10
576-0299025.ZXNV	0299025.ZXNV	F	25	32	1.62	1.53	1.26	1.10
576-0299030.ZXNV	0299030.ZXNV	F	30	32	1.62	1.53	1.26	1.10
576-0299035.ZXNV	0299035.ZXNV	F	35	32	1.62	1.53	1.26	1.10
576-0299040.ZXNV	0299040.ZXNV	F	40	32	1.62	1.53	1.26	1.10
576-0299050.ZXNV	0299050.ZXNV	F	50	32	1.62	1.53	1.26	1.10
576-0299060.ZXNV	0299060.ZXNV	F	60	32	1.62	1.53	1.26	1.10
576-0299070.ZXNV	0299070.ZXNV	F	70	32	2.95	2.75	2.26	2.09
576-0299080.ZXNV	0299080.ZXNV	F	80	32	2.95	2.75	2.26	2.09

© Copyright 2012 Mouser Electronics