



PANASONIC Thick Film Chip Resistors

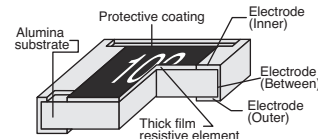

Type (Case Size)	DIMENSIONS: mm					Power Rating (Watts)
	L	W	a	b	t	
ERJ-T06 (0805)	2.00±0.20	1.25±0.10	0.25±0.20	0.40±0.20	0.60±0.10	0.25
ERJ-T08 (1206)	3.20 +0.05/-0.20	1.60 +0.05/-0.15	0.40±0.20	0.50±0.20	0.60±0.10	0.33
ERJ-T14 (1210)	3.20±0.20	2.50±0.20	0.35±0.20	0.50±0.20	0.60±0.10	0.5
ERJ-TRQF (2512)	6.40±0.20	3.20±0.20	0.65±0.20	0.60±0.20	0.60±0.10	1
ERJ-XGNJ (1005)	3.20±0.20	2.50±0.20	0.50±0.20	0.50±0.20	0.60±0.10	0.031

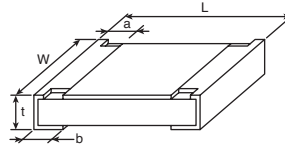

ERJ-T06, ERJ-T08, ERJ-T14, ERJ-1TRQF, AND ERJ-XGNJ SERIES THICK FILM CHIP RESISTORS

- Features:**
- High reliability: Metal glaze thick film resistive element and three layers of electrodes
 - Suitable for both reflow and flow soldering

MOUSER STOCK NO.	Panasonic Part No.	Value (Ω)	Price Each			Reel Qty.	Price Per Piece
			1	100	500		
0805 Case Size - ERJ-T06 Series							
667-ERJ-T06J1R0V	ERJ-T06J1R0V	1	.33	.101	.055	5000	.022
667-ERJ-T06J1R2V	ERJ-T06J1R2V	1.2	.33	.101	.055	5000	.022
667-ERJ-T06J1R5V	ERJ-T06J1R5V	1.5	.33	.101	.055	5000	.022
667-ERJ-T06J1R8V	ERJ-T06J1R8V	1.8	.33	.101	.055	5000	.022
667-ERJ-T06J3R9V	ERJ-T06J3R9V	3.9	.33	.101	.055	5000	.022
667-ERJ-T06J4R7V	ERJ-T06J4R7V	4.7	.33	.101	.055	5000	.022
667-ERJ-T06J6R8V	ERJ-T06J6R8V	6.8	.33	.101	.055	5000	.022
667-ERJ-T06J8R2V	ERJ-T06J8R2V	8.2	.33	.101	.055	5000	.022
667-ERJ-T06J100V	ERJ-T06J100V	10	.33	.101	.055	5000	.022
667-ERJ-T06J150V	ERJ-T06J150V	15	.33	.101	.055	5000	.022
667-ERJ-T06J180V	ERJ-T06J180V	18	.33	.101	.055	5000	.022
667-ERJ-T06J220V	ERJ-T06J220V	22	.33	.101	.055	5000	.022
667-ERJ-T06J560V	ERJ-T06J560V	56	.33	.101	.055	5000	.022
667-ERJ-T06J820V	ERJ-T06J820V	82	.33	.101	.055	5000	.022
667-ERJ-T06J181V	ERJ-T06J181V	180	.33	.101	.055	5000	.022
667-ERJ-T06J331V	ERJ-T06J331V	330	.33	.101	.055	5000	.022
667-ERJ-T06J391V	ERJ-T06J391V	390	.33	.101	.055	5000	.022
667-ERJ-T06J471V	ERJ-T06J471V	470	.33	.101	.055	5000	.022
667-ERJ-T06J681V	ERJ-T06J681V	680	.33	.101	.055	5000	.022
667-ERJ-T06J102V	ERJ-T06J102V	1.0K	.33	.101	.055	5000	.022
667-ERJ-T06J122V	ERJ-T06J122V	1.2K	.33	.101	.055	5000	.022
667-ERJ-T06J152V	ERJ-T06J152V	1.5K	.33	.101	.055	5000	.022
667-ERJ-T06J182V	ERJ-T06J182V	1.8K	.33	.101	.055	5000	.022
667-ERJ-T06J272V	ERJ-T06J272V	2.7K	.33	.101	.055	5000	.022
667-ERJ-T06J332V	ERJ-T06J332V	3.3K	.33	.101	.055	5000	.022
667-ERJ-T06J562V	ERJ-T06J562V	5.6K	.33	.101	.055	5000	.022
667-ERJ-T06J822V	ERJ-T06J822V	8.2K	.33	.101	.055	5000	.022
667-ERJ-T06J273V	ERJ-T06J273V	27K	.33	.101	.055	5000	.022
667-ERJ-T06J683V	ERJ-T06J683V	68K	.33	.101	.055	5000	.022
667-ERJ-T06J474V	ERJ-T06J474V	470K	.33	.101	.055	5000	.022
667-ERJ-T06J684V	ERJ-T06J684V	680K	.33	.101	.055	5000	.022
667-ERJ-T06J105V	ERJ-T06J105V	1M	.33	.101	.055	5000	.022
1206 Case Size - ERJ-T08 Series							
667-ERJ-T08J1R0V	ERJ-T08J1R0V	1	.08	.035	.028	5000	.022
667-ERJ-T08J1R2V	ERJ-T08J1R2V	1.2	.08	.035	.028	5000	.022
667-ERJ-T08J1R5V	ERJ-T08J1R5V	1.5	.08	.035	.028	5000	.022
667-ERJ-T08J1R8V	ERJ-T08J1R8V	1.8	.08	.035	.028	5000	.022
667-ERJ-T08J2R7V	ERJ-T08J2R7V	2.7	.08	.035	.028	5000	.022
667-ERJ-T08J3R3V	ERJ-T08J3R3V	3.3	.08	.035	.028	5000	.022
667-ERJ-T08J3R9V	ERJ-T08J3R9V	3.9	.08	.035	.028	5000	.022
667-ERJ-T08J4R7V	ERJ-T08J4R7V	4.7	.08	.035	.028	5000	.022
667-ERJ-T08J5R6V	ERJ-T08J5R6V	5.6	.08	.035	.028	5000	.022
667-ERJ-T08J6R8V	ERJ-T08J6R8V	6.8	.08	.035	.028	5000	.022
667-ERJ-T08J120V	ERJ-T08J120V	12	.08	.035	.028	5000	.022
667-ERJ-T08J220V	ERJ-T08J220V	22	.08	.035	.028	5000	.022
667-ERJ-T08J270V	ERJ-T08J270V	27	.08	.035	.028	5000	.022
667-ERJ-T08J330V	ERJ-T08J330V	33	.08	.035	.028	5000	.022
667-ERJ-T08J390V	ERJ-T08J390V	39	.08	.035	.028	5000	.022
667-ERJ-T08J560V	ERJ-T08J560V	56	.08	.035	.028	5000	.022
667-ERJ-T08J101V	ERJ-T08J101V	100	.08	.035	.028	5000	.022
667-ERJ-T08J181V	ERJ-T08J181V	180	.08	.035	.028	5000	.022
667-ERJ-T08J331V	ERJ-T08J331V	330	.08	.035	.028	5000	.022
667-ERJ-T08J391V	ERJ-T08J391V	390	.08	.035	.028	5000	.022
667-ERJ-T08J471V	ERJ-T08J471V	470	.08	.035	.028	5000	.022
667-ERJ-T08J561V	ERJ-T08J561V	560	.08	.035	.028	5000	.022
667-ERJ-T08J122V	ERJ-T08J122V	1.2K	.08	.035	.028	5000	.022
667-ERJ-T08J152V	ERJ-T08J152V	1.5K	.08	.035	.028	5000	.022
667-ERJ-T08J222V	ERJ-T08J222V	2.2K	.08	.035	.028	5000	.022
667-ERJ-T08J272V	ERJ-T08J272V	2.7K	.08	.035	.028	5000	.022
667-ERJ-T08J472V	ERJ-T08J472V	4.7K	.08	.035	.028	5000	.022
667-ERJ-T08J562V	ERJ-T08J562V	5.6K	.08	.035	.028	5000	.022
667-ERJ-T08J103V	ERJ-T08J103V	10K	.08	.035	.028	5000	.022
667-ERJ-T08J223V	ERJ-T08J223V	22K	.08	.035	.028	5000	.022
667-ERJ-T08J273V	ERJ-T08J273V	27K	.08	.035	.028	5000	.022
2512 Case Size - ERJ-1TRQF Series							
667-ERJ-1TRQFR22U	ERJ-1TRQFR22U	0.22	.66	.285	.229	4000	.194
667-ERJ-1TRQFR27U	ERJ-1TRQFR27U	0.27	.66	.285	.229	4000	.194
667-ERJ-1TRQFR33U	ERJ-1TRQFR33U	0.33	.66	.285	.229	4000	.194
667-ERJ-1TRQFR39U	ERJ-1TRQFR39U	0.39	.66	.285	.229	4000	.194
667-ERJ-1TRQFR47U	ERJ-1TRQFR47U	0.47	.66	.285	.229	4000	.194
667-ERJ-1TRQFR56U	ERJ-1TRQFR56U	0.56	.66	.285	.229	4000	.194
667-ERJ-1TRQFR68U	ERJ-1TRQFR68U	0.68	.66	.285	.229	4000	.194
667-ERJ-1TRQFR82U	ERJ-1TRQFR82U	0.82	.66	.285	.229	4000	.194
667-ERJ-1TRQF1R0U	ERJ-1TRQF1R0U	1	.66	.285	.229	4000	.194
667-ERJ-1TRQF1R2U	ERJ-1TRQF1R2U	1.2	.66	.285	.229	4000	.194
667-ERJ-1TRQF1R5U	ERJ-1TRQF1R5U	1.5	.66	.285	.229	4000	.194
667-ERJ-1TRQF1R8U	ERJ-1TRQF1R8U	1.8	.66	.285	.229	4000	.194
667-ERJ-1TRQF2R2U	ERJ-1TRQF2R2U	2.2	.66	.285	.229	4000	.194
667-ERJ-1TRQF2R7U	ERJ-1TRQF2R7U	2.7	.66	.285	.229	4000	.194
667-ERJ-1TRQF3R3U	ERJ-1TRQF3R3U	3.3	.66	.285	.229	4000	.194
667-ERJ-1TRQF3R9U	ERJ-1TRQF3R9U	3.9	.66	.285	.229	4000	.194
667-ERJ-1TRQF4R7U	ERJ-1TRQF4R7U	4.7	.66	.285	.229	4000	.194
667-ERJ-1TRQF5R6U	ERJ-1TRQF5R6U	5.6	.66	.285	.229	4000	.194
667-ERJ-1TRQF6R8U	ERJ-1TRQF6R8U	6.8	.66	.285	.229	4000	.194
667-ERJ-1TRQF8R2U	ERJ-1TRQF8R2U	8.2	.66	.285	.229	4000	.194
1005 Case Size - ERJ-XGNJ Series							
667-ERJ-XGNJ100Y	ERJ-XGNJ100Y	10	.35	.118	.093	20000	.033
667-ERJ-XGNJ220Y	ERJ-XGNJ220Y	22	.35	.118	.093	20000	.033
667-ERJ-XGNJ330Y	ERJ-XGNJ330Y	33	.35	.118	.093	20000	.033
667-ERJ-XGNJ470Y	ERJ-XGNJ470Y	47	.35	.118	.093	20000	.033
667-ERJ-XGNJ560Y	ERJ-XGNJ560Y	56	.35	.118	.093	20000	.033
667-ERJ-XGNJ750Y	ERJ-XGNJ750Y	75	.35	.118	.093	20000	.033
667-ERJ-XGNJ101Y	ERJ-XGNJ101Y	100	.35	.118	.093	20000	.033
667-ERJ-XGNJ221Y	ERJ-XGNJ221Y	220	.35	.118	.093	20000	.033
667-ERJ-XGNJ331Y	ERJ-XGNJ331Y	330	.35	.118	.093	20000	.033
667-ERJ-XGNJ471Y	ERJ-XGNJ471Y	470	.35	.118	.093	20000	.033
667-ERJ-XGNJ561Y	ERJ-XGNJ561Y	560	.35	.118	.093	20000	.033
667-ERJ-XGNJ751Y	ERJ-XGNJ751Y	750	.35	.118	.093	20000	.033
667-ERJ-XGNJ102Y	ERJ-XGNJ102Y	1.0K	.35	.118	.093	20000	.033
667-ERJ-XGNJ222Y	ERJ-XGNJ222Y	2.2K	.35	.118	.093	20000	.033
667-ERJ-XGNJ332Y	ERJ-XGNJ332Y	3.3K	.35	.118	.093	20000	.033
667-ERJ-XGNJ472Y	ERJ-XGNJ472Y	4.7K	.35	.118	.093	20000	.033
667-ERJ-XGNJ562Y	ERJ-XGNJ562Y	5.6K	.35	.118	.093	20000	.033
667-ERJ-XGNJ752Y	ERJ-XGNJ752Y	7.5K	.35	.118	.093	20000	.033
667-ERJ-XGNJ103Y	ERJ-XGNJ103Y	10K	.35	.118	.093	20000	.033
667-ERJ-XGNJ223Y	ERJ-XGNJ223Y	22K	.35	.118	.093	20000	.033
667-ERJ-XGNJ333Y	ERJ-XGNJ333Y	33K	.35	.118	.093	20000	.033
667-ERJ-XGNJ473Y	ERJ-XGNJ473Y	47K	.35	.118	.093	20000	.033
667-ERJ-XGNJ563Y	ERJ-XGNJ563Y	56K	.35	.118	.093	20000	.033
667-ERJ-XGNJ753Y	ERJ-XGNJ753Y	75K	.35	.118	.093	20000	.033
667-ERJ-XGNJ104Y	ERJ-XGNJ104Y	100K	.35	.118	.093	20000	.033
667-ERJ-XGNJ224Y	ERJ-XGNJ224Y	220K	.35	.118	.093	20000	.033
667-ERJ-XGNJ334Y	ERJ-XGNJ334Y	330K	.35	.118	.093	20000	.033
667-ERJ-XGNJ474Y	ERJ-XGNJ474Y	470K	.35	.118	.093	20000	.033
667-ERJ-XGNJ564Y	ERJ-XGNJ564Y	560K	.35	.118	.093	20000	.033
667-ERJ-XGNJ754Y	ERJ-XGNJ754Y	750K	.35	.118	.093	20000	.033
667-ERJ-XGNJ105Y	ERJ-XGNJ105Y	1M	.35	.118	.093	20000	.033