



VISHAY/SFERNICE LTO SERIES, 30 & 50 WATT THICK FILM POWER RESISTORS - TO-220 PKG. STYLE




LEAD-FREE RoHS Compliant

Features:

- 30 Watt at 25°C case temperature heatsink mounted
• Direct mounting ceramic on heatsink
• Broad resistance range: R010 to 550K
• Non Inductive
• TO-220 package: Compact and easy to mount
• Isolated case

Electrical Specifications:

- Resistance Range: 0.010Ω to 550KΩ
• Tolerances (Standard): 5%
• Limiting Element Voltage: 250V

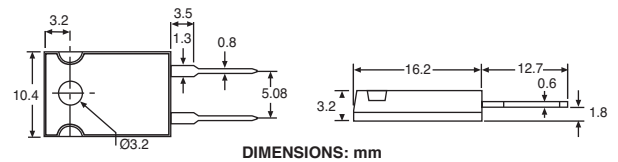

LTO series are the extension of RTO types.

30 Watt

For quantities greater than listed, call for quote.

Table with columns: MOUSER STOCK NO., Vishay Part No., OHMIC Range, Price Each (1, 10, 25, 50). Lists various LTO resistor models and their prices.

50 Watt

For quantities greater than listed, call for quote.

Table with columns: MOUSER STOCK NO., Vishay Part No., OHMIC Range, Price Each (1, 10, 25, 50). Lists various LTO resistor models and their prices.


VISHAY/SFERNICE LTO SERIES, 100 WATT THICK FILM POWER RESISTORS - TO-247 PKG. STYLE

Features:

- 100 Watt at 25°C case temperature heatsink mounted
• Direct mounting ceramic on heatsink
• Broad resistance range: R015 to 1M
• Non Inductive
• TO-247 package: Compact and easy to mount

Electrical Specifications:

- Resistance Range: 0.015Ω to 1MΩ
• Tolerances (Standard): 5%
• Limiting Element Voltage: 375V

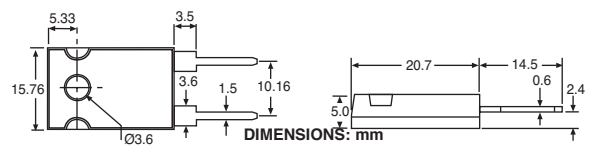

LTO series are the extension of RTO types.



LEAD-FREE RoHS Compliant

For quantities greater than listed, call for quote.

Table with columns: MOUSER STOCK NO., Vishay Part No., OHMIC Range, Price Each (1, 10, 25, 50). Lists various LTO resistor models and their prices.

For quantities greater than listed, call for quote.

Table with columns: MOUSER STOCK NO., Vishay Part No., OHMIC Range, Price Each (1, 10, 25, 50). Lists various LTO resistor models and their prices.


VISHAY/SFERNICE RTO SERIES, 20 WATT 5% THICK FILM POWER RESISTORS - TO-220 PKG. STYLE

Features:

- 20 Watt at 25°C Heatsink Mounted
• High Power Dissipation to size ratio
• Negligible Inductance
• TO-220 Package
• Flat version for surface mount is available - RTOC

Specifications:

- Operating Temperature: -55°C to +155°C
• Inductance: ≤0.1 μH
• Tolerance: 5% Standard
• Dielectric Withstanding Voltage: 2000VRMS

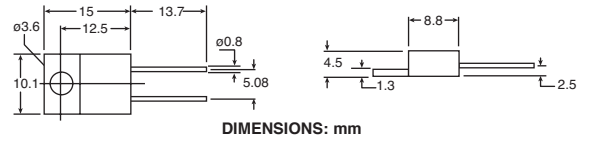

For quantities greater than listed, call for quote.

Table with columns: MOUSER STOCK NO., Vishay Part No., Value (Ω), Price Each (1, 25, 50, 100, 200). Lists various RTO resistor models and their prices.

For quantities greater than listed, call for quote.

Table with columns: MOUSER STOCK NO., Vishay Part No., Value (Ω), Price Each (1, 25, 50, 100, 200). Lists various RTO resistor models and their prices.

Power Resistors Vishay