




CNX718 Series 11/16" LED Panel Mount Indicator

CNX718 Series features a high intensity LED with a wide viewing angle

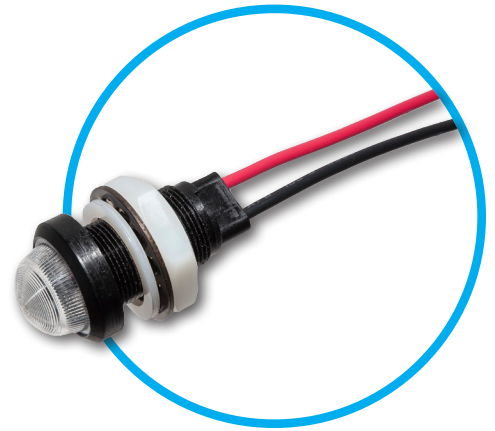

Key features

- Dome-shaped Clear Lens
- Front Panel Mount
- .187" Tab Terminals
- 6" Wire Leads
- Available in 4 Voltage Configurations
- RoHS Compliant

Ordering data

CNX718 11/16" indicator ordering code (example) **CNX718 N X00 XX X**

Lens Type		LED Color			Voltage		Termination Style	
X=	color	X00=	color	typ intensity, mcd	XX=	input voltage	X=	termination style
N	clear				05	5VDC	T	tab terminals
		200	red	2800	12	12VDC	W	wire leads
		400	amber	2800	28	28VDC		
		500	green	2400	120	120VAC		
		900	white	2500				

Dimensions

