

Global 5 Watt Power Supply

Qb



Features

- Interchangeable inputs for global markets
- Small design 32mm3
- USB or fixed cord output
- Available in custom colors
- One year warranty



Electrical Specifications

INPUT VOLTAGE	90 ~ 264VAC	OPERATING TEMPERATURE	-0° ~ 40°C
FREQUENCY	50 ~ 60Hz	STORAGE TEMPERATURE	-20° ~ 60°C
MAXIMUM OUTPUT POWER	5W	HUMIDITY	5% ~ 95% Non-condensing
INPUT CURRENT	Max 30A@230V Cold Start	LEAKAGE CURRENT	<0.25mA (264VAC)
EFFICIENCY	Meets CEC V	HI-POT	4242VDC/1 min/5mA
LOW STANDBY POWER	0.5W Max	MTBF	50K Hours At 25°C

Environmental & Reliability

 

 



 




OVER VOLTAGE / SHORT CIRCUIT PROTECTION

SAFETY & EMC STANDARDS

UL/cUL, CE, CB, GS, SAA, C-Tick, FCC, RoHS, REACH

HDP-QB05010U

OUTPUT (V)	5.0V
OUTPUT (A)	1000mA Max
POWER (W)	5W
RIPPLE	100mV
EFF.	V

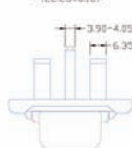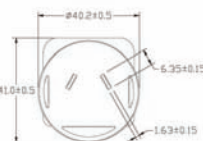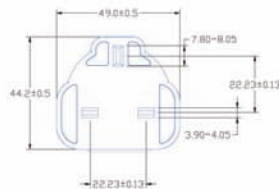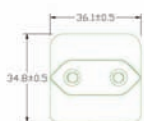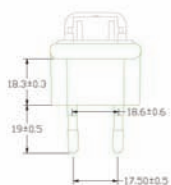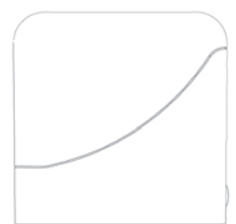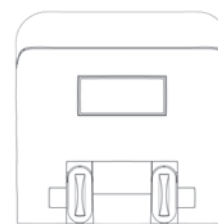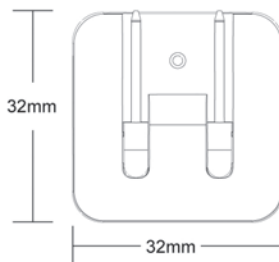

EU

UK

AU

ADAPTER PART NUMBER	AC PLUGS INCLUDED	USB DATALINES	COLOR
HDP-QB-BUSB-B	US	Shorted	Black
HDP-QB-WUSB-B	US	Shorted	White
HDP-QB-0004	US, +EU, AU, UK	Shorted	White
HDP-QB-0005	US, +EU, AU, UK	Shorted	Black

REMOVABLE AC PLUGS

HDP-EU-0004	WHITE EU
HDP-AU-0004	WHITE AU
HDP-UK-0004	WHITE UK
HDP-EU-0005	BLACK EU
HDP-AU-0005	BLACK AU
HDP-UK-0005	BLACK UK