



DigiTemp® EZ - The Next Generation in Liquid Crystal Thermometry

- Immediate
 - Intuitive
- Temperature Recognition**

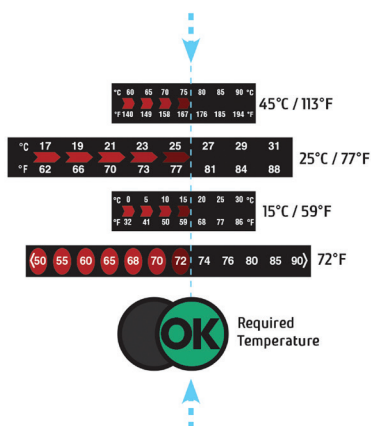

DigiTemp® EZ Easy Read


- No Color Deciphering
- Accuracy
 - 30°C to -4°C : $\pm 2^\circ\text{C}$
 - 3°C to 50°C : $\pm 1^\circ\text{C}$
 - 51°C to 90°C : $\pm 2^\circ\text{C}$
- Continuous Temperature Display
- No Batteries
- Low Cost
- -30°C to 90°C Temperature Range
- Self Adhesive

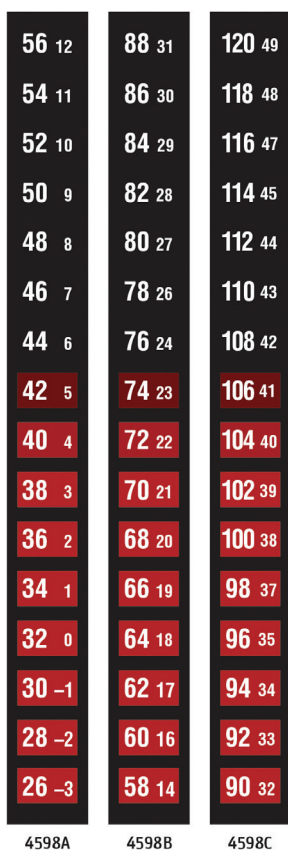

4598A																
°F	26	28	30	32	34	36	38	40	42	44	46	48	50	52	54	56
°C	-3	-2	-1	0	1	2	3	4	5	6	7	8	9	10	11	12
4598B																
°F	58	60	62	64	66	68	70	72	74	76	78	80	82	84	86	88
°C	14	16	17	18	19	20	21	22	23	24	26	27	28	29	30	31
4598C																
°F	90	92	94	96	98	100	102	104	106	108	110	112	114	116	118	120
°C	32	33	34	35	37	38	39	40	41	42	43	44	45	47	48	49

Specifications:

- Size: 5" x 0.5" (127mm x 12.5mm)
- Type: Vertical, self adhesive
- Scale: °F and °C

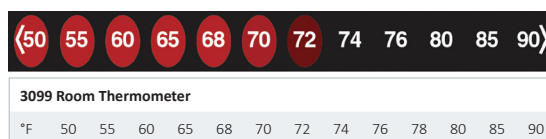


3099 Room Thermometer

°F	50	55	60	65	68	70	72	74	76	78	80	85	90
----	----	----	----	----	----	----	----	----	----	----	----	----	----

Specifications:

 - Size: 3.5" x .4" (90mm x 10mm)
- Type: Horizontal, self adhesive
- Scale: °F




2114 Room Thermometer

°F	62	66	70	73	77	81	84	88
----	----	----	----	----	----	----	----	----

Specifications:

- Size: 3.5" x 0.5" (89mm x 12.5mm)
- Type: Horizontal, self adhesive
- Scale: °F and °C

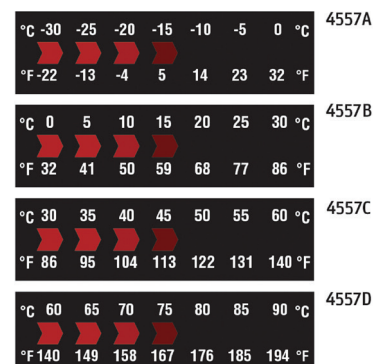

4557A							
°F	-22	-13	-4	5	14	23	32
°C	-30	-25	-20	-15	-10	-5	0

4557B							
°F	32	41	50	59	68	77	86
°C	0	5	10	15	20	25	30

4557C							
°F	86	95	104	113	122	131	140
°C	30	35	40	45	50	55	60

4557D							
°F	140	149	158	167	176	185	194
°C	60	65	70	75	80	85	90

Specifications:

- Size: 0.5" x 1.77" (12.5mm x 45mm)
- Type: Horizontal, self adhesive
- Scale: °F and °C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SpotSee:

[2114 AKC36](#) [3099AKC45](#) [4598C ADP100](#) [4557D ADP100](#) [4598A ADP10](#) [4598A ADP100](#) [4598B ADP10](#) [4598B ADP100](#) [4598C ADP10](#) [4557A ADP100](#) [4557B ADP10](#) [4557B ADP100](#) [4557C ADP10](#) [4557C ADP100](#) [4557D ADP10](#) [4557A ADP10](#)