


SDM-1135G7L/ SDM-1115G4L

Intel® Smart Display Module with 11th Generation Core™ i5-1135G7/ i3-1115G4 Processor,
Dual Channel DDR4 Memory, 3 x USB 3.2 Gen1x1, 1 x USB 2.0

Preliminary Release

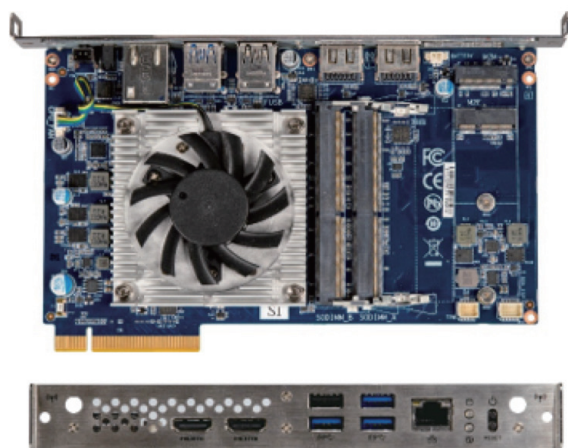

Features

- SDM Large
- Intel® 11th Generation Core™ i5-1135G7/ i3-1115G4 Processor
- Dual Channel DDR4, 2 x SO-DIMMs
- 1 x GbE LAN Port
- 3 x USB3.2 Gen1x1 Ports
- 1 x USB2.0 Port
- All Solid Capacitor
- Environment : Operation 0~55°C
- Long life time support
- Support 4K/60Hz, HDCP v2.2
- Intel® Platform Trust Technology (PTT) 3.0

Application Scenarios

- Digital Signage
- Smart Retail
- Menu Board
- Interactive Whiteboard

Specifications

Model Name	SDM-1135G7L	SDM-1115G4L
Form Factor	SDM-Large, 175W x 100D (mm)	
CPU	Intel® Core™ i5-1135G7 Processor, 8M Cache, up to 4.20 GHz	Intel® Core™ i3-1115G4 Processor, 6M Cache, up to 4.10 GHz
Socket	1 x FCBGA1449	
Memory	2 x DDR4 SO-DIMM sockets, Max. Capacity 32 GB, Support Dual Channel DDR4 2933 MHz	
Ethernet	1 x GbE LAN port	
Video	Integrated Graphics Processor - Intel® Iris X® Graphics 1 x HDMI 2.0 (SDM), 1 x Display Port (SDM) 2 x HDMI 2.0 (Rear) 4 independent display outputs	
Audio	Intel® integrated Audio	
Storage	—	
Expansion Slots	1 x 2280 M.2 M-Key (PCIe x4, SATA 6Gb/s) 1 x 2230 M.2 E-Key	
Rear I/O	1 x RJ45 LAN port 2 x HDMI 2.0 3 x USB3.2 Gen1x1 1 x USB 2.0 1 x Power/ HDD LED 2 x External Antenna Hole (Option) 1 x Reset button 1 x Power button	
TPM	1 x TPM header	
OS Compatibility	Windows® 10 (x64)	
Operating Properties	Operating temperature: 0°C to 55°C Operating humidity: 0-90% (non-condensing) Non-operating temperature: -20°C to 70°C Non-operating humidity: 0%-95% (non-condensing)	

GIGAIPC reserves the right to modify or change technical data without prior notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[GIGAIPC:](#)

[SDM-1135G7L](#)