

# AU 2-PIN POWER SUPPLY, 18 W




## TECHNICAL DATA

### GENERAL

Input voltage	100 – 240 VAC
Input frequency	50 / 60 Hz
Input current	0.6 A
Output voltage	12 VDC
Output current	1.5 A
Input voltage absolute maximum	90 – 264 VAC
Input frequency absolute maximum	47 – 63 Hz
Inrush current	60 A
Output voltage absolute maximum	11.4 – 12.6 VDC

Short circuit protection	✓
HIPOT (dielectric withstand test)	Primary to Secondary: 4242 VDC
MTBF	50000 h
Input connector	AU (Type I)
Output connector	2-pin, with cord end terminals
Weight	102 g
Certification	<b>Safety:</b> AS/NZS 62368.1:2018, AS/NZS 3112:2017 <b>EMC:</b> AS/NZS CISPR 32:2015, EN 55032:2015, EN 55035:2017, EN 61000-3-2:2019, EN 61000-3-3:2013+A1:2019

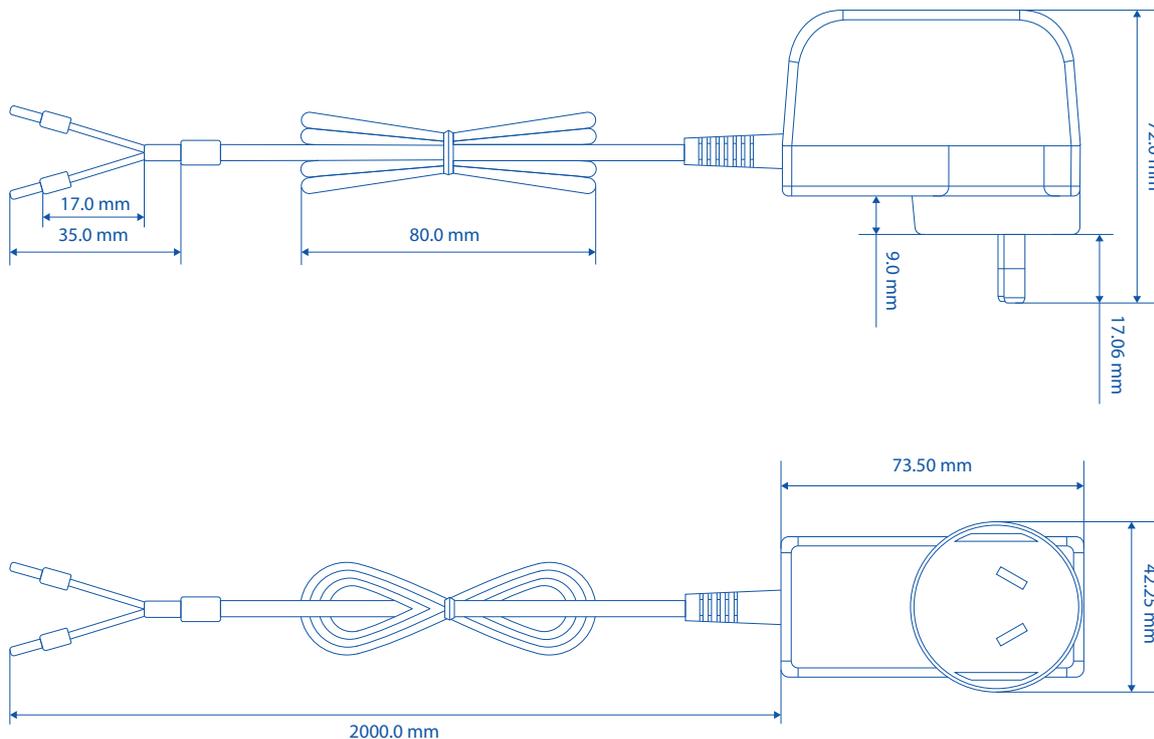

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Teltonika:](#)

[PR315AUA](#)