



 
 
Heyco® Stainless Steel Cable Clamps

- For clamping cable or tubing securely into place, especially in **harsh environments**.
- Smooth "coined clamp" edges prevent damage to cable insulation.
- Constructed from corrosion resistant 304 stainless steel.
- Coated parts are constructed from 304 stainless steel and coated with polyolefin a thermoplastic co-polymer.
- Coating provides a durable non-toxic, odorless coating that has very good low temperature flexibility and excellent electrical properties. This coating also has **FDA food contact** approval.
- All parts require a .203" (5,2 mm) mounting hole suitable for a #10 screw.
- Not for use in a marine salt water environment. Contact Heyco for alternative materials.
- DFARS Compliant

PART DIMENSION A		STANDARD		COATED	
in.	mm.	PART NO.	DESCRIPTION	PART NO.	DESCRIPTION
.19	4,7	S3373	CC H 3/16 SS	S3323	CC H 3/16 SS Coated
.25	6,3	S3374	CC H 1/4 SS	S3324	CC H 1/4 SS Coated
.38	9,5	S3376	CC H 3/8 SS	S3326	CC H 3/8 SS Coated
.50	12,7	S3378	CC H 1/2 SS	S3328	CC H 1/2 SS Coated
.63	15,9	S3380	CC H 5/8 SS	S3330	CC H 5/8 SS Coated
.75	19,1	S3382	CC H 3/4 SS	S3332	CC H 3/4 SS Coated
.88	22,2	S3384	CC H 7/8 SS	S3334	CC H 7/8 SS Coated

NEW!

Consult Heyco for additional sizes.



Heyco® Steel Cushion Clamps

MOUNTING HOLE DIA.	SCREW SIZE	PART DIMENSION A	PART NO.	PART NO.	DESCRIPTION	MARKING	RUBBER THICKNESS
in.	mm.	in.	mm.	304 Stainless			in. mm.

.650" (16,5 mm) Overall Width, .031" (0,8 mm) Steel Thickness


.265	6,7	1/4	0.19	4,7	12300	15730	CCSC L 3/16	3/16	.06	1,5
			0.25	6,3	12301	15731	CCSC L 1/4	1/4		
			0.31	7,9	12302	15732	CCSC L 5/16	5/16		
			0.38	9,5	12303	15733	CCSC L 3/8	3/8		
			0.44	11,1	12304	15734	CCSC L 7/16	7/16		
			0.50	12,7	12305	15735	CCSC L 1/2	1/2		
			0.56	14,3	12306	15736	CCSC L 9/16	9/16		
			0.63	15,9	12307	15737	CCSC L 5/8	5/8		
			0.69	17,4	12308	15738	CCSC L 11/16	11/16		
			0.75	19,1	12309	15739	CCSC L 3/4	3/4		
			0.88	22,2	12310	15740	CCSC L 7/8	7/8		
			1.00	25,4	12311	15741	CCSC L 1	1		
			1.13	28,6	12312	15742	CCSC L 1-1/8	1-1/8		
			1.25	31,8	12313	15743	CCSC L 1-1/4	1-1/4		
			1.50	38,1	12314	15744	CCSC L 1-1/2	1-1/2		
			2.00	50,8	12315	15745	CCSC L 2	2		
			2.50	63,5	12316	15746	CCSC L 2-1/2	2-1/2		
			3.00	76,2	12317	15747	CCSC L 3	3		

.750" (19,1 mm) Overall Width, .047" (1,2 mm) Steel Thickness

.406	10,3	7/16	0.25	6,3	12331	15751	CCSC H 1/4	1/4	.06	1,5
			0.31	7,9	12332	15752	CCSC H 5/16	5/16		
			0.38	9,5	12333	15753	CCSC H 3/8	3/8		
			0.44	11,1	12334	15754	CCSC H 7/16	7/16		
			0.50	12,7	12335	15755	CCSC H 1/2	1/2		
			0.63	15,9	12337	15757	CCSC H 5/8	5/8		
			0.69	17,4	12338	15758	CCSC H 11/16	11/16		
			0.88	22,2	12340	15760	CCSC H 7/8	7/8		
			1.00	25,4	12341	15761	CCSC H 1	1		
			1.25	31,8	12343	15763	CCSC H 1-1/4	1-1/4		
			1.50	38,1	12344	15764	CCSC H 1-1/2	1-1/2		
			2.00	50,8	12345	15765	CCSC H 2	2		
			2.50	63,5	12346	15766	CCSC H 2-1/2	2-2/2		
			3.00	76,2	12347	15767	CCSC H 3	3		



- Light to heavy duty steel clamp.
- E.P.D.M. cushion for electrical insulation and vibration absorption.
- Steel clamps are zinc electroplated for corrosion resistance.
- 304 Stainless Steel clamps for superior corrosion resistance for harsh environments.
- Color - Silver with durable black cushion.

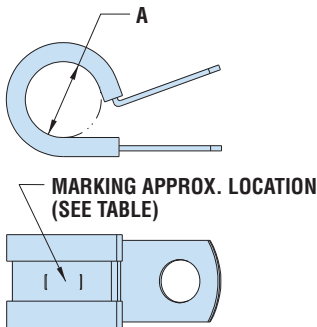

Material **CC H** 304 Stainless Steel
Temperature Range 0°C (32°F) to 60°C (140°F)

CCSC Zinc Plated Steel and 304 Stainless Steel with a UV resistant EPDM Sleeve
-40°C (-40°F) to 100°C (212°F)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[15765](#) [15732](#) [15754](#) [15743](#) [15742](#) [15763](#) [15760](#) [15737](#) [15755](#) [15757](#) [15739](#) [15731](#) [15751](#) [15747](#) [15745](#)
[15736](#) [15735](#) [15753](#) [15733](#) [15730](#) [15744](#) [15766](#) [15764](#) [15741](#) [15746](#) [15752](#) [15734](#) [15738](#) [15740](#) [15767](#)
[15761](#) [15758](#)