 


Heyco® Nytye® Heavy Duty Nylon Cable Ties

PART SPECIFICATIONS				PART NO.		DESCRIPTION	PART DIMENSIONS			
Tensile Strength		Max. Bundle Diameter		Natural	UV Black		A Length		B Width	
Lbs.	N	in.	mm.						in.	mm.
120 Pound										
120	534	1.30	33,0	13172	13172B	NT-120-059	5.91	150	.30	7,6
		1.97	50,0	13175	13175B	NT-120-078	7.87	200		
		2.48	63,0	13178	13178B	NT-120-098	9.84	250		
		3.23	82,0	13181	13181B	NT-120-118	11.81	300		
		3.54	90,0	13183	13183B	NT-120-137	13.78	350		
		3.98	101,0	13185	13185B	NT-120-149	14.96	380		
		4.13	105,0	13186	13186B	NT-120-157	15.75	400		
		6.10	155,0	13190	13190B	NT-120-216	21.65	550		
175 Pound										
175	778	7.48	190,0	13208	13208B	NT-175-256	25.59	650	.35	9,0
		9.65	245,0	13215	13215B	NT-175-315	31.50	800		
		10.67	271,0	13217	13217B	NT-175-362	36.22	920		
		11.42	290,0	13218	13218B	NT-175-394	39.37	1000		
		14.49	368,0	13220	13220B	NT-175-482	48.23	1225		
250 Pound										
250	1112	5.51	140,0	13225	13225B	NT-250-196	19.68	500	.49	12,5
		6.61	168,0	13226	13226B	NT-250-228	22.83	580		
		7.48	190,0	13227	13227B	NT-250-256	25.59	650		
		10.71	272,0	13228	13228B	NT-250-350	35.04	890		
		10.55	268,0	13229	13229B	NT-250-354	35.43	900		
		11.77	299,0	13230	13230B	NT-250-394	39.37	1000		
		12.72	323,0	13231	13231B	NT-250-433	43.31	1100		
		14.33	364,0	13232	13232B	NT-250-472	47.24	1200		


Standard colors natural and UV Black. Consult Heyco for heat-stabilized material and colors.



Heyco® Nytye® Double Loop Cable Ties

PART SPECIFICATIONS				PART NO.		DESCRIPTION	PART DIMENSIONS			
Tensile Strength		Max. Combined Bundle Diameter F		Natural	NEW UV Black		A Length		B Width	
Lbs.	N	in.	mm.			in.	mm.	in.	mm.	
50	222	1.77	45,0	13320	13320B	NTDL-050-076	7.68	195	.19	4,8
		2.05	52,0	13321	13321B	NTDL-050-088	8.86	225		
		2.99	76,0	13323	13323B	NTDL-050-118	11.81	300		
		3.86	98,0	13324	13324B	NTDL-050-145	14.56	370		

Standard color natural.

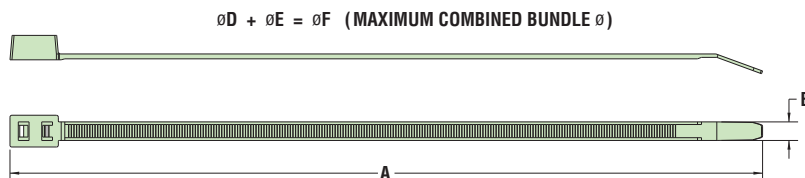

Material
Certifications



Nylon 6/6

Certified by UL for Compliance with both Canadian and U.S. requirements under File E54523 (NT parts only)

Flammability Rating
Temperature Range

94V-2


-40°F (-40°C) to 185°F (85°C)



- Smooth, radiused edges ensure that Nytyes won't cut into the cable's insulation—or the installer's hand.
- One-piece design reduces cost and installation time.
- Nytyes feature a bent tip for ease of pickup and insertion around small bundles. V-shaped raised ridges on the tip provide a sure grip.
- Close, evenly spaced teeth permit fine adjustment—from .025" (0,6 mm) on the smallest Nytyes to .063" (1,6 mm) on the largest.
- Compliant with MS3367 and MIL-S-23190E



- Cost-effective way to secure and separate two bundles with one cable tie
- Quickly and easily pulls through increasing productivity
- Single part covers multiple bundle sizes resulting in reduced part number inventory

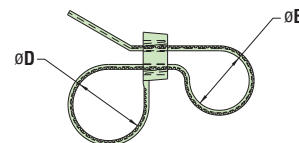

Quick Specs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[13225](#) [13225B](#) [13226](#) [13226B](#) [13230](#) [13230B](#) [13231](#) [13231B](#) [13232](#) [13232B](#) [13227](#) [13227B](#) [13228](#) [13228B](#)
[13229](#) [13229B](#)