

MIC-717-OX

AI NVR Solution with NVIDIA Metropolis Microservices on Jetson



Features

- Compact fan design
- Embedded NVIDIA® Jetson Orin™ NX capable of up to 100 TOPS
- Support 1 x 3.5" SATA HDD, or 1 x 2.5" SSD
- Integrated with NVIDIA Metropolis Microservices on Jetson
- Supports Allxon 24/7 remote monitoring and OTA deployment


Specifications

	MIC-717-OX	MIC-717-OX
Processor System	CPU Model	Jetson Orin NX 16GB
	AI Performance	100 TOPS
	GPU	1024-core NVIDIA Ampere architecture GPU with 32 Tensor Cores
	CPU	8-core Arm® Cortex®-A78AE v8.2 64-bit CPU 2 MB L2 + 4 MB L3
	Memory Capacity	16 GB 128-bit LPDDR5 102.4 GB/s
I/O	Ethernet	2 x 10/100/1000 Mbps
	Display	HDMI (max. resolution 3840 x 2160 @ 60 Hz)
	USB	1 x USB 3.0 ((Internally used for recovery mode) 2 x USB 2.0
	Digital I/O	4-ch DI, 4-ch DO
	PoE + Ports	8 x RJ-45 (10/100 Mbps + PoE / total power: 123.2 W)
Expansion	M.2	1 x M.2 3042 (B-Key, signal: USB)
	SIM	1 x Nano SIM slot
	TPM	1 x TPM 2.0
Storage	M.2	1 x M.2 2280 (M-Key, NVMe, signal: PCIe x4)
	HDD/SSD	1 x 3.5" HDD or 1 x 2.5" SSD
Power	Power Input	54 V DC, 4.26 A
	Power Supply	Adapter (external)
Environment	Operating Temperature*	0 to 50°C (32 to 122°F)
	Operating Humidity	95% relative humidity @ 40°C (104°F), non-condensing
	Vibration	3 Grms @ 5 to 500 Hz, random, 1 hr/axis
	Shock	10G / 11ms
Mechanical	Dimensions (W x D x H)	254.5 x 195.0 x 44.45 mm (10.0 x 7.67 x 1.75 in)
	Weight	1.14 kg (2.5 lb)
	Installation	Desktop / wallmount
BSP	Jetpack	Above 5.1
Certifications		UL, cUL, CE, UKCA, RoHS, Reach (SVHC)
Safety		UL/CSA/IEC/EN 62368-1

* Depending on the installation situation and interface connection. Derating of max. operating temp. is possible when using the cellular LTE module.

Dimensions

Unit: mm

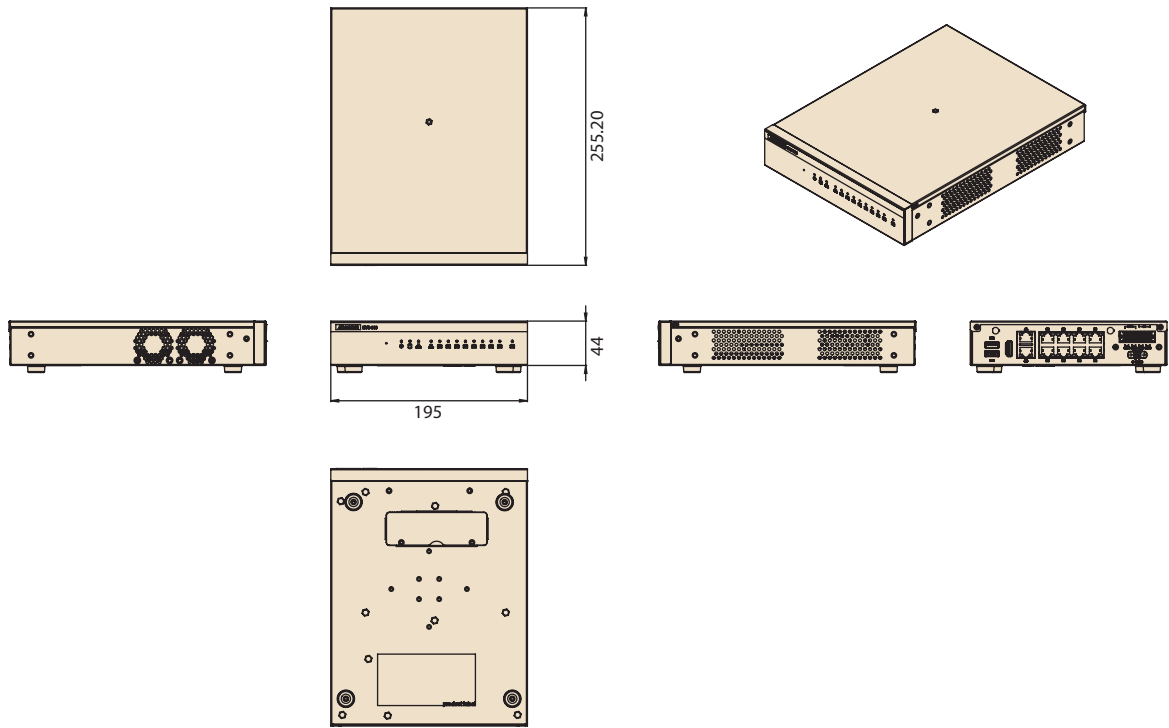

Ordering Information

Part Number	NVIDIA Module	NVIDIA Module Memory	NVIDIA Module Emmc	NVMe**
MIC-717-0X3A1	Orin NX	8 GB	N/A	128 GB
MIC-717-0X4A1	Orin NX	16 GB	N/A	128 GB

** The system BSP will be pre-installed in a 128GB NVMe M.2 SSD.


Packing List

Packing List	Description	Q'ty
1960102775T002	Wall Mount Kit	2
1652007963-01	DIO Terminal Block	1
1930004905	HDD Screw	4
1700032684-01	M cable SATA 22P/SATA 7P+1x4P-2.5 20cm 90/180 6G	1
1700023588-01	M Cable USB-A 4P(M)/USB-A 4P(M) 120cm	1
1930005626	Screw M4*5L S/S D=8.0 H=1.6 + ST Ni	4
1652002209	Power terminal block	1


Optional

Part Number	Description
XAC-FSP230-AWAN3	ADP A/D 100-240 V 230 W 54 V
1702002600-01	Power cord (USA)
1702002605	Power cord (EU) 2-pin
9651960AL00	LTE bracket accessory kit
NVS-960STD-RM	NVS-960 STD rack mount kit
NVS-960STD-DR	NVS-960 STD DIN rail kit

Front View

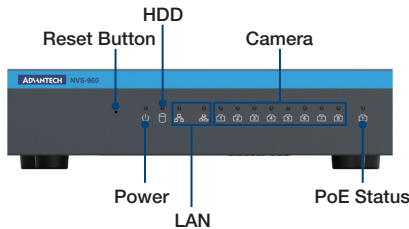

Back View

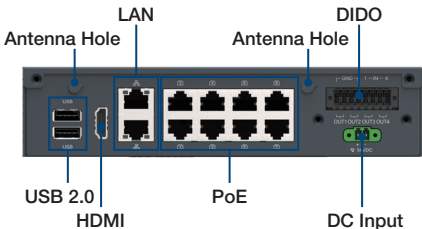

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[MIC-717-OX4A1](#) [MIC-717-OX3A1](#)