


NMC-1009

2 Ports 10GbE SFP+ Module

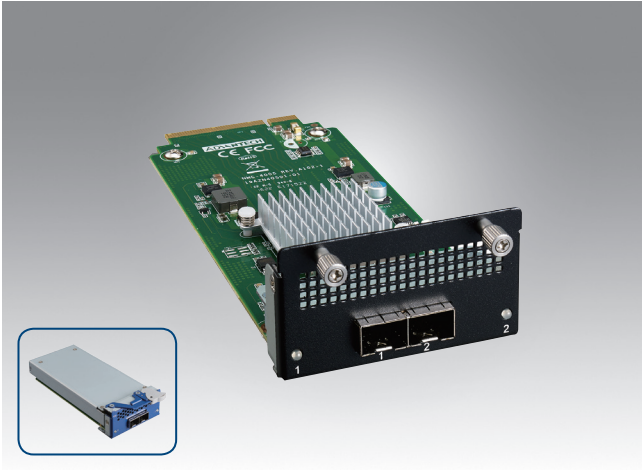

Features

- 1x Intel XL710-BM1
- 2 ports SFP+ connector
- PCI-E 3.0 x8
- RoHS compliant




Specifications

Controller	1x Intel XL710-BM1
Interface	PCI-E 3.0 x8
Speed	10GbE
Port	2x SFP+ Port
LAN LED definition	Port#1 & Port#2 Indicator: Link: LED0 on Act: Blinking
Advanced Software Features	Teaming support IEEE 802.3ad IEEE 802.1Q VLANs IEEE 802.3 2005 flow control support Interrupt moderation
OS Support	Windows® Server 2012 R2, 2012, 2008 R2 X86-64 Linux RedHat EL 6.5 and 7.0 IA-32, X86-64, and IA-64 Linux SuSE SLES 11 SP3 and 12 IA-32, X86-64, and IA-64 FreeBSD 9 and 10 IA-32, X86-64, and IA-64 UEFI 2.1 and 2.3 X86-64 and I-64 VMware ESXi 5.1, ESXi 5.5 and ESXi 6.0 X86-64
Operating Conditions	Operation: -5 ~ 45°C Storage: -20 ~ 60°C
Supported Platform	FWA-6520/FWA-5020
Power Voltage & consumption	+12V ± 15% 16W
Dimension (mm)	163.7 x 74.6 x 35.5
Compliance	CE/FCC

Dimensions

Unit: mm

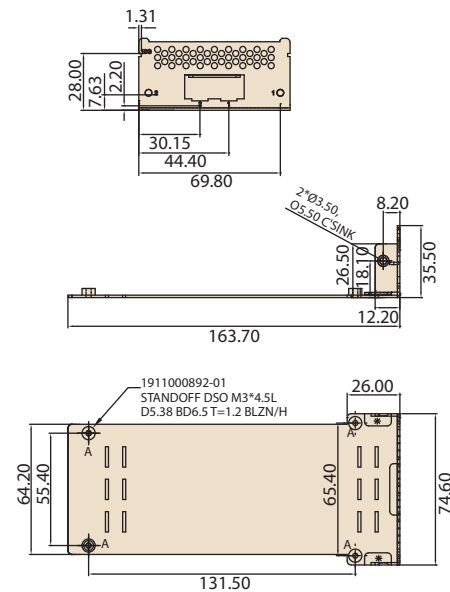

Ordering Information

Part Number	Description
NMC-1009-000010E	2 Ports 10G SFP+ Latch
NMC-1009-02FSA1	2 Ports 10G SFP+ Thumbscrew

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[NMC-1009-02FSA1](#)