


## Protect It! 6-Outlet Surge Protector with USB-A and USB-C Charging Ports - 5-15R Outlets, 900 Joules, Desk Clamp, 6 ft. (1.8 m) Cord, White

MODEL NUMBER: **TLP66UCLAMP**

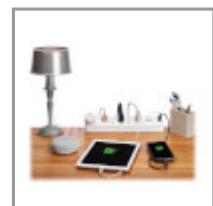

Clamps safely to your workstation to protect your electronics against surges and charge your mobile devices.

### Features

#### 6-Outlet Surge Protector with USB Safeguards Your Sensitive Electronics

Ideal for your home, office, retail or industrial workstation, this Protect It!® surge protector features a surge protection rating of 900 joules to defend your valuable electronic components against power surges and spikes. Because residential power outlets have three wires—hot line (H), neutral (N) and ground (G)—the TLP66UCLAMP protects all three, covering the two protection modes: full normal mode (H-N) and common mode (N-G/H-G).

#### NEMA 5-15R Outlets Accept a Wide Range of Electronic Devices

Plug your computer, printer, router, desk lamp or other home/office electronics into six NEMA 5-15R outlets to protect them against dangerous surges, spikes and line noise. One outlet is separated from the others to allow connection of a bulky transformer without blocking adjacent outlets.

#### USB Ports Support up to 5.4A for Charging Mobile Devices

One USB-A port (5V) and one USB-C port (5V) feature 5.4 total amps, which is sufficient for charging smartphones, tablets and other mobile devices.

#### Premium Protection from EMI/RFI Line Noise Helps Your Equipment Perform Better

This surge protector filters out disruptive EMI (electromagnetic interference) and RFI (radio frequency interference) line noise that can disturb your electronics and inflict hardware damage or data loss. This EMI/RFI filtering also helps your connected components perform better and last longer.

#### Clamps Firmly to Your Workstation for Easy Access

The TLP66UCLAMP features an adjustable mounting clamp, which attaches to a desk, table or other flat surface from .04 to 2.2 inches (1 to 56 millimeters). The six-foot (1.8-meter) braided input cord with NEMA 5-15P right-angle plug allows you some flexibility in placing the surge suppressor away from the nearest wall outlet.

### Highlights

- Clamps to most flat surfaces to keep outlets and mobile devices within easy reach
- 6 NEMA 5-15R outlets power most computers, monitors and other electronic devices
- 2 USB ports feature 5.4 total amps for charging smartphones and other mobile devices
- 900 joules protect your valuable electronics against dangerous surges and spikes
- 6 ft. input cord allows some flexibility in placing devices away from wall outlet

### Package Includes

- TLP66UCLAMP 6-Outlet Surge Protector
- Desk clamp
- Owner's manual

## Specifications

<b>OVERVIEW</b>	
UPC Code	037332290557
Product Type	Surge Protector
Charging Form Factor	Strip
Device Compatibility	Phone; Tablet; Amazon Kindle
<b>INPUT</b>	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V
Input Cord Length Details	Strip
Input Cord Gauge (AWG)	14
Voltage Compatibility (VAC)	125
Input Plug Type	NEMA 5-15P
Input Cord Length (ft.)	6
Right-Angle Plug	Yes
Input Cord Length (m)	1.83
Integrated Cord Clip	No
<b>OUTPUT</b>	
Frequency Compatibility	60 Hz
Output (Watts)	1875
Output Receptacles	(6) 5-15R
Circuit Breaker (amps)	15
Transformer Accommodation	Yes
Right-Angle Outlets	No
<b>USER INTERFACE, ALERTS &amp; CONTROLS</b>	
Diagnostic LED(s)	Yes
Diagnostic LED Details	X1 Green LED - Protected
<b>CHARGING</b>	
Number of Charging Ports	2
Total Charging Amps	1 USB-A, 1-USB-C ports 5.4A per port
Charging Method	USB
Charging Port Type	(1) USB A (FEMALE); (1) USB C (FEMALE)
Overcharge Protection	No

<b>SURGE / NOISE SUPPRESSION</b>	
AC Suppression Joule Rating	900
AC Suppression Response Time	< 1 ns
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line suppression
UL1449 Let Through Rating	600, 600, 600
EMI / RFI Filtering	Yes
Automatic Shut-Off	No
<b>DATALINE SURGE SUPPRESSION</b>	
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
Telephone/DSL Protection	No
<b>PHYSICAL</b>	
Material of Construction	Plastic
Power Cord Color	White
Housing Color	White
Included Mounting Accessories	Desk Clamp. Clamp Range.4 to 2.2"
Mounting Holes or Slots	No
Receptacle Color	Black
Shipping Dimensions (hwd / in.)	5.90 x 21.60 x 12.80
Shipping Dimensions (hwd / cm)	14.99 x 54.86 x 32.51
Shipping Weight (lbs.)	2.09
Shipping Weight (kg)	0.95
Unit Dimensions (hwd / in.)	12.050 x 2.710 x 1.910
Unit Dimensions (hwd / cm)	306.80 x 68.94 x 48.64
Unit Weight (lbs.)	1.5
Unit Weight (kg)	0.68
<b>FEATURES &amp; SPECIFICATIONS</b>	
Rotatable Outlets	No
Antimicrobial	No
GaN Technology	No
Mounting Accessory Included	Yes
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	CAN/CSA-C22.2 No. 308 (Canada); ICES (Canada); UL 962A



*Powering Business Worldwide*

TRIPP LITE  
SERIES

Product Compliance	FCC Part 15 Class B (USA)
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty
Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$25,000 <a class="insuranceLink" href="//tripplite.eaton.com/support/insurance-policy">Ultimate Lifetime Insurance</a>

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[TLP66UCLAMP](#)