

Item No.	Part No.	Description
1	SVA-41T-P1.1	VA Connector Contact
2	UL1015, 18 AWG	Black

## APPLICABLE HOUSINGS

NO. OF CIRCUITS	HOUSING PART NO.
2	VAR-2


## Electrical Specifications

Current: 7.0A AC/DC

Voltage: 250V AC/DC

226.4 +/- 5.0

203.2 +/- 5.0

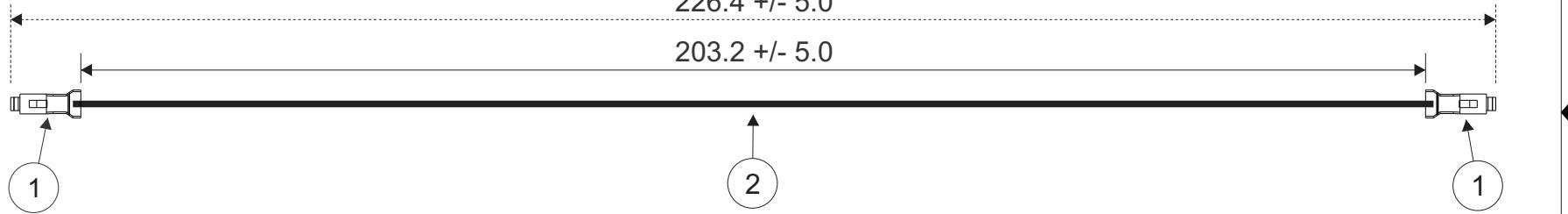

JST

All dimensions are in millimeters with a default tolerance of +/- 5.0 unless otherwise specified.

**CUSTOMER NAME**

#### DESCRIPTION

11

Drawn By:  
Larissa Mosley  
Checked By:

**7.92mm Pitch VA Series Standard Leads - 8" Inside Length  
DOUBLE END LEADS**

SIZE	CUSTOMER PART NO.	PART NO.
		AVAVA18K203

SCALE 1:1	DRAWING NO. GAM-852	DATE 4/10/2019
--------------	------------------------	-------------------

ZONE	REV	DESCRIPTION	DATE	APPROVED