


THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO J.S.T. AND SHALL NOT BE USED OR SHOWN WITHOUT WRITTEN PERMISSION.

Item No.	Part No.	Description
1	SYM-001T-P0.6	SM Connector Contact
2	UL1007, 22 AWG	Black

Electrical Specifications
Current: 3AAC/DC
Voltage: 250V AC/DC

APPLICABLE HOUSINGS		
NO. OF CIRCUITS	HOUSING PART NO.	HOUSING COLOR
2	SMR-02V-B	BLACK
	SMR-02V-N	WHITE
3	SMR-03V-B	BLACK
	SMR-03V-N	WHITE
4	SMR-04V-B	BLACK
	SMR-04V-N	WHITE
5	SMR-05V-B	BLACK
	SMR-05V-N	WHITE
6	SMR-06V-B	BLACK
	SMR-06V-N	WHITE
7	SMR-07V-B	BLACK
	SMR-07V-N	WHITE
8	SMR-08V-B	BLACK
	SMR-08V-N	WHITE
9	SMR-09V-B	BLACK
	SMR-09V-N	WHITE
10	SMR-10V-B	BLACK
	SMR-10V-N	WHITE
11	SMR-11V-B	BLACK
	SMR-11V-N	WHITE
12	SMR-12V-B	BLACK
	SMR-12V-N	WHITE
18	SMR-18V-B	BLACK
	SMR-18V-N	WHITE

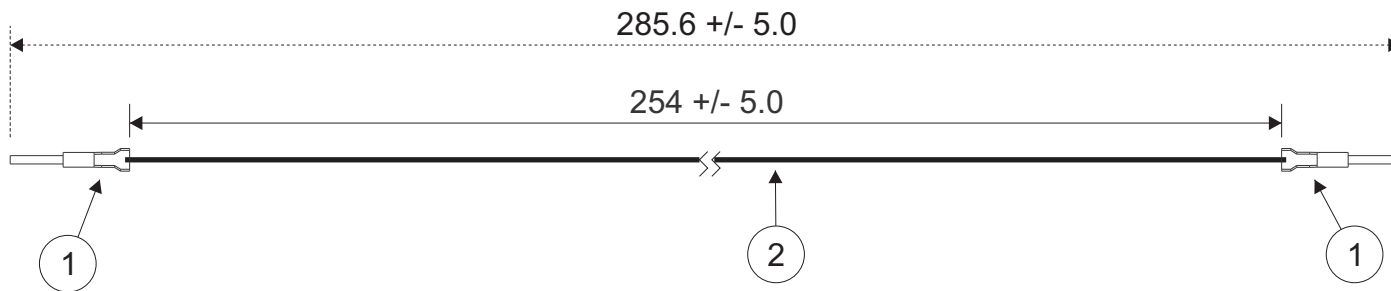

ZONE	REV	DESCRIPTION	DATE	APPROVED

All dimensions are in millimeters with a default tolerance of +/- 5.0 unless otherwise specified.		CUSTOMER NAME		
		DESCRIPTION		
		2.5mm Pitch SM Series Standard Leads - 10" Inside Length DOUBLE END LEADS, M-M		
Drawn By: Larissa Mosley	SIZE	CUSTOMER PART NO.	PART NO.	REV
Checked By: Steven Pilkington	SCALE 1:1	ASMRSMR22K254		
	DRAWING NO. GAM-635		DATE 1/8/2019	