


THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO J.S.T. AND SHALL NOT BE USED OR SHOWN WITHOUT WRITTEN PERMISSION.

Item No.	Part No.	Description
1	SGVHSF-002T-0.2	GVH Connector Contact
2	UL1061, 26 AWG	Black

Electrical Specifications
Current: 1AAC/DC
Voltage: 50V AC/DC

APPLICABLE HOUSINGS	
NO. OF CIRCUITS	HOUSING PART NO.
2	GVHRSF-02V-S
3	GVHRSF-03V-S
4	GVHRSF-04V-S
5	GVHRSF-05V-S
6	GVHRSF-06V-S
7	GVHRSF-07V-S
8	GVHRSF-08V-S
9	GVHRSF-09V-S
10	GVHRSF-10V-S
11	GVHRSF-11V-S
12	GVHRSF-12V-S
13	GVHRSF-13V-S
14	GVHRSF-14V-S
15	GVHRSF-15V-S

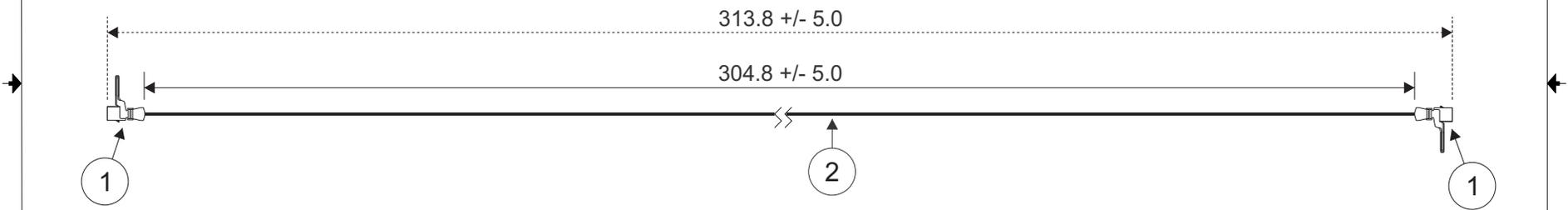

All dimensions are in millimeters with a default tolerance of +/- 5.0 unless otherwise specified.		CUSTOMER NAME			
		DESCRIPTION 1.25mm Pitch GVH Series Standard Leads - 12" Inside Length DOUBLE END LEADS, SIDE FEED TYPE			
Drawn By: Larissa Mosley	SIZE	CUSTOMER PART NO.	PART NO.	REV	DATE 1/25/2019
Checked By: Steven Pilkington	SCALE 1:1	DRAWING NO. GAM-704	AGVHGVH26K305		

ZONE	REV	DESCRIPTION	DATE	APPROVED