

Features

- 9th/8th Gen Intel® Xeon® E / Core™ i7/i5/i3 Pentium® QC/DC Processor, up to 4.7GHz
- 2x DDR4 DIMM, Max. 32GB
- 2x Gigabit LAN
- Intel® processor integrated graphics, supports DVI-I/ DVI-D/ LVDS
- 3x USB 2.0, 5x USB 3.0, 5x SATA III, 4x COM
- 2x M.2 socket (M-Key/E-Key)

Specifications

CPU Socket	LGA1151
CPU	9th/8th Gen Intel® Xeon® E / Core™ i7/i5/i3 DT processors
PCH	IB995AF-C246: Intel® C246 PCH IB995AF: Intel® Q370 PCH IB995EF: Intel® H310 PCH
Memorys	2x DDR4-2166/2400MHz DIMM, Max. 32GB (ECC compatible)
BIOS	AMI
Watchdog Timer	256 levels
H/W Monitor	Yes
Storage Device Interface	1x M.2 (supports NVMe)
Expansion Slots	4x PCI, 4x PCI-E (x1) or 1x PCI-E (x4) 1x PCI-E (x16) from backplane
Mini Type Slots	1x M.2 (M-Key, type:2280, supports NVMe) 1x M.2 (E-Key, type:2230, supports CNVI)
Graphics Controller	Intel® UHD Graphics P630
Video Output	Supports DVI-D, DVI-I, 24-bit dual-channel LVDS
Ethernet	IB995AF-C246& IB995AF: Intel® I219LM Gigabit LAN PHY IB995EF: Intel® I219V Gigabit LAN PHY Intel® I211AT or I210AT Gigabit LAN (as 2nd LAN) IB995AF-C246: Intel® I210AT Gigabit LAN (as 2nd LAN)
I/O Chipset	Fintek F81964D-I
Serial Port	1x RS232/422/485 (jumperless selection) 3x RS232
USB 2.0	2x USB 2.0 on board 1x USB 2.0 via on board USB vertical connector 1x USB 2.0 via M.2 (E-Key)
USB 3.X	5x USB 3.0 on board for IB995AF series 3x USB 3.0 on board for IB995EF
Serial ATA	5x SATA III for IB995AF-C246 3x SATA III for IB995AF 2x SATA III for IB995EF
Audio	Intel® PCH built-in HD audio controller + Realtek ALC888S codec
TPM	TPM (2.0)
Others	Digital I/O (4-in/ 4-out), RAID, iAMT (11.6)
Dimensions (L x W)	338mm x 126mm (13.3" x 4.96")


Power Consumption	Intel® Core™ i7-9700K 3.60GHz Innodisk M4U0-BGS2KCIK-A35 w/ 2x DDR4-2666 32G +3.3V : 0.76A +5V : 0.93A +5VSB : 0.08A +12V : 12.08A
Operating Temperature	0°C ~ 60°C(32°F ~ 140°F)
Storage Temperature	-20°C ~ 80°C(-4°F ~ 140°F)
Relative Humidity	90%(non-condensing @60°C)

Ordering Information

IB995AFS-C246	LGA1151 C246 PICMG1.3 Full-Size CPU Card w/ DVI-I, DVI-D, LVDS, Dual Gigabit LAN, iAMT (11.6), 5x SATA III
IB995AFS	LGA1151 Q370 PICMG1.3 Full-Size CPU Card w/ DVI-I, DVI-D, LVDS, Dual Gigabit LAN, iAMT (11.6), 3x SATA III
IB995EFS	LGA1151 H310 PICMG1.3 Full-Size CPU Card w/ DVI-I, DVI-D, LVDS, Dual Gigabit LAN, 2x SATA III

*(S) means with Realtek ALC888S codec

Dimensions and Drawing

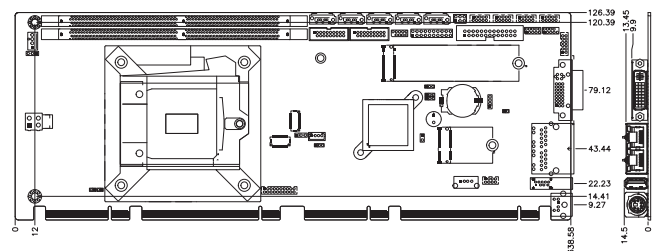

1 Single Board Computers

2 CPU Modules

3 Motherboards

4 CPU Cards