


Specification Sheet

Part Number: 115-06960

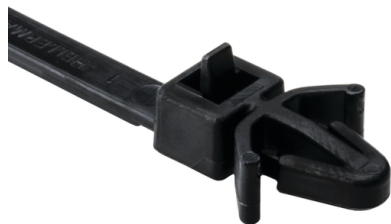

An all-in-one bundling and fixing solution reduces costs.

High-specification materials and superior design suit the fixing and bundling needs of complex applications.

Releasable to provide quick access to bundles.

1-Piece Cable Tie with Arrowhead Mount, 9.0"L, 2.0" Bundle Diameter, PA66, Black, 1000/pkg

Article Number	115-06960
----------------	-----------

Type	RT50SFK
------	---------

Color	Black (BK)
-------	------------

Quantity Per	pack
--------------	------

Product Description	One-piece mounting ties offer a complete solution by bundling cables while at the same time providing a mounting solution. This tie features an extended pawl, allowing the user to release the tie for bundle maintenance. Push mount ties offer the ideal combination of high specification materials and superior design to suit the mounting and bundling needs of complex applications.
---------------------	--

Short Description	1-Piece Cable Tie with Arrowhead Mount, 9.0"L, 2.0" Bundle Diameter, PA66, Black, 1000/pkg
-------------------	--

Global Part Name	RT50SFK-PA66-BK
------------------	-----------------

Minimum Tensile Strength (Imperial)	50
-------------------------------------	----

Minimum Tensile Strength (Metric)	225
-----------------------------------	-----

Length L (Imperial)	9.0
---------------------	-----

Length L (Metric)	225
-------------------	-----

Fixation Method	Arrowhead
-----------------	-----------

Identification Plate Position	none
-------------------------------	------

Releasable Closure	Yes
--------------------	-----

Variant	Inside Serrated
---------	-----------------

Width W (Imperial)	0.2
--------------------	-----

Width W (Metric)	5.0
------------------	-----

Bundle Diameter Min (Imperial)	0.24
--------------------------------	------

Bundle Diameter Min (Metric)	6.0
------------------------------	-----

Bundle Diameter Max (Imperial)	1.97
--------------------------------	------

Bundle Diameter Max (Metric)	50.0
------------------------------	------

Thickness T (Imperial)	0.055
------------------------	-------

Thickness T (Metric)	1.4
Height H (Imperial)	0.24
Height H (Metric)	6
Panel Thickness Min (Imperial)	0.03
Panel Thickness Max (Imperial)	0.11
Panel Thickness Min (Metric)	0.8
Panel Thickness Max (Metric)	3.0
Mounting Hole Diameter D (Imperial)	0.25 - 0.28 "
Mounting Hole Diameter D (Metric)	6.4 - 7.0 mm
Mounting Hole Diameter D Min (Imperial)	0.25
Mounting Hole Diameter D Max (Imperial)	0.28
Mounting Hole Diameter D Max (Metric)	7.0

Material Polyamide 6.6 (PA66)

Material Shortcut PA66

Flammability UL 94 V-2

UV Resistant (Yes/No)	No
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	1000
Package Quantity (Metric)	1000
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)