


Specification Sheet

Part Number: 115-07189

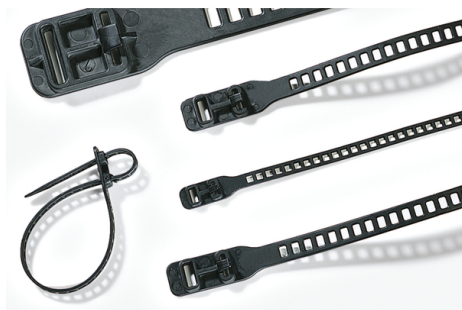

Manufactured from a soft, tear-resistant thermoplastic polyurethane these ties have several unique features: strong, yet elastic, and suitable for temperatures as low as -20 degrees C.

The SOFTFIX ties are releasable and reusable which is ideal for bundling cables in temporary applications such as musical events, theatres etc.

Article Number	115-07189
----------------	-----------

Type	SRT1807
------	---------

Color	Black (BK)
-------	------------

Quantity Per	pack
--------------	------

Product Description	Soft, flexible material makes these ties particularly suitable for use on sensitive wires, such as fibre-optic cables. Additionally the ties are suitable for use on moving or vibrating applications. The double slotted head allows for parallel bundling.
---------------------	--

Short Description	Cable Tie without Serration, 7.0" Long, Flexible TPU, Black, 50/pkg
-------------------	---

Global Part Name	SRT1807-TPU-BK
------------------	----------------

Minimum Tensile Strength (Metric)	57
Length L (Imperial)	7.0
Length L (Metric)	180
Fixation Method	Releasable Cable Tie
Identification Plate Position	none
Releasable Closure	Yes
Tie Closure	ladder style
Variant	Not Serrated
Width W (Metric)	7.0
Bundle Diameter Min (Imperial)	0.39
Bundle Diameter Min (Metric)	10.0
Bundle Diameter Max (Imperial)	1.77
Bundle Diameter Max (Metric)	45.0
Thickness T (Metric)	1.7
Material	Thermoplastic Polyurethane (TPU)

Material Shortcut	TPU
Flammability	UL 94 HB
Halogen Free	Yes
UV Resistant (Yes/No)	No
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	50
Package Quantity (Metric)	50
Customs Number	3926909988
Weight (Metric)	2.2

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com