


Specification Sheet

Part Number: 150-55500

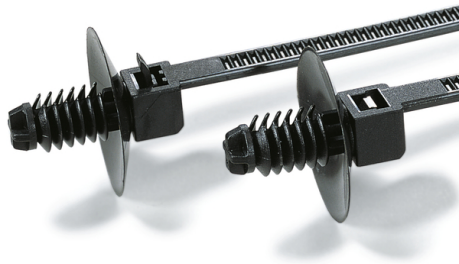

An all-in-one bundling and mounting solution that reduces parts and costs.

High-specification materials and superior design suit the bundling and fastening requirements of complex applications.

Release feature allows maintenance or changeouts as needed.

1-Piece Cable Tie with Fir Tree Mount, 6.7" Long, 0.25 - 0.28" Mounting Hole Diameter, PA66, Black, 500/pkg

Article Number	150-55500
Type	REL30SDP6
Color	Black (BK)
Quantity Per	pack
Product Description	The releasable cable tie with fir tree mount offers a complete bundling and fastening solution. The extended pawl allows the user to release the tie for bundle maintenance. HellermannTyton's one-piece mounting ties deliver the ideal combination of high-specification materials and superior design.
Short Description	1-Piece Cable Tie with Fir Tree Mount, 6.7" Long, 0.25 - 0.28" Mounting Hole Diameter, PA66, Black, 500/pkg
Global Part Name	REL30SDP6-PA66-BK

Minimum Tensile Strength (Imperial)	30
Minimum Tensile Strength (Metric)	135
Length L (Imperial)	6.7
Length L (Metric)	170.0
Fixation Method	Fir tree for round holes
Identification Plate Position	none
Releasable Closure	Yes
Tie Closure	plastic pawl
Variant	Inside Serrated
Width W (Imperial)	0.2
Width W (Metric)	5.0
Bundle Diameter Min (Imperial)	0.06
Bundle Diameter Min (Metric)	1.5
Bundle Diameter Max (Imperial)	1.22
Bundle Diameter Max (Metric)	31.0
Thickness T (Imperial)	0.06

Thickness T (Metric)	1.5
Height H (Imperial)	0.5
Panel Thickness Min (Imperial)	0.12
Panel Thickness Max (Imperial)	0.28
Panel Thickness Min (Metric)	3.0
Panel Thickness Max (Metric)	7.0
Mounting Hole Diameter D (Imperial)	0.25 - 0.28 "
Mounting Hole Diameter D (Metric)	6.3 - 7.1 mm
Mounting Hole Diameter D Min (Imperial)	0.25
Mounting Hole Diameter D Max (Imperial)	0.28
Mounting Hole Diameter D Max (Metric)	7.1
Disc Diameter (Metric)	22.0
Disc Diameter (Imperial)	0.87

Material Polyamide 6.6 (PA66)

Material Shortcut PA66

Flammability	UL 94 V-2
UV Resistant (Yes/No)	No
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	500
Package Quantity (Metric)	500
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)