


Specification Sheet

Part Number: MB29C2

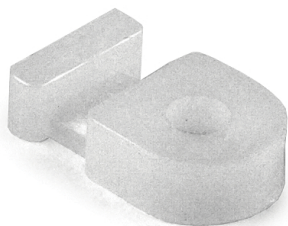

Compact size for areas with limited mounting space.

Simple to install with a screw or rivet.

Single hole attachment with two-way entry for cable tie.

Cable Tie Anchor Mount, 0.81 x .49", 0.193" Hole Dia, 0.18" Max Tie Width, PA66, Natural, 100/pkg

Article Number	151-00227
----------------	-----------

Type	MB2
------	-----

Color	Natural (NA)
-------	--------------

Quantity Per	pack
--------------	------

Product Description	These cable tie mounts are compact in size. They are designed for simple yet robust installation particularly in areas with limited space. They pair with a cable tie for mounting applications including telecom equipment, switchgear and control cabinets.
---------------------	---

Short Description	Cable Tie Anchor Mount, 0.81 x .49", 0.193" Hole Dia, 0.18" Max Tie Width, PA66, Natural, 100/pkg
-------------------	---

Global Part Name	MB2-PA66-NA
------------------	-------------

Length L (Imperial)	0.81
Length L (Metric)	20.6
Fixation Method	Screw Mount
Width W (Imperial)	0.49
Width W (Metric)	12.5
Cable Ties	T18 - T50
Height H (Imperial)	0.13
Height H (Metric)	3.30
Cable Tie Width Max (Imperial)	0.18
Cable Tie Width Max (Metric)	4.6
Mounting Hole Diameter D (Imperial)	0.193 "
Mounting Hole Diameter D (Metric)	4.9 mm
Mounting Hole Diameter D Max (Metric)	4.9
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66

Flammability	UL 94 V-2
Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	100
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)