


## Specification Sheet

Part Number: SRCI0500C2

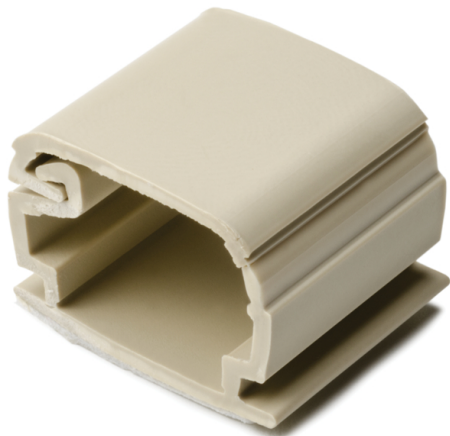

Co-extruded hinge offers unlimited access to wire and cables and can be open and closed repeatedly without signs of wear.

Rubber based adhesive allows for a permanent bond to most surfaces.

TSR Adhesive Cable Clamp, 0.76" Width, 0.51" Height, PVC, Ivory, 100/pkg

Article Number 151-00278

Type SRCI0500

Color Ivory (IV)

Quantity Per pack

Product Description Manufactured from HellermannTyton's surface raceway, these adhesive cable clamps are designed with a co-extruded hinge offering unlimited and easy access to wire and cable. The clip can be open and closed repeatedly without deformation or signs of wear. The rubber based adhesive allows for a permanent bond to most surfaces. Available in three sizes.

Short Description TSR Adhesive Cable Clamp, 0.76" Width, 0.51" Height, PVC, Ivory, 100/pkg

Global Part Name	SRCI0500-PVC-BGE
Length L (Imperial)	0.75
Length L (Metric)	19.1
Width W (Imperial)	0.84
Width W (Metric)	21.3
Bundle Diameter Max (Imperial)	0.5
Bundle Diameter Max (Metric)	12.7
Height H (Imperial)	.51
Height H (Metric)	13.0
Material	Polyvinylchloride (PVC)
Material Shortcut	PVC
Adhesive	Rubber
Flammability	UL 94 V-0 (excluding adhesive)
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only

Operating Temperature +122°F (+50°C)

BABA Compliant YES

Reach Compliant (Article 33) No

ROHS Compliant Yes

Package Quantity (Imperial) 100

Package Quantity (Metric) 100

Customs Number 3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: [corp@htamericas.com](mailto:corp@htamericas.com)

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Privacy Policy](#)

[Cookie Policy](#)

[Terms and Conditions](#)