

## Specification Sheet

Part Number: MB4A10A2H4


For use with HellermannTyton T18 - T50 cable ties to provide stability when securing bundles.

4-way opening allows cable ties to be installed parallel or perpendicular to bundles.

The acrylic-based adhesive is an economical choice ideal for indoor applications, with a static load weight of 1.1 lb.

Two predrilled holes extend mounting options and solutions.

Extended adhesive liner is easy to remove quickly.

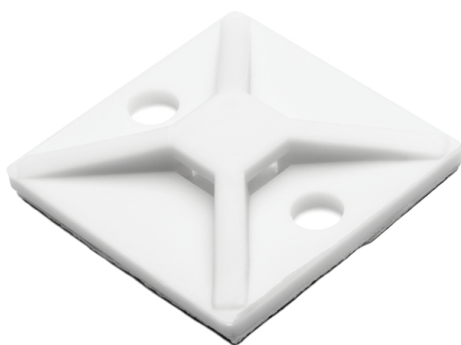

Acrylic Adhesive Cable Tie Mount, 1.12 x 1.12", Use With T18-T50 Cable Tie, PA66, White, 500/pkg

|                |           |
|----------------|-----------|
| Article Number | 151-00322 |
|----------------|-----------|

|      |      |
|------|------|
| Type | MB4A |
|------|------|

|       |            |
|-------|------------|
| Color | White (WH) |
|-------|------------|

|              |      |
|--------------|------|
| Quantity Per | pack |
|--------------|------|

|                     |                                                                                                                                                                                                                                                           |
|---------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Product Description | MB4A adhesive mounts are for use with HellermannTyton T18 - T50 Series cable ties to provide stability when securing bundles. The acrylic adhesive-backed mounts can be used to secure a bundle and have two predrilled holes to extend mounting options. |
|---------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|

|                                     |                                                                                                  |
|-------------------------------------|--------------------------------------------------------------------------------------------------|
| Short Description                   | Acrylic Adhesive Cable Tie Mount, 1.12 x 1.12", Use With T18-T50 Cable Tie, PA66, White, 500/pkg |
| Global Part Name                    | MB4A-PA66-WH                                                                                     |
| Length L (Imperial)                 | 1.12                                                                                             |
| Length L (Metric)                   | 28.5                                                                                             |
| Fixation Method                     | Adhesive                                                                                         |
| Width W (Imperial)                  | 1.12                                                                                             |
| Width W (Metric)                    | 28.5                                                                                             |
| Cable Ties                          | T18 - T50                                                                                        |
| Height H (Imperial)                 | .23                                                                                              |
| Height H (Metric)                   | 5.8                                                                                              |
| Cable Tie Width Max (Imperial)      | 0.18                                                                                             |
| Cable Tie Width Max (Metric)        | 4.6                                                                                              |
| Mounting Hole Diameter D (Imperial) | 0.18 "                                                                                           |
| Mounting Hole Diameter D (Metric)   | 4.6 mm                                                                                           |
| Mounting Hole Centers (Imperial)    | 0.8                                                                                              |

|                                |                                         |
|--------------------------------|-----------------------------------------|
| Material                       | Polyamide 6.6 (PA66)                    |
| Material Shortcut              | PA66                                    |
| Adhesive                       | Acrylate with base of polyethylene foam |
| Flammability                   | UL 94 V-2 (excluding adhesive)          |
| UV Resistant (Yes/No)          | No                                      |
| Use Conditions                 | For Indoor Use Only                     |
| Adhesive Operating Temperature | -31°F to +158°F (-35 °C to +70 °C)      |
| Operating Temperature          | -40°F to +185°F (-40°C to +85°C)        |
| Reach Compliant (Article 33)   | Yes                                     |
| ROHS Compliant                 | Yes                                     |
| Package Quantity (Imperial)    | 500                                     |
| Package Quantity (Metric)      | 500                                     |
| Customs Number                 | 3926909988                              |