

Specification Sheet

Part Number: MB5A10F4


For use with HellermannTyton T18 - T150 cable ties to provide stability when securing bundles.

4-way opening allows cable ties to be installed parallel or perpendicular to bundles.

The rubber-based adhesive is an economical choice ideal for indoor applications, with a static load weight of 2.1 lb.

Two predrilled holes extend mounting options and solutions.

Extended adhesive liner is easy to remove quickly.

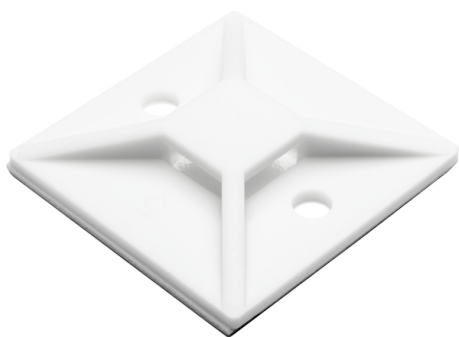

Rubber Adhesive Cable Tie Mount, 1.49 x 1.49", Use T18-T150 Cable Tie, PA66, White, 250/pkg

Article Number	151-00427
----------------	-----------

Type	MB5A
------	------

Color	White (WH)
-------	------------

Quantity Per	pack
--------------	------

Product Description	MB5A adhesive mounts are for use with HellermannTyton T18 - T150 Series cable ties to provide stability when securing bundles. The rubber adhesive-backed mounts can be used to secure a bundle and have two predrilled holes to extend mounting options.
---------------------	---

Short Description	Rubber Adhesive Cable Tie Mount, 1.49 x 1.49", Use T18-T150 Cable Tie, PA66, White, 250/pkg
Global Part Name	MB5A-PA66-WH
Length L (Imperial)	1.49
Length L (Metric)	37.7
Fixation Method	Adhesive
Width W (Imperial)	1.49
Width W (Metric)	37.7
Cable Ties	T18 - T150
Height H (Imperial)	.28
Height H (Metric)	7.1
Cable Tie Width Max (Imperial)	0.35
Cable Tie Width Max (Metric)	8.9
Mounting Hole Diameter D (Imperial)	0.19 "
Mounting Hole Diameter D (Metric)	4.8 mm
Mounting Hole Centers (Imperial)	1.0

Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Adhesive	Synthetic rubber with base of polyethylene foam
Flammability	UL 94 V-2 (excluding adhesive)
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Adhesive Operating Temperature	0°F to +150°F (-18 °C to +66 °C)
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	250
Package Quantity (Metric)	250
Customs Number	3926909988