


Specification Sheet

Part Number: 151-00757

Suitable for applications with minimal space.

CTAM has 4-way entry design for use in line or at 90° angle to cable run.

CTAM mounts are available in different sizes and materials.

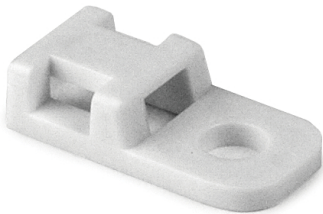

Cable Tie Anchor Mount, 0.17" Hole Dia, 0.20" Max Tie Width, PEEK, Beige, 100/pkg

|                     |                                                                                                                                                                                                                                                                                                                |
|---------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Article Number      | 151-00757                                                                                                                                                                                                                                                                                                      |
| Type                | CTAM1                                                                                                                                                                                                                                                                                                          |
| Color               | Beige (BGE)                                                                                                                                                                                                                                                                                                    |
| Quantity Per        | pack                                                                                                                                                                                                                                                                                                           |
| Product Description | Anchor Mounts for cable ties are suitable for applications with minimal space. Anchors are mounted onto the equipment prior to cable installation and take up no more space than the cable itself. Choose between a four-way entry design that can be used either 'in line' or at 90 degrees to the cable run. |
| Short Description   | Cable Tie Anchor Mount, 0.17" Hole Dia, 0.20" Max Tie Width, PEEK, Beige, 100/pkg                                                                                                                                                                                                                              |
| Global Part Name    | CTAM1-PEEK-BGE                                                                                                                                                                                                                                                                                                 |

|                                       |                             |
|---------------------------------------|-----------------------------|
| Length L (Imperial)                   | 0.81                        |
| Length L (Metric)                     | 20.5                        |
| Fixation Method                       | Screw Mount                 |
| Width W (Imperial)                    | 0.4                         |
| Width W (Metric)                      | 10.2                        |
| Cable Ties                            | T18 - T50                   |
| Height H (Imperial)                   | 0.22                        |
| Height H (Metric)                     | 5.5                         |
| Cable Tie Width Max (Imperial)        | 0.2                         |
| Cable Tie Width Max (Metric)          | 5.0                         |
| Mounting Hole Diameter D (Imperial)   | 0.17 "                      |
| Mounting Hole Diameter D (Metric)     | 4.3 mm                      |
| Mounting Hole Diameter D Max (Metric) | 4.3                         |
| Material                              | Polyetheretherketone (PEEK) |
| Material Shortcut                     | PEEK                        |

|                              |                                   |
|------------------------------|-----------------------------------|
| Flammability                 | UL 94 V-0                         |
| UV Resistant (Yes/No)        | No                                |
| Use Conditions               | For Indoor and Outdoor Use        |
| Operating Temperature        | -67°F to +464°F (-55°C to +240°C) |
| Reach Compliant (Article 33) | Yes                               |
| ROHS Compliant               | Yes                               |
| Package Quantity (Imperial)  | 100                               |
| Package Quantity (Metric)    | 100                               |
| Customs Number               | 3926909988                        |

7930 N. Faulkner Road, Milwaukee, WI 53224  
 Phone: (800) 537-1512 | Email: corp@htamericas.com