


Specification Sheet

Part Number: 151-00903

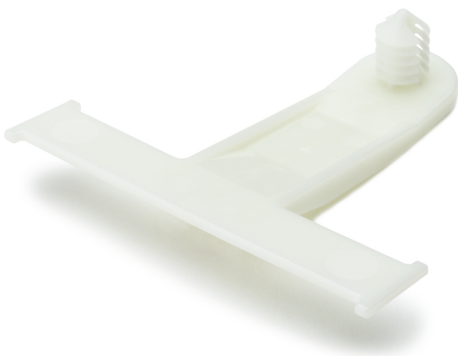

Clip can be installed by hand – no need for hardware or tools.

Design provides low insertion and high extraction force, for simple, secure performance.

Clip keeps bundle away from areas that could cause damage due to rubbing.

Standoff Bundling Clip, 2.3" Long, 0.02 - 0.23" Panel Thickness, PA66HIRHS, Natural, 3000/box

Article Number	151-00903
Type	SOC10FT6LG
Color	Natural (NA)
Quantity Per	pack
Product Description	Bundling clips are designed to provide simple and easy methods of securing cable bundles, hoses, or pipes. They are fastened onto the tape bar using bundle or cable ties. The different fixing orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters. Standard bundling clips are available as well as standoff and stud mount versions.
Short Description	Standoff Bundling Clip, 2.3" Long, 0.02 - 0.23" Panel Thickness, PA66HIRHS, Natural, 3000/box

Global Part Name	SOC10FT6LG-PA66HIRHS-NA
Length L (Imperial)	2.3
Length L (Metric)	58.0
Offset Length (Imperial)	1.71
Offset Length (Metric)	43.35
Fixation Method	Fir Tree
Width W (Imperial)	0.6
Width W (Metric)	16.0
Height H (Imperial)	0.60
Height H (Metric)	14.50
Panel Thickness Min (Imperial)	0.02
Panel Thickness Max (Imperial)	0.23
Panel Thickness Min (Metric)	0.6
Panel Thickness Max (Metric)	5.75
Mounting Hole Diameter D (Imperial)	0.24 - 0.26 " (HEXAGONAL) 0.24 - 0.27 "
Mounting Hole Diameter D (Metric)	6.1 - 6.6 mm

Mounting Hole Diameter D Min (Imperial) 0.24

Mounting Hole Diameter D Max (Imperial) 0.27

Mounting Hole Diameter D Max (Metric) 6.9

Material Polyamide 6.6, high impact modified, heat stabilized (PA66HIRHS)

Material Shortcut PA66HIRHS

Flammability UL 94 HB

UV Resistant (Yes/No) No

Use Conditions For Indoor Use Only

Operating Temperature -40°F to +221°F (-40°C to +105°C)

Reach Compliant (Article 33) Yes

ROHS Compliant Yes

Package Quantity (Imperial) 3000

Package Quantity (Metric) 3000

Customs Number 3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)