


Specification Sheet

Part Number: 151-01888

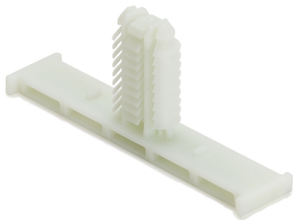

Oval fir tree design allows for this bundling clip to be used in 4 different hole sizes, and various panel thicknesses without compromising performance.

The unique design of the fir tree grips onto the panel due to the branches on all four sides of the mount.

Bundling Clip with Oval Fir Tree, 2.28" L, 0.02 - 0.43" Panel Thickness, PA66HIRHS, Natural, 3000/ctn

Article Number	151-01888
Type	BCFTOVALXL
Color	Natural (NA)
Quantity Per	pack
Product Description	HellermannTyton's bundling clips allow a harness to be routed around a corner and attached to the panel at this location.
Short Description	Bundling Clip with Oval Fir Tree, 2.28" L, 0.02 - 0.43" Panel Thickness, PA66HIRHS, Natural, 3000/ctn
Global Part Name	BCFTOVALXL-PA66HIRHS-NA

Length L (Imperial)	0.53
Length L (Metric)	13.4
Fixation Method	Fir Tree for oval holes
Width W (Imperial)	0.38
Width W (Metric)	9.6
Height H (Imperial)	0.97
Height H (Metric)	24.58
Panel Thickness Min (Imperial)	0.02
Panel Thickness Max (Imperial)	0.43
Panel Thickness Min (Metric)	0.6
Panel Thickness Max (Metric)	11.0
Mounting Hole Diameter D (Imperial)	0.27 x 0.47 " 0.25 x 0.50 " 0.24 x 0.48 "
Mounting Hole Diameter D (Metric)	6.5 x 13.0 mm 7.0 x 12.0 mm 6.2 x 12.2 mm 6.5 x 12.5 mm
Mounting Hole Diameter D Min (Imperial)	0.24
Mounting Hole Diameter D Max (Imperial)	0.50
Mounting Hole Diameter D Max (Metric)	13.0

Material	Polyamide 6.6, high impact modified, heat stabilized (PA66HIRHS)
Material Shortcut	PA66HIRHS
Flammability	UL 94 HB
Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	-40°F to +221°F (-40°C to +105°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	3000
Package Quantity (Metric)	3000
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com