

Specification Sheet

Part Number: MB3A10A2H4


For use with HellermannTyton T18 - T30 cable ties to provide stability when securing bundles.

4-way opening allows cable ties to be installed parallel or perpendicular to bundles.

The acrylic-based adhesive is an economical choice ideal for indoor applications, with a static load weight of 0.6 lb.

Two predrilled holes extend mounting options and solutions.

Extended adhesive liner is easy to remove quickly.

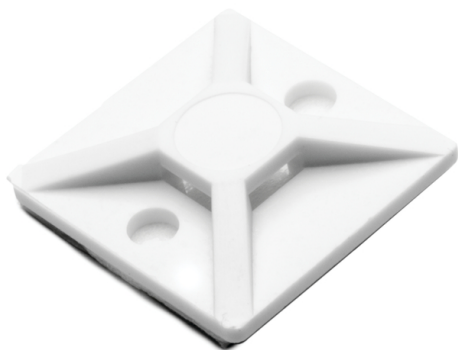

Acrylic Adhesive Cable Tie Mount, 0.75 x 0.75", Use With T18-T30 Cable Tie, PA66, White, 500/pkg

Article Number	151-28717
----------------	-----------

Type	MB3A
------	------

Color	White (WH)
-------	------------

Quantity Per	pack
--------------	------

Product Description	MB3A adhesive mounts are for use with HellermannTyton T18 - T30 Series cable ties to provide stability when securing bundles. The acrylic adhesive-backed mounts can be used to secure a bundle and have two predrilled holes to extend mounting options.
---------------------	---

Short Description	Acrylic Adhesive Cable Tie Mount, 0.75 x 0.75", Use With T18-T30 Cable Tie, PA66, White, 500/pkg
Global Part Name	MB3A-PA66-WH
Length L (Imperial)	0.75
Length L (Metric)	19.0
Fixation Method	Adhesive
Width W (Imperial)	0.75
Width W (Metric)	19.0
Cable Ties	T18 - T30
Height H (Imperial)	.19
Height H (Metric)	4.8
Cable Tie Width Max (Imperial)	0.14
Cable Tie Width Max (Metric)	3.6
Mounting Hole Diameter D (Imperial)	0.12 "
Mounting Hole Diameter D (Metric)	3.0 mm
Mounting Hole Centers (Imperial)	0.52

Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Adhesive	Acrylate with base of polyethylene foam
Flammability	UL 94 V-2 (excluding adhesive)
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Adhesive Operating Temperature	-31°F to +158°F (-35 °C to +70 °C)
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	500
Package Quantity (Metric)	500
Customs Number	3926909988