


Specification Sheet

Part Number: 155-05701

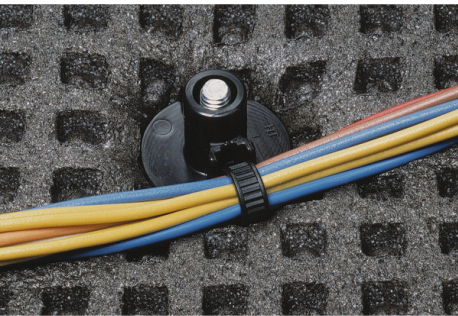

Oval mount design pushes on easy by hand without the need for tools.

Design provides low insertion and high extraction force.

1-Pc Cable Tie/Oval Stud Mount, Designed for 5.0 mm stud, 6.0" Long, PA66HS, Black, 500/pkg

Article Number	155-05701
Type	T50SOSSBH5E
Color	Black (BK)
Quantity Per	pack
Product Description	The special oval shape provides for an approximate .20" (5.0 mm) lateral adjustment, allowing for any misalignment of the stud or incorrect positioning of the tie on the cables
Short Description	1-Pc Cable Tie/Oval Stud Mount, Designed for 5.0 mm stud, 6.0" Long, PA66HS, Black, 500/pkg
Global Part Name	T50SOSSBH5E-PA66HS-BK

Minimum Tensile Strength (Imperial)	50
Minimum Tensile Strength (Metric)	225
Length L (Imperial)	6.0
Length L (Metric)	166.4
Fixation Method	Weld Stud Fixing
Identification Plate Position	none
Releasable Closure	No
Tie Closure	plastic pawl
Variant	Outside Serrated
Width W (Imperial)	0.181
Width W (Metric)	4.6
Bundle Diameter Min (Imperial)	0.04
Bundle Diameter Min (Metric)	1.0
Bundle Diameter Max (Imperial)	1.38
Bundle Diameter Max (Metric)	35.0
Thickness T (Metric)	1.35

Stud Diameter (Metric)	5.0 mm
Stud Diameter (Imperial)	0.197
Material	Polyamide 6.6 heat stabilized (PA66HS)
Material Shortcut	PA66HS
Flammability	UL 94 V-2
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-40°F to +221°F (-40°C to +105°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	500
Package Quantity (Metric)	500
Customs Number	3926909988

