


Specification Sheet

Part Number: 166-90446

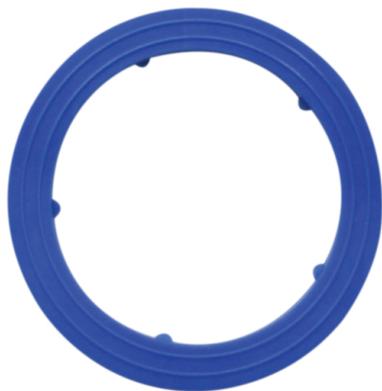

Polyester elastomer washer provides ingress protection against moisture and is oil resistant.

Small "pips" in bore retain washer onto metric threaded fittings.

Ribs on both sides of washer enhances sealing performance.

HelaGuard® Accessories, Sealing Washer, M16-3/8", Polyester Elastomer, Blue, 10/pkg

Article Number	166-90446
Type	RSW038
Color	Blue (BU)
Quantity Per	pack
Product Description	Face sealing washer affixed between metric threaded fitting and entry wall surface to achieve IP66, IP67, IP68 and IP69 levels of ingress protection. Hardness 33 Shore D. Self-extinguishing and halogen free.
Short Description	HelaGuard® Accessories, Sealing Washer, M16-3/8", Polyester Elastomer, Blue, 10/pkg
Global Part Name	RSW038-TPE-BU

Variant	Seal Washer
Thickness T (Imperial)	0.06
Thickness T (Metric)	1.6
Inner Diameter D (Imperial)	0.63
Inner Diameter D (Metric)	16.0
Outside Diameter OD (Imperial)	0.94
Outside Diameter OD (Metric)	24.0
Nominal Diameter (Imperial)	0.38
Nominal Diameter (Metric)	16.0
Material	Thermoplastic Elastomer (TPE)
Material Shortcut	TPE
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	-58°F to +275°F (-50°C to +135°C)
Reach Compliant (Article 33)	No

Package Quantity (Imperial) 10

Package Quantity (Metric) 10

Customs Number 3926904500

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)