

Specification Sheet


Part Number: 170-03084

Split wrap design needs no fasteners and installs quickly, saving assembly time and future accessibility without disassembly.

Bends to a tight radius without distortion or splitting open.

Unique construction retains shape and rigidity throughout unrolling.

Easy open design allows quick access and ability to apply protective sleeving post assembly or post installation situations.

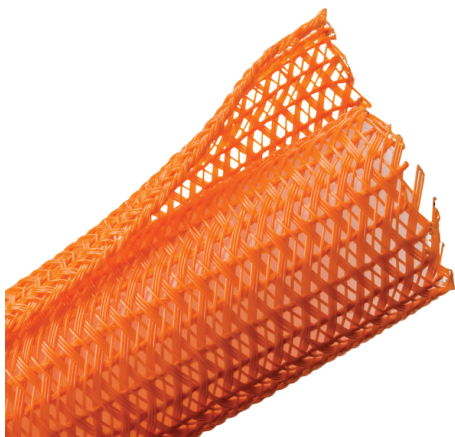

Braided Sleeving, Split Wrap, 0.75" Dia, PET, Orange, 100 ft/ bulk reel

Article Number

170-03084

Type

BSPSW343B

Color

Orange (OG), High Voltage (HV)

Quantity Per

pack

Product Description

A lateral split semi-rigid braided sleeving configuration used when ease of installation and repeat access to wire bundle is required. The lateral split allows the sleeving to open and accommodate a variety of bundling requirements. The 25% edge overlap rolls back over connectors and splices without exposing the bundled wires.

Short Description

Braided Sleeving, Split Wrap, 0.75" Dia, PET, Orange, 100 ft/ bulk reel

Global Part Name	BSPSW343B-PET-OG
------------------	------------------

Length L (Imperial)	100.0
---------------------	-------

Length L (Metric)	30.48
-------------------	-------

Bundle Diameter Min (Imperial)	0.1
--------------------------------	-----

Bundle Diameter Min (Metric)	2.54
------------------------------	------

Bundle Diameter Max (Imperial)	0.75
--------------------------------	------

Bundle Diameter Max (Metric)	19.1
------------------------------	------

Diameter D (Imperial)	0.75
-----------------------	------

Diameter D (Metric)	19.1
---------------------	------

Nominal Diameter (Imperial)	0.75
-----------------------------	------

Nominal Diameter (Metric)	19.1
---------------------------	------

Wall Thickness WT (Imperial)	0.025
------------------------------	-------

Wall Thickness WT (Metric)	0.64
----------------------------	------

Material	Polyester (PET)
----------	-----------------

Material Shortcut	PET
-------------------	-----

Flammability	UL 94 V-0
Halogen Free	Yes
UV Resistant (Yes/No)	Yes
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-94°F to +257°F (-70°C to +125°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
UL Recognized (US)	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	30.48
Customs Number	5808100000

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com