


Specification Sheet

Part Number: 170-20600

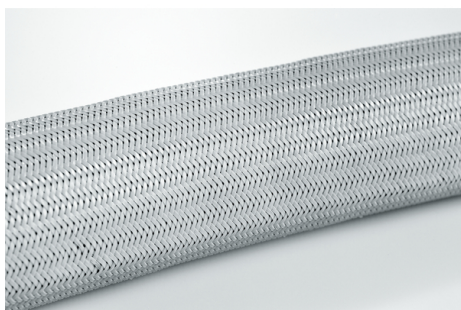

Nylon monofilament construction weave offers a tight braid that provides full coverage but will not rot or retain moisture.

Material performs well in wet applications and where abiding substrate has a smooth surface.

Helagaine Braided Sleeving, 6 mm Dia, PA66,GY, 328ft/Reel

Article Number 170-20600

Type HEGPA6606

Color Gray (GY)

Quantity Per pack

Product Description Helagaine Nylon Polyamide Expandable Braided Sleeving is a pliable yet durable sleeve that protects against cuts, abrasion and excessive wear caused by repetitive motion.

Short Description Helagaine Braided Sleeving, 6 mm Dia, PA66,GY, 328ft/Reel

Global Part Name HEGPA6606-PA66-GY

Length L (Imperial)	328.0
Length L (Metric)	100.0
Bundle Diameter Min (Imperial)	0.16
Bundle Diameter Min (Metric)	4
Bundle Diameter Max (Imperial)	0.31
Bundle Diameter Max (Metric)	8
Diameter D (Imperial)	0.24
Diameter D (Metric)	6.1
Nominal Diameter (Imperial)	0.25
Nominal Diameter (Metric)	6
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Flammability	FMVSS 302 UL 94 V-2
Halogen Free	Yes
UV Resistant (Yes/No)	No

Use Conditions	For Indoor Use Only
Operating Temperature	-76°F to +302°F (-60°C to +150°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	328
Package Quantity (Metric)	100
Customs Number	5808100000

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Privacy Policy](#) [Cookie Policy](#) [Terms and Conditions](#)