


## Specification Sheet

Part Number: 183-28060

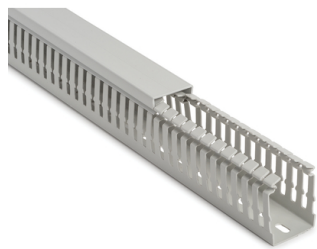

Narrow slots suitable for small-diameter wires.

Fingers can be removed with no sharp edges at pre-notched snap-off points.

Duct covers hold securely even in a vertical position and under vibration.

Base perforation according to DIN EN 50085.

Halogen Free Slotted Wiring Duct & Cover, without Adhesive, 80mm x 60mm, Piece/ABS, Gray, 20 m/Box

Article Number 183-28060

Type HTWD-HF-80X60

Color Gray (GY)

Quantity Per pack

**Product Description**

HelaDuct HTWD-HF wiring duct is used to route and protect wires in control panels and switching systems where there are high demands on personal or material safety in case of fire, such as in public transport, tunnels, data processing centers or public buildings. Snap-on covers are included with corresponding duct sizes to ensure complete wire protection.

**Short Description**

Halogen Free Slotted Wiring Duct & Cover, without Adhesive, 80mm x 60mm, Piece/ABS, Gray, 20 m/Box

|                       |                                                                     |
|-----------------------|---------------------------------------------------------------------|
| Global Part Name      | HTWD-HF-80X60-PC/ABS-GY                                             |
| Length L (Imperial)   | 6.56                                                                |
| Length L (Metric)     | 2.0                                                                 |
| Fixation Method       | Screw Mounting                                                      |
| Width W (Imperial)    | 3.15                                                                |
| Width W (Metric)      | 80.0                                                                |
| Height H (Imperial)   | 2.36                                                                |
| Height H (Metric)     | 60.0                                                                |
| Material              | Acrylonitrile Butadiene Styrene alloyed with Polycarbonate (PC/ABS) |
| Material Shortcut     | PC/ABS                                                              |
| Flammability          | UL 94 V-0                                                           |
| Halogen Free          | Yes                                                                 |
| UV Resistant (Yes/No) | No                                                                  |
| Use Conditions        | For Indoor Use Only                                                 |
| Operating Temperature | -13°F to +194°F (-25°C to +90°C)                                    |

|                               |                                                                                                       |
|-------------------------------|-------------------------------------------------------------------------------------------------------|
| Reach Compliant (Article 33)  | Yes                                                                                                   |
| ROHS Compliant                | Yes                                                                                                   |
| Certification/Specification   | UL   csa-C22.2 no. 62275 UL   csa-C22.2 no. 18.5 UL   ANSI/UL 62275<br>UL   ANSI/UL 1565 EN [45545-2] |
| UL Recognized (US)            | Yes                                                                                                   |
| UL Recognized (US and Canada) | Yes                                                                                                   |
| Package Quantity (Imperial)   | 65.62                                                                                                 |
| Package Quantity (Metric)     | 20.0                                                                                                  |
| Customs Number                | 3925900000                                                                                            |

7930 N. Faulkner Road, Milwaukee, WI 53224  
Phone: (800) 537-1512 | Email: corp@htamericas.com