


Specification Sheet

Part Number: 184-22206

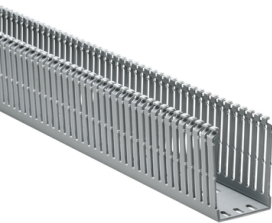

Narrow fingers reduce fanning of wires to terminal blocks, providing a neater appearance.

Each finger features a double restriction to hold wires in the bottom portion of the duct, simplifying installation.

Mounting holes are uniform in size to those in slotted and solid wall duct but are provided every two inches to accommodate compact designs and provide ease of installation.

Nonpermanent adhesive allows repositioning prior to final installation.

High Density Slotted Wall Wiring Duct, 4" x 5", Non-Adhesive, PVC, Gray 7FT, 70ft/Carton

Article Number	184-22206
Type	SLHDA4X5
Color	Gray (GY)
Quantity Per	carton
Product Description	HellermannTyton High-Density Slotted Wall Wiring Duct features narrow fingers equaling a 2-to-1 finger ratio compared to standard slotted wiring duct. With the narrow fingers, compact designs and components are more easily accommodated.

Short Description	High Density Slotted Wall Wiring Duct, 4" x 5", Non-Adhesive, PVC, Gray 7FT, 70ft/Carton
Global Part Name	SLHDA4X5-PVC-GY
Length L (Imperial)	7
Length L (Metric)	2.13
Width W (Imperial)	4.00
Width W (Metric)	101.60
Height H (Imperial)	4.07
Height H (Metric)	103.40
Material	Polyvinylchloride - rigid extrusion grade (PVC)
Material Shortcut	PVC
Flammability	UL 94 V-0
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	+122°F (+50°C)

Reach Compliant (Article 33)	No
ROHS Compliant	Yes
Certification/Specification	EN 50085-2-3_1A UL EN 50085-1:2005 + A1:2013 CSA
UL Recognized (US)	Yes
Package Quantity (Imperial)	70.0
Package Quantity (Metric)	21.34
Customs Number	3925900000

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)