


Specification Sheet

Part Number: FPG

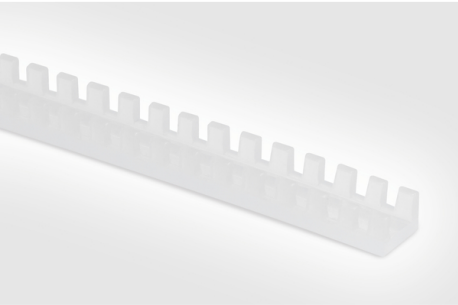

Can be cut to length with scissors, eliminating waste and keeping stock to a minimum.

Available in 9 sizes, for thicknesses from .016" to .512", insuring proper fit.

Grommet, Panel Thickness 0.319"-0.382", PE, Natural, 82ft/pkg

Article Number	251-10709
Type	G51PG
Color	Natural (NA)
Quantity Per	pack
Product Description	HellermannTyton's Flexiform grommet is a unique, continuous wire protection product which fits easily in all shapes and sizes of holes without the aid of tools or adhesives. Flexiform grommet can be used on any type of material including wood, steel, aluminum, plexiglass, and glass.
Short Description	Grommet, Panel Thickness 0.319"-0.382", PE, Natural, 82ft/pkg
Global Part Name	G51PG-PE-NA

Length L (Imperial) 82.0

Variant Open

Width W (Imperial) 0.52

Width W (Metric) 13.2

Height H (Imperial) 0.268

Height H (Metric) 6.8

Panel Thickness Min (Imperial) 0.32

Panel Thickness Max (Imperial) 0.38

Panel Thickness Min (Metric) 8.1

Panel Thickness Max (Metric) 9.7

Material Polyethylene (PE)

Material Shortcut PE

Flammability UL 94 HB

Halogen Free Yes

UV Resistant (Yes/No) No

Use Conditions	For Indoor Use Only
Operating Temperature	-22°F to +176°F (-30°C to +80°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	82
Package Quantity (Metric)	25
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)