


Specification Sheet

Part Number: FHB

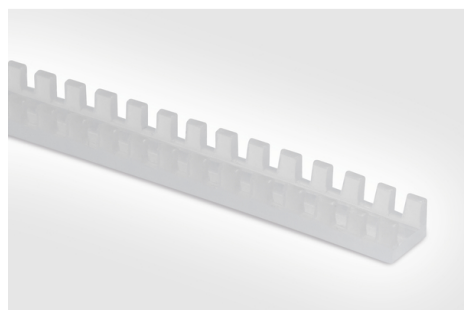

Can be cut to length with scissors, eliminating waste and keeping stock to a minimum.

Available in 9 sizes, for thicknesses from .016" to .512", insuring proper fit.

Article Number	251-21209
----------------	-----------

Type	G51NB
------	-------

Color	Natural (NA)
-------	--------------

Quantity Per	pack
--------------	------

Product Description	HellermannTyton's Flexiform grommet is a unique, continuous wire protection product which fits easily in all shapes and sizes of holes without the aid of tools or adhesives. Flexiform grommet can be used on any type of material including wood, steel, aluminum, plexiglass, and glass.
---------------------	---

Short Description	Grommet, Panel Thickness 0.051"-0.083", PA6, Natural, 82ft/pkg
-------------------	--

Global Part Name	G51NB-PA6-NA
------------------	--------------

Length L (Imperial)	82.0
Variant	Open
Width W (Imperial)	0.181
Width W (Metric)	4.6
Height H (Imperial)	0.169
Height H (Metric)	4.3
Panel Thickness Min (Imperial)	0.05
Panel Thickness Max (Imperial)	0.08
Panel Thickness Min (Metric)	1.3
Panel Thickness Max (Metric)	2.1

Material	Polyamide 6 (PA6)
Material Shortcut	PA6
US MIL SPEC	MS21266-2N
Flammability	UL 94 HB
Halogen Free	Yes

UV Resistant (Yes/No)	No
Operating Temperature	-76°F to +203°F (-60°C to +95°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Certification/Specification	NASM21266
Package Quantity (Imperial)	82
Package Quantity (Metric)	25
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)