


Specification Sheet

Part Number: 251-30309

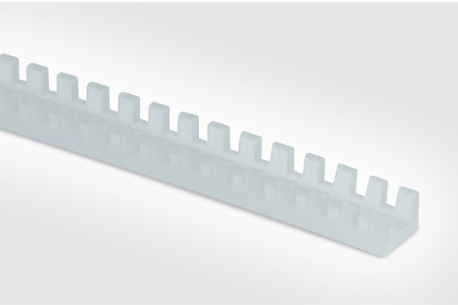

Can be cut to length with scissors, eliminating waste and keeping stock to a minimum.

Available in 9 sizes, for thicknesses from .016" to .512", insuring proper fit.

Grommet, Panel Thickness 0.083"-0.130", PTFE, Natural, 9.7ft/pkg

Article Number	251-30309
Type	G51TC
Color	Natural (NA)
Quantity Per	pack
Product Description	HellermannTyton's Flexiform grommet is a unique, continuous wire protection product which fits easily in all shapes and sizes of holes without the aid of tools or adhesives. Flexiform grommet can be used on any type of material including wood, steel, aluminum, plexiglass, and glass.
Short Description	Grommet, Panel Thickness 0.083"-0.130", PTFE, Natural, 9.7ft/pkg
Global Part Name	G51TC-PTFE-NA

Length L (Imperial) 9.7

Variant Open

Width W (Imperial) 0.224

Width W (Metric) 5.7

Height H (Imperial) 0.169

Height H (Metric) 4.3

Panel Thickness Min (Imperial) 0.08

Panel Thickness Max (Imperial) 0.13

Panel Thickness Min (Metric) 2.1

Panel Thickness Max (Metric) 3.3

Material Polytetrafluoroethylene (PTFE)

Material Shortcut PTFE

US MIL SPEC MS21266-3T

Flammability UL 94 V-0

Halogen Free No

UV Resistant (Yes/No)	No
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-76°F to +500°F (-60°C to +260°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	9.7
Package Quantity (Metric)	3
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)