

## Specification Sheet


Part Number: 553-50018

Slide Slit and optional center slits for easy wire insertion.

Smooth surface for clean and legible printing.

Supplied on a ladder style carrier so that markers can be kitted after printing.

A 3:1 shrink ratio means fewer skews as each marker covers a wider range of wire diameters.

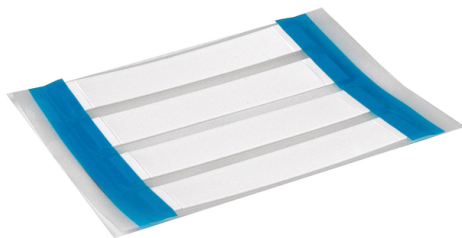

ShrinkTrak Labels, 1-Sided, Unslit, 0.25" (6.35mm), PO-X, White, 5000/box

|                |           |
|----------------|-----------|
| Article Number | 553-50018 |
|----------------|-----------|

|      |          |
|------|----------|
| Type | HST6-2WH |
|------|----------|

|       |            |
|-------|------------|
| Color | White (WH) |
|-------|------------|

|              |      |
|--------------|------|
| Quantity Per | pack |
|--------------|------|

|                     |                                                                                                                                                                                                                                                                                                                                                                                                                       |
|---------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Product Description | HellermannTyton's ShrinkTrak heat shrinkable markers make it easy to mark wire, cable and other components. The military approved heat shrink tubing is flattened and assembled in a ladder style carrier system for easy printing using a thermal transfer printer. The ladder system creates a kit of markers that can be sorted, removed and applied in any order thus saving time, labor and speeding production. |
|---------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|

|                   |                                                                           |
|-------------------|---------------------------------------------------------------------------|
| Short Description | ShrinkTrak Labels, 1-Sided, Unslit, 0.25" (6.35mm), PO-X, White, 5000/box |
|-------------------|---------------------------------------------------------------------------|

|                  |                  |
|------------------|------------------|
| Global Part Name | HST6-2WH-PO-X-WH |
|------------------|------------------|

|         |           |
|---------|-----------|
| Variant | Thin-Wall |
|---------|-----------|

|                    |     |
|--------------------|-----|
| Width W (Imperial) | 1.9 |
|--------------------|-----|

|                  |       |
|------------------|-------|
| Width W (Metric) | 48.26 |
|------------------|-------|

|                        |      |
|------------------------|------|
| Thickness T (Imperial) | .003 |
|------------------------|------|

|                      |       |
|----------------------|-------|
| Thickness T (Metric) | .0762 |
|----------------------|-------|

|                     |      |
|---------------------|------|
| Height H (Imperial) | 0.42 |
|---------------------|------|

|                   |       |
|-------------------|-------|
| Height H (Metric) | 10.67 |
|-------------------|-------|

|                         |      |
|-------------------------|------|
| Width of Liner (Metric) | 76.2 |
|-------------------------|------|

|                           |     |
|---------------------------|-----|
| Width of Liner (Imperial) | 3.0 |
|---------------------------|-----|

|                                |      |
|--------------------------------|------|
| Outside Diameter OD (Imperial) | 0.25 |
|--------------------------------|------|

|                              |      |
|------------------------------|------|
| Outside Diameter OD (Metric) | 6.35 |
|------------------------------|------|

|                                 |      |
|---------------------------------|------|
| Outside Diameter Max (Imperial) | 0.25 |
|---------------------------------|------|

|                               |      |
|-------------------------------|------|
| Outside Diameter Max (Metric) | 6.35 |
|-------------------------------|------|

|                              |       |
|------------------------------|-------|
| Wall Thickness WT (Imperial) | 0.028 |
|------------------------------|-------|

|                            |      |
|----------------------------|------|
| Wall Thickness WT (Metric) | 0.71 |
|----------------------------|------|

|                              |                                                                                |
|------------------------------|--------------------------------------------------------------------------------|
| Material                     | Polyolefin, cross-linked (PO-X)                                                |
| Material Shortcut            | PO-X                                                                           |
| US MIL SPEC                  | MIL-STD-202G Method 215K<br>SAE-AS81531<br>SAE-AMS-DTL-23053/5 Class 1 and 3   |
| Flammability                 | UL 224 VW-1                                                                    |
| Halogen Free                 | No                                                                             |
| UV Resistant (Yes/No)        | No                                                                             |
| Use Conditions               | For Indoor Use Only                                                            |
| Operating Temperature        | -67°F to +275°F (-55°C to +135°C)                                              |
| Reach Compliant (Article 33) | Yes                                                                            |
| ROHS Compliant               | Yes                                                                            |
| Certification/Specification  | SAE - AMS - DTL-23053/5 Class 1 and 3 UL 224 125 °C 600V VW-1<br>SAE - AS81531 |
| Package Quantity (Imperial)  | 5001                                                                           |
| Package Quantity (Metric)    | 5000                                                                           |
| Customs Number               | 3917320000                                                                     |

Labels per Column 1

Labels per Row 1

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: [corp@htamericas.com](mailto:corp@htamericas.com)

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#)   [RoHS/WEEE Compliance](#)   [Disclaimer](#)   [Terms and Conditions](#)