


Specification Sheet

Part Number: 553-50064

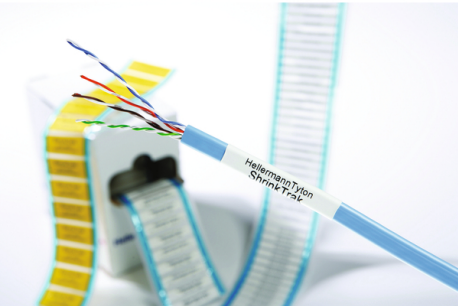

Slide Slit and optional center slits for easy wire insertion.

Smooth surface for clean and legible printing.

Supplied on a ladder style carrier so that markers can be kitted after printing.

A 3:1 shrink ratio means fewer skews as each marker covers a wider range of wire diameters.

ShrinkTrak Labels, 1-Sided, 3-Slit, 0.187" (4.74mm), PO-X, White, 1000/box

|                     |                                                                                                                                                                                                                                                                                                                                                                                                                       |
|---------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Article Number      | 553-50064                                                                                                                                                                                                                                                                                                                                                                                                             |
| Type                | HST4.8-1.6WH-3S                                                                                                                                                                                                                                                                                                                                                                                                       |
| Color               | White (WH)                                                                                                                                                                                                                                                                                                                                                                                                            |
| Quantity Per        | pack                                                                                                                                                                                                                                                                                                                                                                                                                  |
| Product Description | HellermannTyton's ShrinkTrak heat shrinkable markers make it easy to mark wire, cable and other components. The military approved heat shrink tubing is flattened and assembled in a ladder style carrier system for easy printing using a thermal transfer printer. The ladder system creates a kit of markers that can be sorted, removed and applied in any order thus saving time, labor and speeding production. |
| Short Description   | ShrinkTrak Labels, 1-Sided, 3-Slit, 0.187" (4.74mm), PO-X, White, 1000/box                                                                                                                                                                                                                                                                                                                                            |

|                  |                         |
|------------------|-------------------------|
| Global Part Name | HST4.8-1.6WH-3S-PO-X-WH |
|------------------|-------------------------|

|         |           |
|---------|-----------|
| Variant | Thin-Wall |
|---------|-----------|

|                    |       |
|--------------------|-------|
| Width W (Imperial) | 0.475 |
|--------------------|-------|

|                  |       |
|------------------|-------|
| Width W (Metric) | 12.07 |
|------------------|-------|

|                        |      |
|------------------------|------|
| Thickness T (Imperial) | .003 |
|------------------------|------|

|                      |       |
|----------------------|-------|
| Thickness T (Metric) | .0762 |
|----------------------|-------|

|                     |       |
|---------------------|-------|
| Height H (Imperial) | 0.312 |
|---------------------|-------|

|                   |      |
|-------------------|------|
| Height H (Metric) | 7.92 |
|-------------------|------|

|                         |      |
|-------------------------|------|
| Width of Liner (Metric) | 76.2 |
|-------------------------|------|

|                           |     |
|---------------------------|-----|
| Width of Liner (Imperial) | 3.0 |
|---------------------------|-----|

|                                |       |
|--------------------------------|-------|
| Outside Diameter OD (Imperial) | 0.187 |
|--------------------------------|-------|

|                              |      |
|------------------------------|------|
| Outside Diameter OD (Metric) | 4.74 |
|------------------------------|------|

|                                 |       |
|---------------------------------|-------|
| Outside Diameter Max (Imperial) | 0.187 |
|---------------------------------|-------|

|                               |      |
|-------------------------------|------|
| Outside Diameter Max (Metric) | 4.74 |
|-------------------------------|------|

|                              |       |
|------------------------------|-------|
| Wall Thickness WT (Imperial) | 0.026 |
|------------------------------|-------|

|                            |      |
|----------------------------|------|
| Wall Thickness WT (Metric) | 0.66 |
|----------------------------|------|

|                              |                                                                              |
|------------------------------|------------------------------------------------------------------------------|
| Material                     | Polyolefin, cross-linked (PO-X)                                              |
| Material Shortcut            | PO-X                                                                         |
| US MIL SPEC                  | MIL-STD-202G Method 215K<br>SAE-AMS-DTL-23053/5 Class 1 and 3<br>SAE-AS81531 |
| Flammability                 | UL 224 VW-1                                                                  |
| Halogen Free                 | No                                                                           |
| UV Resistant (Yes/No)        | No                                                                           |
| Use Conditions               | For Indoor Use Only                                                          |
| Operating Temperature        | -67°F to +275°F (-55°C to +135°C)                                            |
| Reach Compliant (Article 33) | Yes                                                                          |
| ROHS Compliant               | Yes                                                                          |
| Certification/Specification  | CEN UL 224 125 °C 600V VW-1                                                  |
| Package Quantity (Imperial)  | 1000                                                                         |
| Package Quantity (Metric)    | 1000                                                                         |
| Customs Number               | 3917320000                                                                   |

Labels per Column 1

Labels per Row 4

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: [corp@htamericas.com](mailto:corp@htamericas.com)

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#)   [RoHS/WEEE Compliance](#)   [Disclaimer](#)   [Terms and Conditions](#)