

## Specification Sheet


Part Number: 553-50078

Slide Slit and optional center slits for easy wire insertion.

Smooth surface for clean and legible printing.

Supplied on a ladder style carrier so that markers can be kitted after printing.

A 3:1 shrink ratio means fewer skews as each marker covers a wider range of wire diameters.

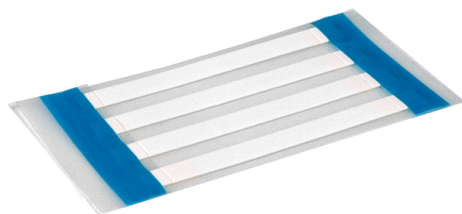

ShrinkTrak Labels, 1-Sided, Unslit, 0.125" (3.17mm), PO-X, White, 2500/box

|                |           |
|----------------|-----------|
| Article Number | 553-50078 |
|----------------|-----------|

|      |          |
|------|----------|
| Type | HST3-1WH |
|------|----------|

|       |            |
|-------|------------|
| Color | White (WH) |
|-------|------------|

|              |      |
|--------------|------|
| Quantity Per | pack |
|--------------|------|

|                     |                                                                                                                                                                                                                                                                                                                                                                                                                       |
|---------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Product Description | HellermannTyton's ShrinkTrak heat shrinkable markers make it easy to mark wire, cable and other components. The military approved heat shrink tubing is flattened and assembled in a ladder style carrier system for easy printing using a thermal transfer printer. The ladder system creates a kit of markers that can be sorted, removed and applied in any order thus saving time, labor and speeding production. |
|---------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|

|                   |                                                                            |
|-------------------|----------------------------------------------------------------------------|
| Short Description | ShrinkTrak Labels, 1-Sided, Unslit, 0.125" (3.17mm), PO-X, White, 2500/box |
|-------------------|----------------------------------------------------------------------------|

|                  |                  |
|------------------|------------------|
| Global Part Name | HST3-1WH-PO-X-WH |
|------------------|------------------|

|         |           |
|---------|-----------|
| Variant | Thin-Wall |
|---------|-----------|

|                    |     |
|--------------------|-----|
| Width W (Imperial) | 1.9 |
|--------------------|-----|

|                  |       |
|------------------|-------|
| Width W (Metric) | 48.26 |
|------------------|-------|

|                        |      |
|------------------------|------|
| Thickness T (Imperial) | .003 |
|------------------------|------|

|                      |       |
|----------------------|-------|
| Thickness T (Metric) | .0762 |
|----------------------|-------|

|                     |       |
|---------------------|-------|
| Height H (Imperial) | 0.235 |
|---------------------|-------|

|                   |      |
|-------------------|------|
| Height H (Metric) | 5.69 |
|-------------------|------|

|                         |      |
|-------------------------|------|
| Width of Liner (Metric) | 76.2 |
|-------------------------|------|

|                           |     |
|---------------------------|-----|
| Width of Liner (Imperial) | 3.0 |
|---------------------------|-----|

|                                |       |
|--------------------------------|-------|
| Outside Diameter OD (Imperial) | 0.125 |
|--------------------------------|-------|

|                              |     |
|------------------------------|-----|
| Outside Diameter OD (Metric) | 3.2 |
|------------------------------|-----|

|                                 |       |
|---------------------------------|-------|
| Outside Diameter Max (Imperial) | 0.125 |
|---------------------------------|-------|

|                               |     |
|-------------------------------|-----|
| Outside Diameter Max (Metric) | 3.2 |
|-------------------------------|-----|

|                              |       |
|------------------------------|-------|
| Wall Thickness WT (Imperial) | 0.031 |
|------------------------------|-------|

|                            |      |
|----------------------------|------|
| Wall Thickness WT (Metric) | 0.79 |
|----------------------------|------|

|                              |                                                                              |
|------------------------------|------------------------------------------------------------------------------|
| Material                     | Polyolefin, cross-linked (PO-X)                                              |
| Material Shortcut            | PO-X                                                                         |
| US MIL SPEC                  | SAE-AS81531<br>SAE-AMS-DTL-23053/5 Class 1 and 3<br>MIL-STD-202G Method 215K |
| Flammability                 | UL 224 VW-1                                                                  |
| Halogen Free                 | No                                                                           |
| UV Resistant (Yes/No)        | No                                                                           |
| Use Conditions               | For Indoor Use Only                                                          |
| Operating Temperature        | -67°F to +275°F (-55°C to +135°C)                                            |
| Reach Compliant (Article 33) | Yes                                                                          |
| ROHS Compliant               | Yes                                                                          |
| Certification/Specification  | CEN                                                                          |
| Package Quantity (Imperial)  | 2500                                                                         |
| Package Quantity (Metric)    | 2500                                                                         |
| Customs Number               | 3917320000                                                                   |

|                   |   |
|-------------------|---|
| Labels per Column | 1 |
|-------------------|---|

|                |   |
|----------------|---|
| Labels per Row | 1 |
|----------------|---|

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: [corp@htamericas.com](mailto:corp@htamericas.com)

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#)   [RoHS/WEEE Compliance](#)   [Disclaimer](#)   [Terms and Conditions](#)