


Specification Sheet

Part Number: 556-00165

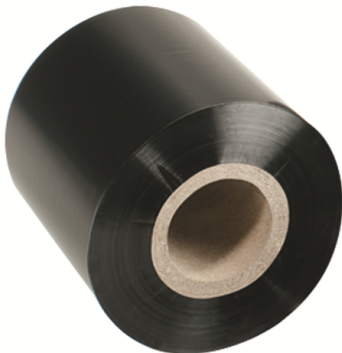

- Ribbons are resin based for the best print durability
- Ribbons are available to fit all HellermannTyton printers for easy resupply
- Ribbons are available in colors for maximizing design printing capabilities
- Ribbons meet UL recognition and Military standard where applicable to meet specific industry label requirements

Thermal Transfer Ribbon, SwiftMark, 2.0" x 984', 1" Core, 100 Resin, Black, 1/pkg

Article Number	556-00165
Type	SM100OUT
Color	Black (BK)
Quantity Per	pack
Product Description	HellermannTyton thermal transfer ribbons are designed for use in HellermannTyton thermal transfer printers. Available on 1/2" and 1" cores, the ribbons are coated side out and available in two different lengths. All ribbons are available in a variety of colors and are matched to the HellermannTyton label stock to give the best chemical and abrasion resistance.
Short Description	Thermal Transfer Ribbon, SwiftMark, 2.0" x 984', 1" Core, 100 Resin, Black, 1/pkg

Global Part Name	SM100OUT-PET-BK
Length L (Imperial)	984.0
Length L (Metric)	300
Reel Diameter (Imperial)	2.5
Reel Diameter (Metric))	63.5
Reel Width (Imperial)	2.0
Reel Width (Metric)	50.8
Variant	Colored ribbon
Width W (Imperial)	2.0
Width W (Metric)	50.8
Material	Polyester (PET)
Material Shortcut	PET
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	+40°F to +300°F (+4°C to +82°C)

Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	1
Package Quantity (Metric)	1
Customs Number	3702390100

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.
[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)