


Specification Sheet

Part Number: TAG15J-450

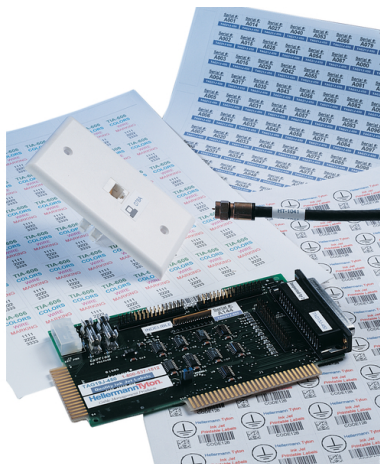

Inkjet printable polyester has a smooth surface, allowing for the highest resolution and print contrast.

The acrylic-based adhesive bonds to a wide variety of substrates and resists abrasion.

When used with black pigment-based inks, the material can withstand chemicals and solvents.

Inkjet Label, 1.0" x .50", 117 Per Sheet, PET, White, 5000/pkg

Article Number	593-15450
----------------	-----------

Type	TAG15J
------	--------

Color	Black (BK)
-------	------------

Quantity Per	pack
--------------	------

Product Description	HellermannTyton offers a series of technologically advanced labels for use on standard inkjet printers. The labels come on 8.5" x 11" sheets and are printable using HellermannTyton's TagPrint Pro software. A wide range of materials and sizes is available for wire and component marking. When used with pigment based inks, HellermannTyton inkjet labels offer superior non-smear marks that are chemical and solvent resistant. Even colors can be printed when used on a color inkjet printer. Inkjet labels are available in polyester or paper.
---------------------	--

Short Description	Inkjet Label, 1.0" x .50", 117 Per Sheet, PET, White, 5000/pkg
Global Part Name	TAG15J-450-BK
Width W (Imperial)	0.5
Width W (Metric)	12.7
Thickness T (Metric)	64.0
Height H (Imperial)	1.0
Height H (Metric)	25.4
Material	Type 450, Polyethylene Terephthalate (450)
Material Shortcut	450
Adhesive	Acrylic
Halogen Free	No
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Adhesive Operating Temperature	-40°F to +302°F (-40°C to +150°C)
Operating Temperature	-40°F to +302°F (-40°C to +150°C)

Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	5000
Package Quantity (Metric)	5000
Customs Number	3919905060
Labels per Column	9
Labels per Row	13

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com