


Technical data sheet

Article number:
156-03189

T30RFT5

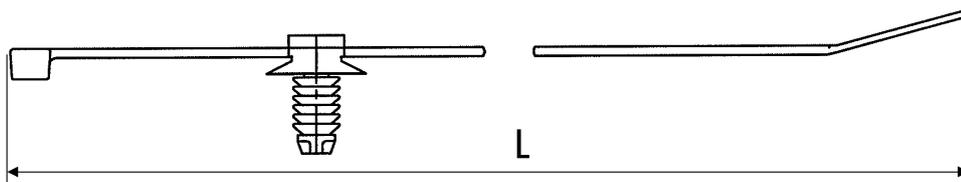

Product Group	2-piece fixing ties with fir tree, with disc, for round holes
Product Family	Fir tree parts FT5
Material	Polyamide 6.6, heat stabilised (PA66HS), Polyamide 6.6, high impact modified, heat stabilised (PA66HIRHS)
Colour	Black (BK)
Application Tool	MK3PNSP2, EVOcut, MK7P, MK10-SB, MK20, EVO7, EVO7SP, EVO7i, EVO7iSP
Bundle Ø max.	35.0 mm
Bundle Ø min.	5.0 mm
Cable Tie	Polyamide 6.6, heat stabilised (PA66HS)
CE Certification	No
Fixation Method	Fir tree for round holes
Flammability	UL 94 HB
Foot Part	Polyamide 6.6, high impact modified, heat stabilised (PA66HIRHS)
for Hole Ø (FH)	4.5 - 5.0 mm
Height (H)	1.2 mm
Length (L)	150.0 mm
Length (L2)	11.6 mm
Min.Tensile Strength	135 N
Operating Temperature	-40 °C to +105 °C
Package Content	500 pcs.
Package Content packed in	bag
Panel Thickness	0.7 - 3.0 mm
Panel Thickness max.	3.0 mm
Panel Thickness min.	0.7 mm
ROHS compliant	Yes
Thickness (T)	1.2 mm

UV-Stabilised	No
Variant	Inside Serrated
Width (W)	3.5 mm

