


# TECHNICAL DATA SHEET

**Part No.** 170-20800  
**Article No.** 170-20800  
**Type** HEGPA6608

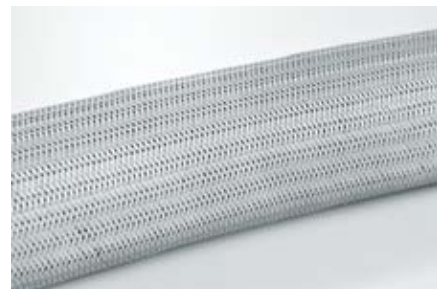

Helagaine Nylon Polyamide Expandable Braided Sleeve is a pliable yet durable sleeve that protects against cuts, abrasion and excessive wear caused by repetitive motion.

|                              |                                   |
|------------------------------|-----------------------------------|
| <b>Material</b>              | Polyamide 6.6 (PA66)              |
| <b>Operating Temperature</b> | -76°F to +302°F (-60°C to +150°C) |
| <b>Melting Point</b>         | +491 °F (+255 °C)                 |
| <b>Abrasion Resistance</b>   | High                              |
| <b>Flammability</b>          | UL 94 V-2, FMVSS 302              |
| <b>Halogen Free</b>          | Yes                               |
| <b>UV Resistant</b>          | No                                |
| <b>Use Conditions</b>        | For Indoor Use Only               |
| <b>Color</b>                 | Gray (GY)                         |
| <b>Pkg. Qty.</b>             | 328 ft                            |
| <b>Carton Qty.</b>           | 1                                 |
| <b>Customs Number</b>        | 5808100000                        |

|                                        |          |
|----------------------------------------|----------|
| <b>Max. Bundle Diameter (imperial)</b> | 0.39 "   |
| <b>Max. Bundle Diameter (metric)</b>   | 10 mm    |
| <b>Min. Bundle Diameter (imperial)</b> | 0.2 "    |
| <b>Min. Bundle Diameter (metric)</b>   | 5 mm     |
| <b>Nominal Diameter (imperial)</b>     | 0.31 "   |
| <b>Nominal Diameter (metric)</b>       | 8 mm     |
| <b>Reel Length (imperial)</b>          | 328.0 ft |
| <b>Reel Length (metric)</b>            | 100.0 m  |

HF ✓

RoHS ✓