


TECHNICAL DATA SHEET

Part No. WC1503X2
Article No. 597-00034
Type WC1503

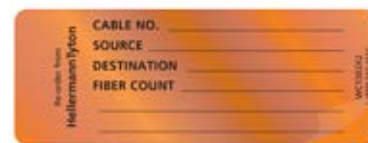

Custom fiber optic tag features a plastic flap to protect tag message.

Material	Polyvinylchloride (PVC)
Adhesive	Acrylic
Operating Temperature	-40°F to +266°F (-40°C to +130°C)
Halogen Free	No
UV Resistant	No
Use Conditions	For Indoor and Outdoor Use
Color	Silver (SR)
Pkg. Qty.	25
Carton Qty.	1
Customs Number	3926909988

Height (imperial)	1.0 "
Height (metric)	25.40 mm
Width (imperial)	4.0 "
Width (metric)	101.60 mm

RoHS ✓