



Common Mode Choke

TCK-087


Order Code	TCK-087
Inductance (each winding)	224 μ H $\pm$ 35% (at 100 kHz / 100 mV)
Impedance (DCR)	4.16 m Ω max.
Rated Current	15.4 A max.
Rated Voltage	500 VDC max. (between windings)
Operating Temperature	-40°C to +105°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-087

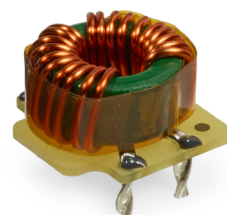

Impedance Curve

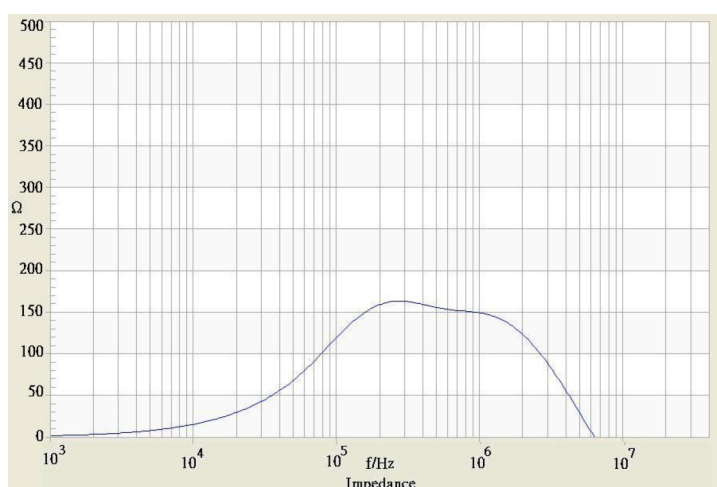

Outline Dimensions

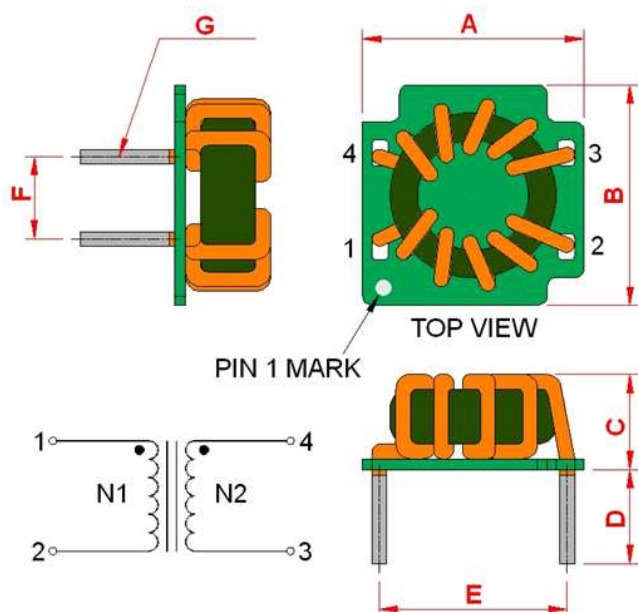

Dimensions [mm]

A	16.6 $\pm$ 0.4
B	16.4 $\pm$ 0.4
C	12.5 max.
D	5.0 $\pm$ 1.0
E	14.1 $\pm$ 0.5
F	6.1 $\pm$ 0.5
G	$\varnothing$ 1.6 max.

All specifications valid at +25°C, unless otherwise stated.